




Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Connectors

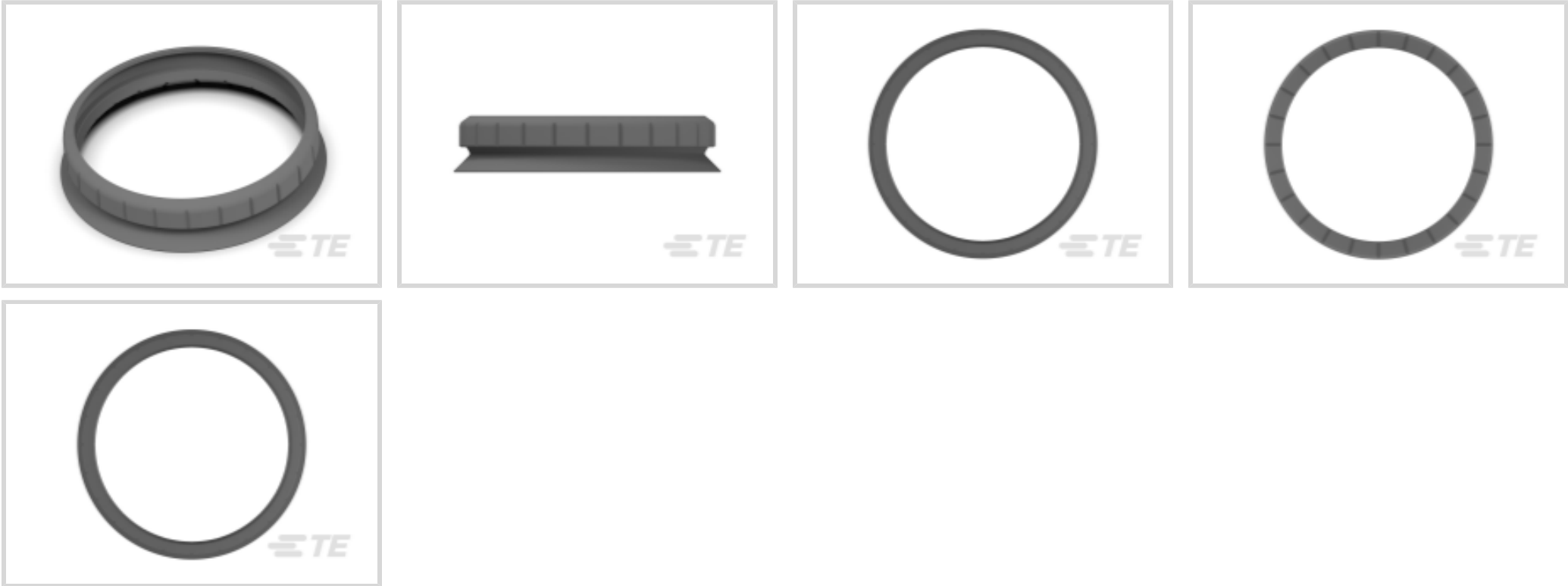

Lighting Product Type: **Accessory**
Primary Product Color: **Dark Gray**
Product Height: **18.4 mm [.724 in]**
Number of Positions: **1**
Sealable: **No**

Features

Product Type Features

Lighting Product Type	Accessory
Sealable	No

Configuration Features

Number of Positions	1
---------------------	---

Body Features

Primary Product Color	Dark Gray
-----------------------	-----------

Dimensions

Product Diameter	80 mm[3.149 in]
Product Height	18.4 mm[.724 in]

Usage Conditions

Operating Temperature Range	-40 – 90 °C[-40 – 194 °F]
-----------------------------	---------------------------

Industry Standards

IP Rating	IP66
-----------	------



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-2328823-3
LUMAWISE S 80MM DIA DOME
CLEAR TALL

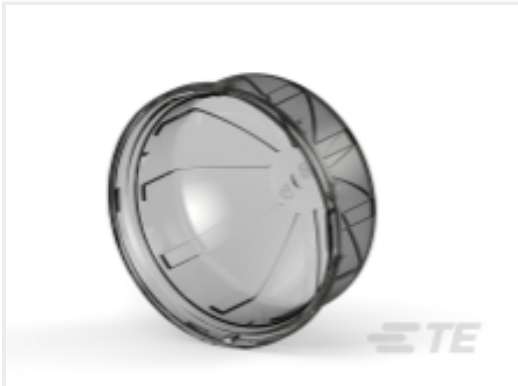

TE Part # 2328823-2
LUMAWISE S 80MM DIA DOME
SMOKE GRAY MED



TE Part # 1-2328823-2
LUMAWISE S 80MM DIA DOME
CLEAR MEDIUM



TE Part # 1-2328823-1
LUMAWISE S 80MM DIA DOME
CLEAR LOW





TE Part # 2328823-1

LUMAWISE S 80MM DIA DOME
SMOKE GRAY LOW




TE Part # 4-2328823-3

LUMAWISE ENDURANCE S 80MM
DOME,GRAY TALL



TE Part # 4-2328823-2


LUMAWISE ENDURANCE S 80MM
DOME, GRAY MED

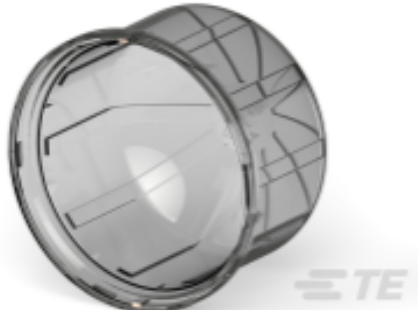


TE Part # 2328823-3

LUMAWISE S 80MM DIA DOME
SMOKE GRAY TALL

Also in the Series | LUMAWISE Endurance S

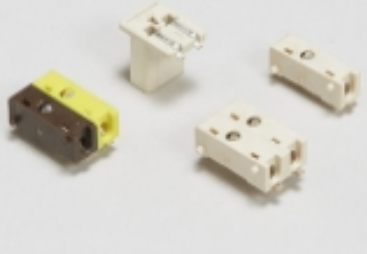

Poke-In Connectors(1)

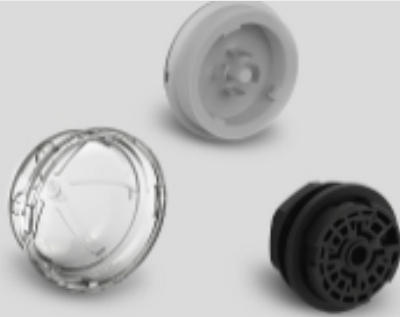

Street Lighting Connectors(47)



Street Lighting Power Management(5)

Customers Also Bought




TE Part #2213837-1

ASSEM., 40MM LUMAWISE
ENDURANCE S




TE Part #1-2328823-1

LUMAWISE S 80MM DIA DOME
CLEAR LOW

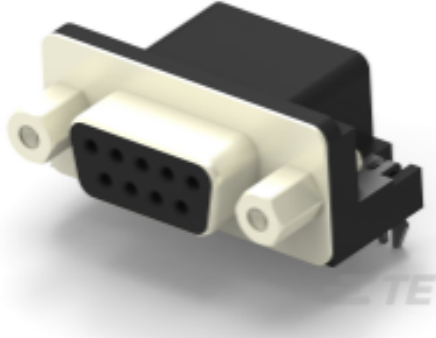


TE Part #2301844-2

AMPL REC HD20, R/A, 9P, B/L,4-40 S
/LOCK

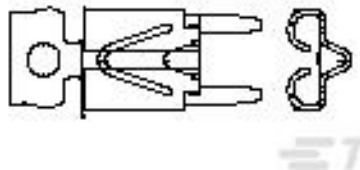

TE Part #1217080-1

FASTON 205/250 PCB MOUNTED
TPBR

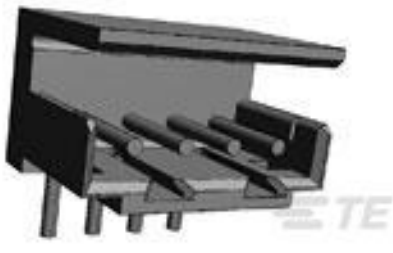

TE Part #292250-4

CT P/HDR BOX H ASSY 4P W/KINK



TE Part #2213795-1

SEALING CAP, RCPT, LUMAWISE
ENDURANCE S



TE Part #1-2213871-1

LIGHT CONTROLLER BASE ASSY,
76MM DIA,5POS



TE Part #292228-5

1.5 MINI CT SGL H SMT W/O BOSS



TE Part #2329013-1

LUMAWISE 40MM DIA DOME SMOKE
GRAY LOW



TE Part #5520251-4

MJ,R/A,8P,PNL STOPS



Documents

Product Drawings

RAIN-SKIRT, LUMAWISE ENDURANCE S, DK GRY

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-2337216-3_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-2337216-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-2337216-3_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

LUMAWISE ENDURANCE Connector System

English

LUMAWISE STREET LIGHT DIMMING AND CONTROL QUICK REFERENCE GUIDE

English

Lumawise Endurance S Modules

English