

# USB

## AOC USB Type C Cable

The AOCUSB3C-7 range of USB-C active optical cables have the unique advantage of being able to support two different specifications depending on the needs of the user. The cable can adjust to its current use and prioritise either video or data transmission.

By using optical fibre instead of copper wire as a high-speed signal transmission medium, it is able to be longer thinner, and less susceptible to electromagnetic interference.

### Specification

- Active optical cable
- Adaptive video/data rates
- TPE Jacket
- Kevlar cable filler
- Backward compatible with USB 2.0/1.1
- Highly resistant to EMI and RFI Interference




This cable can support two different modes depending on the bandwidth of the video signal:

MODE	VIDEO	DATA
Video Mode	8K @ 30Hz	USB2.0 (480Mbps)
Data Mode	4K @ 60Hz	USB3.2 (10Gbps)

Supported Power Delivery

LENGTH	PD SUPPORT
5 - 10 Metres	60w
15 Metres	40w

Lengths Available: 5m, 7.5m, 10 and 15m

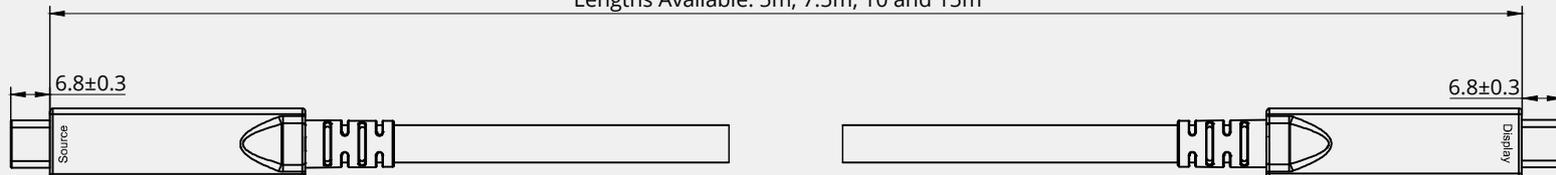

### Part Codes

DESCRIPTION	PART CODE
5m AOC USB C-C Cable - 60w	AOCUSB3C-705
7.5m AOC USB C-C Cable - 60w	AOCUSB3C-707
10m AOC USB C-C Cable - 60w	AOCUSB3C-710
15m AOC USB C-C Cable - 40w	AOCUSB3C-715