




U-Wave bluetooth, Buzzer

Reference: 264-627

Images



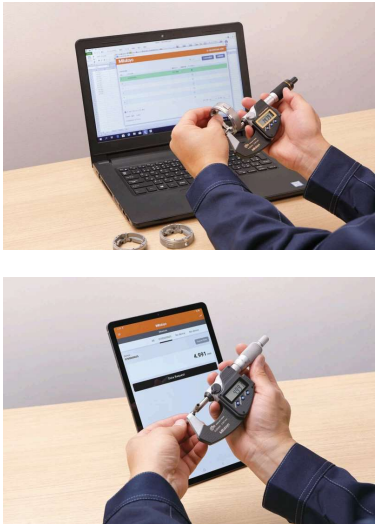


Description

Wireless Transmitter for Micrometer

Features

Wireless communication protocol:	Low energy
Modulation method:	FH-SS (Frequency Hopping Spread Spectrum Method)
Model:	U-Wave-TMB
Data entry confirmation:	Buzzer and LED (green, red, orange)
Communication distance:	Approx. 16 m (without obstacle), 10 m (factory environment)
Food:	CR2032 battery x 1 pc.
Communication with measuring instrument:	Digimatic (6 digits), Digimatic 2 (8 digits) automatic identification
Communication frequency:	2.4 GHz band
Data output:	3.2 mW (5 dBm) or less (class 2)
Compatible operating system:	Windows 10, Android, iOS
Battery life:	WIN 10: approx. 3 months
Dimensions:	41.9 x 38.8 x 12.9 mm
Book:	With screwdriver and CR 2032 battery
Weight:	20 g

Dimensions

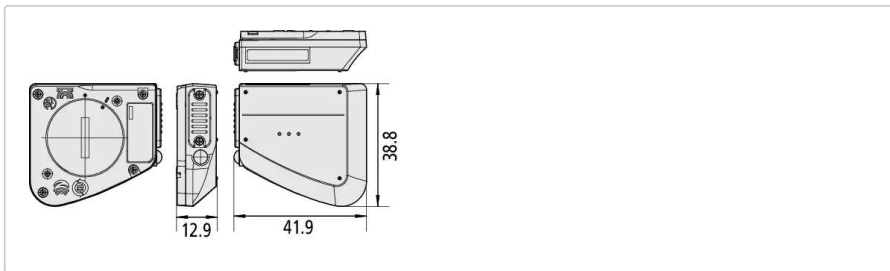

Accessories

Optional accessories:

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Online Software

Art No. 06AGR543

Recommended retail price: € 340.00 *



Connector, U-Wave fit

Waterproof

Art No. 02AZF310

Recommended retail price: € 110.00 *



Connector for comparator

12.7 mm - U-Wave fit, U-Wave fit Bluetooth

Art No. 02AZF700

Recommended retail price: € 124.00 *



Standard accessories:



CR-2032 battery

1 room

Art No. 05SAA217D

Recommended retail price: € 10.00 *