





ENGLISH

Datasheet

Stock No: 522-575

RS Pro 3 Core Screened CY Control Cable, Polyvinyl Chloride PVC Sheath

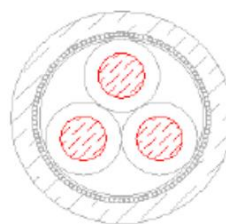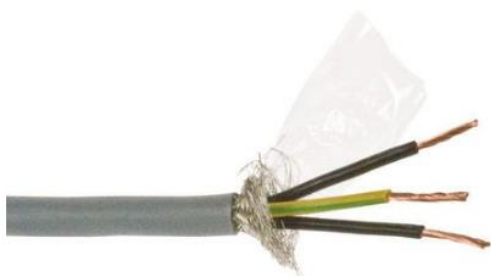

Conductor: Bare Copper
Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$
Insulation: PVC
Insulation Dia. (mm): $2.8 \pm 0.1 \times 3C$
Tape Mylar: $\geq 115\%$
Braid Shield : Tinned Copper
Conductor Dia. (mm): 0.12
Conductor Qty: 16 x 8
Pitch(mm):
Coverage: 70%
Jacket: PVC
Outer Dia. (mm): 8.06 ± 0.2
Colour:
The colour of the insulation: Blue , Brown , Yellow/Green
The jacket colour: Grey (RAL-7001)
Marking(3times/m):
RS 522575 CY/CC 3 Core x 1.5mm²

Description:

Rated Temperature (oC): -20 ~ 80
Rated Voltage (V): 300

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<13.7
Min.Insulation DC Resistance at 20°C (MΩ*KM) :
>500
Current Rating : 16 A