


# weatherproof and vandal-resistant bulkhead lights IP 54/IP 55

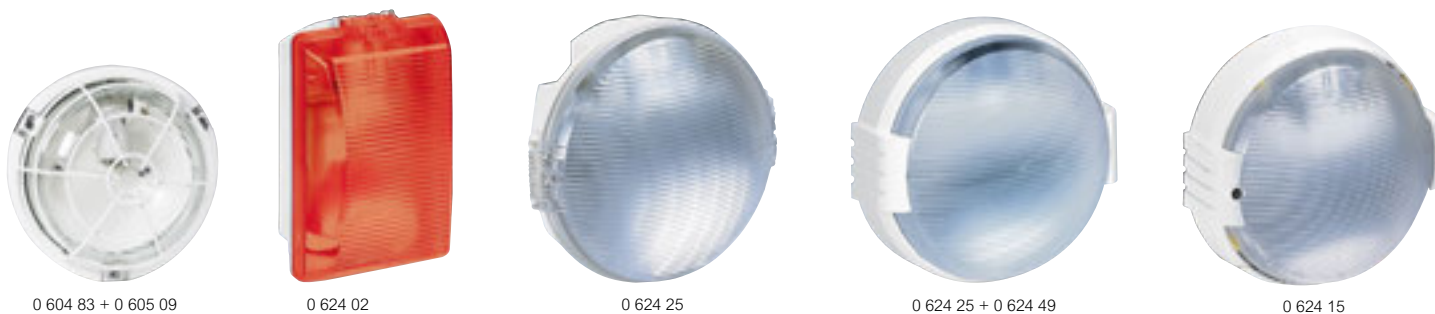

Dimensions p. 626

For domestic, commercial areas and tough environments

Pack	Cat.Nos	<b>Weatherproof bulkhead lights for tough environments</b>
		Metal/glass bulkhead lights. For exterior/indoor use For industrial use. Earth terminal - 3 entries in T Operating temperature: • min.: - 30 °C, • max.: + 35 °C IP 55 - IK 04
1	E 27 0 604 77	Oval - for 75 W incandescent lamp With colourless glass diffuser
1	0 605 08	Metal protection grid for Cat.No 0 604 77 For IK 07 protection
1	0 604 83	Round - for 100 W incandescent lamp With colourless diffuser
1	0 605 09	Metal protection grid for Cat.No 0 604 83 For IK 07 protection

Pack	Cat.Nos	<b>Plexo rectangular - IP 54 - IK 08 - class II</b>
		Polycarbonate diffuser, mounted on hinge Opening can be reversed Top/Base Supplied with one Plexo end cap, not assembled Through wiring or terminal connection (side or rear) Lampholder mounted on reflector (swivel pull-out type) Grey base self-extinguishing: 850 °C For 75 W incandescent lamp
5	E 27 0 624 00	With clear diffuser
5	0 624 02	With red diffuser

Pack	Cat.Nos	<b>Round Koro bulkhead lights and accessory</b>
		<b>IP 54 - IK 08 - class II</b> Polycarbonate diffuser, mounted on hinge Opening can be reversed right/left Supplied with 1 Plexo end cap, not assembled Through wiring or terminal connection (side or back) Porcelain lampholder mounted on reflector (swivel pull-out type). Self-extinguishing at 850 °C. White
5	E 27 0 624 25	For 100 W lamps
1	G 23 0 624 26	For 2 x 9 W compact fluorescent lamps
1	0 624 49	<b>Finishing accessories</b> White clip-on cover plate for round bulkhead lights Polycarbonate

Pack	Cat.Nos	<b>Vandal-resistant Koro bulkhead lights</b>
		For risk situation, indoors and outdoors tough environments, internal and external applications <b>IP 55 - IK 09 - class II</b> Security assured by covering trim. Locked with 2 special screws which may be locked with key Cat.No 0 919 45 (below). Shock-resistant polycarbonate diffuser. Opening can be reversed right / left supplied with 1 Plexo membrane gland. Through. wiring or terminal connection (side or rear). White
1	E 27 0 624 15	Round for 100 W lamps
1	0 919 45	<b>Vandal resistant accessory</b> Screwdriver to remove/tighten tamperproof screws