



U.53S - Jack beams



Description:

- These 2 non tapped beams with mechanical specifications exceeding U.53K (dimensions, steel and thermal treatment) are designed to withstand the high loads generated by the power of jacks used.

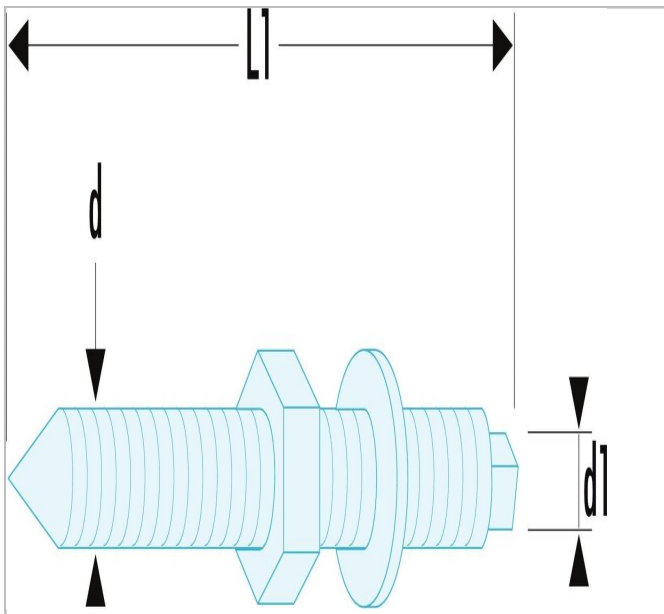

	Depth Maxi [mm]	Diame ter [mm]	Diame ter D1 [mm]	Len gth L [mm]	Len gth L1 [mm]	Len gth L2 [mm]	Len gth L3 [mm]	C Mi ni - Ma xi [mm]	Screw Size ["]	Tonn es ["]	t ["]	Wei ght [Kg]
U.53S 2A	235. 0	280.0	M20	220. 0	280. 0	35.0	35.0	120 - 200	U.53S2 A07	10.0	100 .0	3.0
U.53S 4A	340. 0	420.0	M33	450. 0	420. 0	60.0	60.0	170 - 400	U.53S4- 07	30.0	300 .0	15.5