


RACON, round plunger 14.5 mm, L 4.6 mm

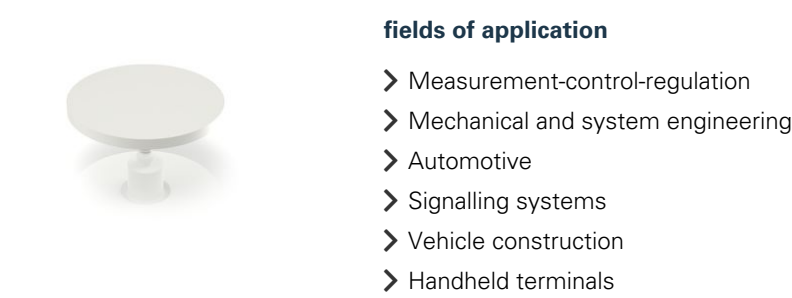

- fields of application
- > Measurement-control-regulation
 - > Mechanical and system engineering
 - > Automotive
 - > Signalling systems
 - > Vehicle construction
 - > Handheld terminals

description

The wide selection of standard plungers in different shapes and colors guarantees a versatile range of applications for the RACON tactile switch.

technical data

> general

Color	white
Collar shape	round
illuminated	No
Packaging unit	500 pcs.
net weight	0.2 g
MOQ order	1,000 pcs.
RoHS compliant	Yes
REACH compliant	Yes
Component material	Plastic

> mounting diameters


Outside dimension, length	6.1 mm
Outside dimension, width	14.5 mm
Outside dimension, height	14.5 mm
Plunger length L	4.6 mm

direct links

- > [RAFI eCatalog](#)

drawings

Dimensioned drawing

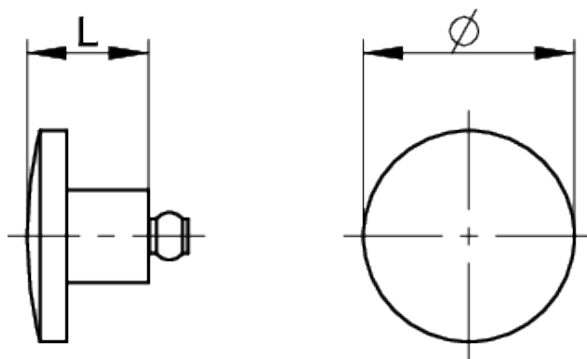

System drawing

SMT gullwing connection

Recommended: Embossing: 0.35 mm

Adhesive thickness: 0.15 mm

