


Tapered roller bearings, single row, metric bearings

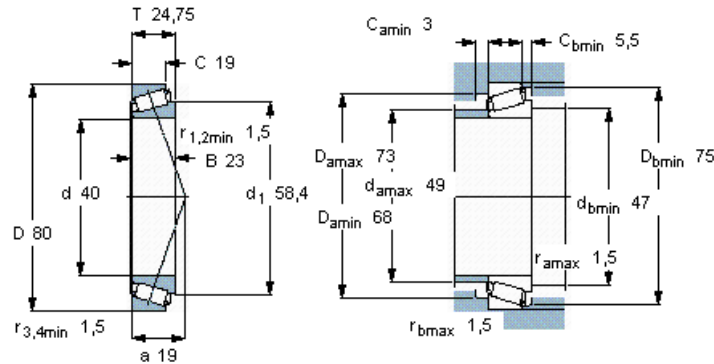

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass kg	Designation
d	D	T	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min		-	
40	80	24,75	78,8	86,5	9,8	6300	8500	0,53	32208 J2/Q



Calculation factors

e 0,37
 Y 1,6
 Y_0 0,9