

Han 24HPR-enlarged-HSM angled-3xM32

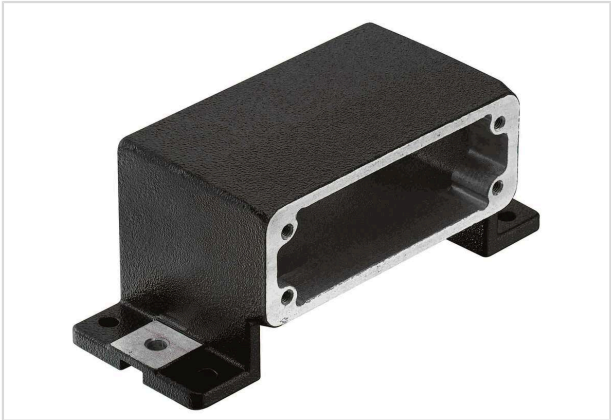


Image is for illustration purposes only. Please refer to product description.

Part number	19 40 024 0968
Specification	Han 24HPR-enlarged-HSM angled-3xM32
HARTING eCatalogue	https://harting.com/19400240968

Identification

Category	Hoods / Housings
Series of hoods/housings	Han [®] HPR enlarged
Type of hood/housing	Surface mounted housing
Description of hood/housing	Horizontal version

Version

Size	24 HPR enlarged
Version	Top entry
Number of cable entries	3
Cable entry	3x M32
Field of application	Hoods/housings for harsh outdoor environments
Details	Bulkhead mounted housing 09 40 024 0368 not included, please order separately
Details	When using Han [®] Standard inserts of size B or Han-Modular [®] hinged frames, please order adapter 09400009961 separately.

Technical characteristics

Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP65 IP68 IP69 / IPX9K acc. to ISO 20653
Type rating acc. to UL 50 / UL 50E	4 4X 12



Pushing Performance
Since 1945

Material properties

Material (hood/housing)	Aluminium die-cast Corrosion resistant
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 9005 (jet black)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R1 (HL 1-3) R7 (HL 1-3)

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	CE DNV GL

Commercial data

Packaging size	1
Net weight	850 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140130265
eCl@ss	27440202 Shell for industrial connectors
ETIM	EC000437
UNSPSC 24.0	39121466