




**LED A60 Switch E27 DIM 8.5W (60W) 806lm 5CCT 827-865**

Article number: 145935

BAI LED A60 Switch E27 8.5W (60W) 806lm Dimmable 5CCT 2700K-3000K-4000K-5000K-6500K Opal 230V-240V 180° 60x114mm LED-lamp

Sustainability is not only about replacing old light sources with a more energy-efficient version. It is even more sustainable when 5 different versions are combined in 1 product. This saves on transport and storage. The special thing about the Switch series is that by simply adjusting a switch, the light color can change into 2700K, 3000K, 4000K, 5000K and 6500K. That's Smart and Green Thinking. Ambient temperature: -20°C to +40°C.

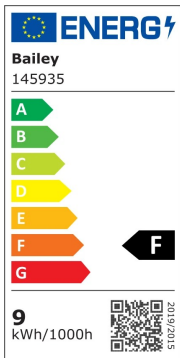

**General ETIM properties**

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED A60 Switch E27 DIM 8.5W (60W) 806lm 5CCT 827-865
Brand	Bailey
Productseries	Ecoplus LED bulb
Producttype	A60 Switch

## ETIM specifications

Socket	E27
Luminous flux [lm]	806 - 806
Nominal voltage [V]	220 - 240
Lamp power [W]	8.5 - 8.5
Colour temperature [K]	2700 - 6500
Diameter [mm]	60
Length [mm]	114
Dimmable	Yes
Lamp shape	Pear-shape
Beam angle [°]	180 - 180
Colour	White
Type of glass/cover	Opal
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	806
Power factor	0.8
Lamp efficacy [lm/W]	95
Nominal current [mA]	53 - 53
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	7500
Weighted energy consumption in 1000 hours [kWh]	9
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

---

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Plastic