 


- Plug-in unit
- Fixed output voltages
- Thermal fuse in transformer
- Available as standard version with bridge rectifier and capacitor
- Exchangeable output plugs
- Plugg-inn enhet
- Faste utgangsspenninger
- Termosikring i transformator
- Standardversjonen leveres med brolikeretter og kondensator
- Utskiftbare plugger




Technical specifications

Input voltage:
 Output voltage:
 Max. output power:
 Insulation class:
 Electrical safety standard:
 EMC standards
 • Emission:
 • Immunity:
 Output terminals
 Cord with/without plug:
 Dimensions excl. plug:
 Weight:

Tekniske data

Inngangsspenning: 230 VAC +6/-10%, 50/60Hz
 Utgangsspenning: 1,5-42 VDC
 Maks. utgangseffekt: 6,5 W
 Isolasjonsklasse: II
 Elektrisk sikkerhetsstandard: EN 60950
 EMC standarder
 • Emisjon: EN 61000-6-3
 • Immunitet: EN 61000-6-1
 Utgangsterminaler
 Sek. ledning med/uten plugg: Accessories /Tilbehør
 Mål uten plugg: 95 x 51 x 57 mm
 Vekt: 390 g

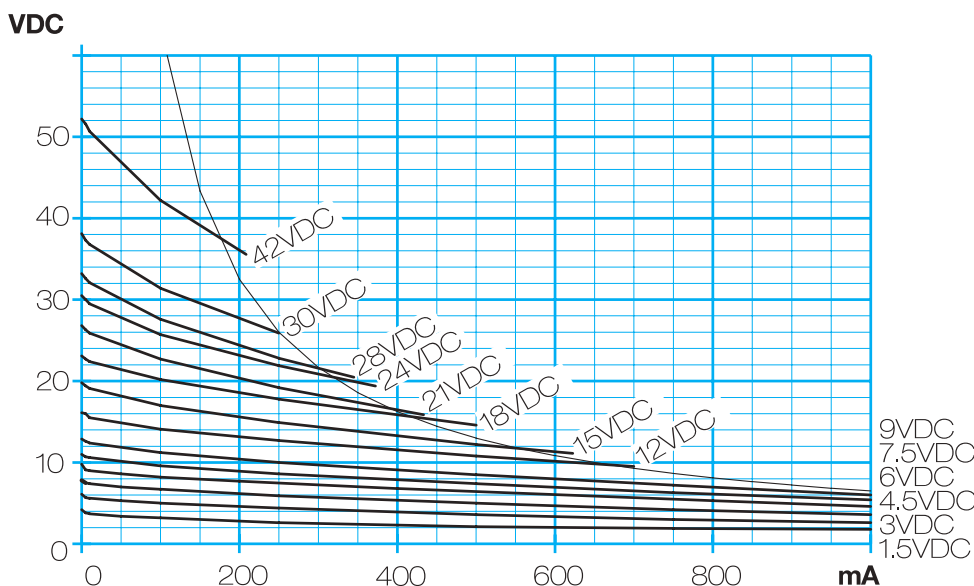

Voltage version (VDC) Spenningsversjoner (VDC)	Max. power (W) Maks. effekt (W)
1,5	1,9
3	3,5
4,5	4,5
6	5,5
7,5	5,5
9	6,0
12	6,5
15	6,5
18	6,5
21	6,5
24	6,5
28	6,5
30	6,5
42	6,5