


# Datasheet


## AC Axial Fan, 119.5 x 119.5 x 38.5mm, 121m/h, 15W, 230 V ac

RS Stock number 789-7905

Dimensions: (mm)

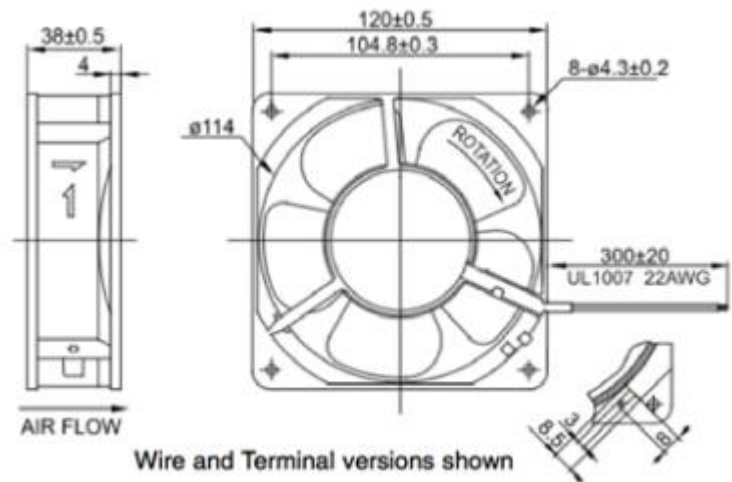

### Specifications

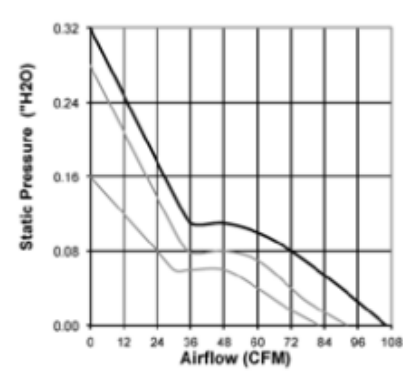Frame	Diecast Aluminum	Notes	
Impeller	PBT, UL94V-0	Date: 041912	
Connection	2x Lead Wires or terminals	<u>Available Options</u> Dual Voltage	
Motor	AC shaded pole, impedance and thermally protected		
Bearing System	Ball or Sleeve bearing		
Insulation Resistance	DC500V 100M ohm between lead wire and frame (500VDC)	* Specify configuration: TB = Terminal, Ball bearing WB = Wire leads, Ball bearing TS = Terminal, Sleeve bearing WS = Wire leads, Sleeve bearing	
Dielectric Strength	1 minute at 1500VAC, max. leakage < 500 MicroAmp		
Temperature Range	-20C ~ +80C (ball) -10C ~ +50C (sleeve)		
Life Expectancy	40000 hours L10 (40C) 20000 hours L10 (40C)		