

Datasheet

RS Pro P13.5s Filament Indicator Lamp, Clear, 4.75 V, 500 mA, 20h

RS Stock No: **105-152**



Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 4.75 V and current rating of 500 mA. The lamp has 20 h life.

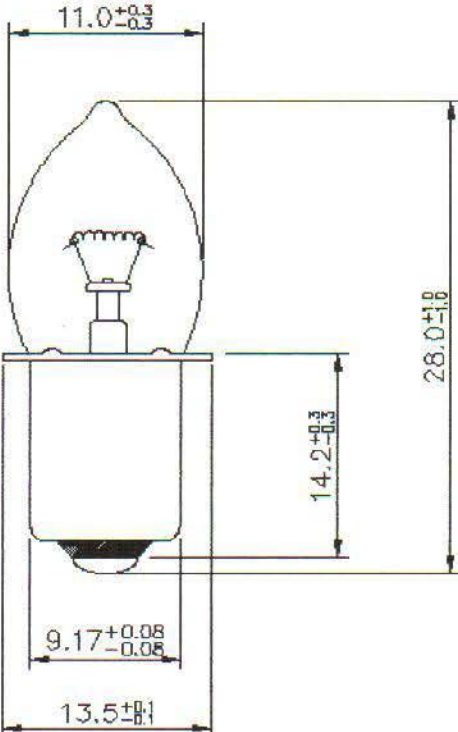
Features and Benefits

- Olive shape B3 1/2 - 11 mm glass
- P13.5s prefocus base
- Vacuum



Specifications:

Current Rating	500 mA
Diameter	11.3 mm
Lamp Base	P13.5s
Lamp Size	B3 1/2
Length	29 mm
Lens Colour	Clear
Life Hours	20 h
Luminosity	32 lm
Voltage Rating	4.75 V

RS Stock No.		105152	
<i>DRAWING - I</i>			
		Unit : mm	
1. Structure	Bulb Type	B3 1/2	
	Bulb Diameter	Ø 11.3Max.	
	Length	29.0Max	
	Base Type	P13.5s KRP	
2. Design Characteristics	Voltage	4.75V	
	Amperage	500mA±10%	
	Gas Type	Krypton gas-filled	
	M.S.C.P.	2.54CP±20%	
	Life Hours	20Hrs	