

2106136-3 ✓ ACTIVE

[SlimSeal](#) | [SlimSeal Connectors Headers](#)

TE Internal #: 2106136-3

Wire-to-Wire, 3 Position, .14 mm [3.5 in] Centerline, Sealable, Wire & Cable, SlimSeal Connectors Headers, Plug & Socket Lighting Connectors

[View on TE.com >](#)



[Connectors](#) > [Lighting Connectors](#) > [Plug & Socket Lighting Connectors](#)



Connector System: **Wire-to-Wire**

Number of Positions: **3**

Centerline (Pitch): **.14 mm [ 3.5 in ]**

Sealable: **Yes**

Connector & Contact Terminates To: **Wire & Cable**

## Features

### Product Type Features

Connector System	Wire-to-Wire
Sealable	Yes
Connector & Contact Terminates To	Wire & Cable
Lighting Connector Style	Receptacle

### Configuration Features

Number of Positions	3
---------------------	---

### Electrical Characteristics

Operating Voltage	250 VDC
-------------------	---------

### Body Features

Primary Product Color	Black
-----------------------	-------

### Contact Features

Contact Current Rating (Max)	5 A
------------------------------	-----

### Housing Features



Centerline (Pitch)	.14 mm[3.5 in]
--------------------	----------------

**Usage Conditions**

Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]
-----------------------------	----------------------------

**Product Compliance**

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

**Compatible Parts**






TE Part # 2-2106124-2  
Contact, Tab, Tin Plated, 22-26 AWG

### Also in the Series | SlimSeal Connectors Headers



Plug & Socket Lighting Connectors(19)


### Customers Also Bought

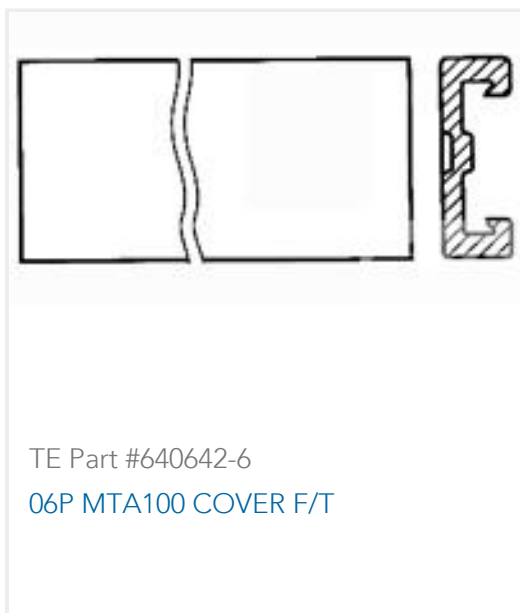

TE Part #640642-6  
06P MTA100 COVER F/T



TE Part #2106135-3  
Assembly, Plug, 3-Position

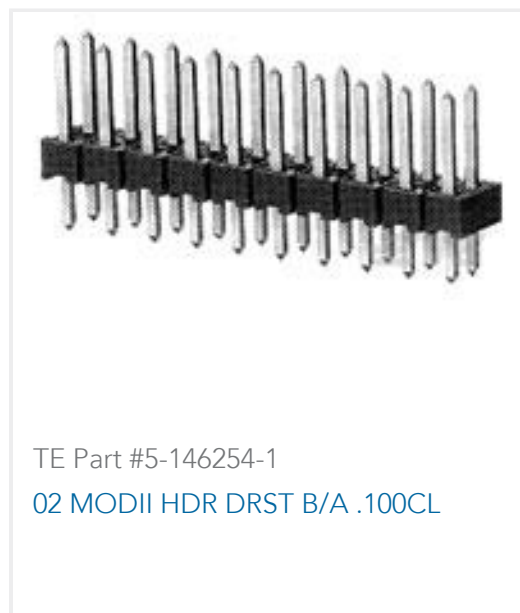

TE Part #5-146254-1  
02 MODII HDR DRST B/A .100CL



TE Part #34067  
PG BUTT SPLC 22-16COMM22-18MIL



TE Part #2213469-1  
GASKET, PHOTOCELL RECEPTACLE



TE Part #4-1393211-6  
T92P11A22-277



TE Part #1775690-2  
Std USB Type A, VT, T/H, 2.5A



TE Part #4-1437624-6  
PKES120B1/4=KNOB PLSTC FLUTED



TE Part #2213362-2  
Rcpt Assy,Dimmable Photocontrol,  
150C,3/4



TE Part #Y12345-000  
ALR-SC-10A



## Documents

### Product Drawings

[Assembly, Receptacle, 3-Position](#)

English

---

### CAD Files

Customer View Model

[ENG\\_CVM\\_CVM\\_2106136-3\\_A1.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2106136-3\\_A1.3d\\_stp.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2106136-3\\_A1.2d\\_dxf.zip](#)

English

[3D PDF](#)

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

---

### Datasheets & Catalog Pages

[SLIMSEAL\\_SSL\\_CONNECOTS](#)

English

---

### Product Specifications

[Application Specification](#)

English

---

### Agency Approvals

[UL Report](#)

English