

# Sortiment Nr. 725922

## SUPER CHAMP II

PN 169060-8



Farbcodierung/Color Coding

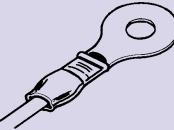
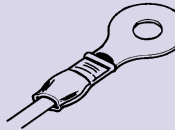

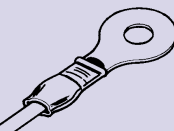
Rot/Red: 0,4 – 1,0 mm<sup>2</sup> (AWG 22-16)  
 Blau/Blue: 1,1 – 2,6 mm<sup>2</sup> (AWG 16-14)  
 Gelb/Yellow: 2,7 – 6,6 mm<sup>2</sup> (AWG 12-10)

# tyco

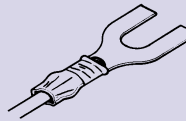
## Electronics

Tyco Electronics AMP GmbH  
 AMPèrestrasse 7-11  
 63225 Langen/Germany  
 Telefon: +49-61 03/709-0  
 Fax: +49-61 03/709-1223  
[www.tycoelectronics.com](http://www.tycoelectronics.com)

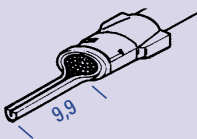
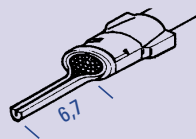
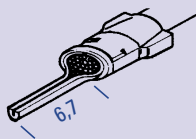
### Ringzunge für Bolzen/Ring Tongue for Bolts

M10	M8	M5	M5
DIN-Ø 4–6 mm <sup>2</sup> (AWG 12–10) PN 160124 	DIN-Ø 4–6 mm <sup>2</sup> (AWG 12–10) PN 160296 	DIN-Ø 1,5–2,5 mm <sup>2</sup> (AWG 16–14) PN 130102 	DIN-Ø 0,5–1,0 mm <sup>2</sup> (AWG 22–16) PN 130014 

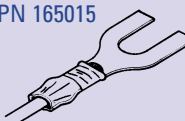
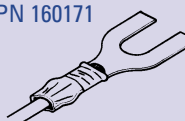
### Gabel für Bolzen Spades for Bolts M5

DIN-Ø 4–6 mm <sup>2</sup> (AWG 12–10) PN 165017 
---

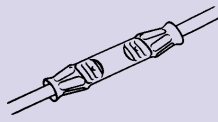
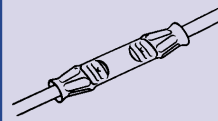
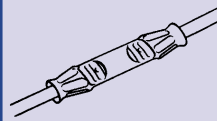
### Stift/Wire Pin

DIN-Ø 4–6 mm <sup>2</sup> (AWG 12–10) PN 165085 	DIN-Ø 1,5–2,5 mm <sup>2</sup> (AWG 16–14) PN 165075-1 	DIN-Ø 0,5–1,0 mm <sup>2</sup> (AWG 22–16) PN 165143 
--	--	--

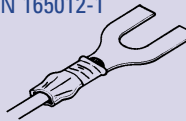

### Gabel für Bolzen Spades for Bolts M4 M5

DIN-Ø 4–6 mm <sup>2</sup> (AWG 12–10) PN 165015 	DIN-Ø 1,5–2,5 mm <sup>2</sup> (AWG 16–14) PN 160171 
---	--

 
 
### Stossverbinder/Butt Splices

DIN-Ø 4–6 mm <sup>2</sup> (AWG 12–10) PN 34072 	DIN-Ø 1,5–2,5 mm <sup>2</sup> (AWG 16–14) PN 34071 	DIN-Ø 0,5–1,0 mm <sup>2</sup> (AWG 22–16) PN 34070 
--	--	--

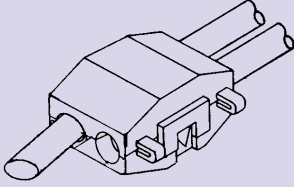
### Gabel für Bolzen Spades for Bolts M4 M2,6

DIN-Ø 1,5–2,5 mm <sup>2</sup> (AWG 16–14) PN 165012-1 	DIN-Ø 0,5–1,0 mm <sup>2</sup> (AWG 22–16) PN 165004 
--	---

### FASTON Steckhülse FASTON Receptacle 6,3x0,8 4,8x0,5

DIN-Ø 1,5–2,5 mm <sup>2</sup> (AWG 16–14) PN 9-160313-2 	DIN-Ø 0,5–1,0 mm <sup>2</sup> (AWG 22–16) PN 9-160481-1 
--	--

### ELECTRO-TAP

DIN-Ø 1,0-2,5 mm <sup>2</sup> PN 735398 
---

Austria – Vienna  
 Phone: +43-190-560-0  
 Fax: +43-190-560-1333

France – Cergy-Pontoise Cedex  
 Phone: +33-1-3420-8888  
 Fax: +33-1-3420-8600

Germany – Bensheim  
 Phone: +49-6251-133-0  
 Fax: +49-6251-133-1600

Great Britain – Stanmore Middlesex  
 Phone: +44-181-954-2356  
 Fax: +44-181-954-6234

Nordic Area – Upplands Väsby  
 Phone: +46-8-50-72-50-00  
 Fax: +46-8-50-72-50-01

Russia – St. Petersburg  
 Phone: +7-812-325-30-83  
 Fax: +7-812-325-32-88

Benelux – 's-Hertogenbosch  
 Phone: +31-73-6246-246  
 Fax: +31-73-6212-365

France – Tyco Electronics Export, St Ouen L'Aumone  
 Phone: +33-1-3440-7200  
 Fax: +33-1-3440-7220/7230

Langen  
 Phone: +49-6103-709-0  
 Fax: +49-6103-709-1223

Hungary – Budapest  
 Phone: +36-1-289-1000  
 Fax: +36-1-289-1010

Poland – Warsaw  
 Phone: +48-22-5490-888  
 Fax: +48-22-5490-880

Spain – Barcelona  
 Phone: +34-93-291-0330  
 Fax: +34-93-201-7879

Czech Republic – Kurim  
 Phone: +420-5-41-162-111  
 Fax: +420-5-41-162-223

HTS Division – Neunkirchen  
 Phone: +49-2247-305-0  
 Fax: +49-2247-305-122

Italy – Collegno (Torino)  
 Phone: +39-011-4012-111  
 Fax: +39-011-4031-116

Russia – Moscow  
 Phone: +7-095-926-55-06...09  
 Fax: +7-095-926-55-05

Switzerland – Steinach  
 Phone: +41-71-447-0447  
 Fax: +41-71-447-0444