


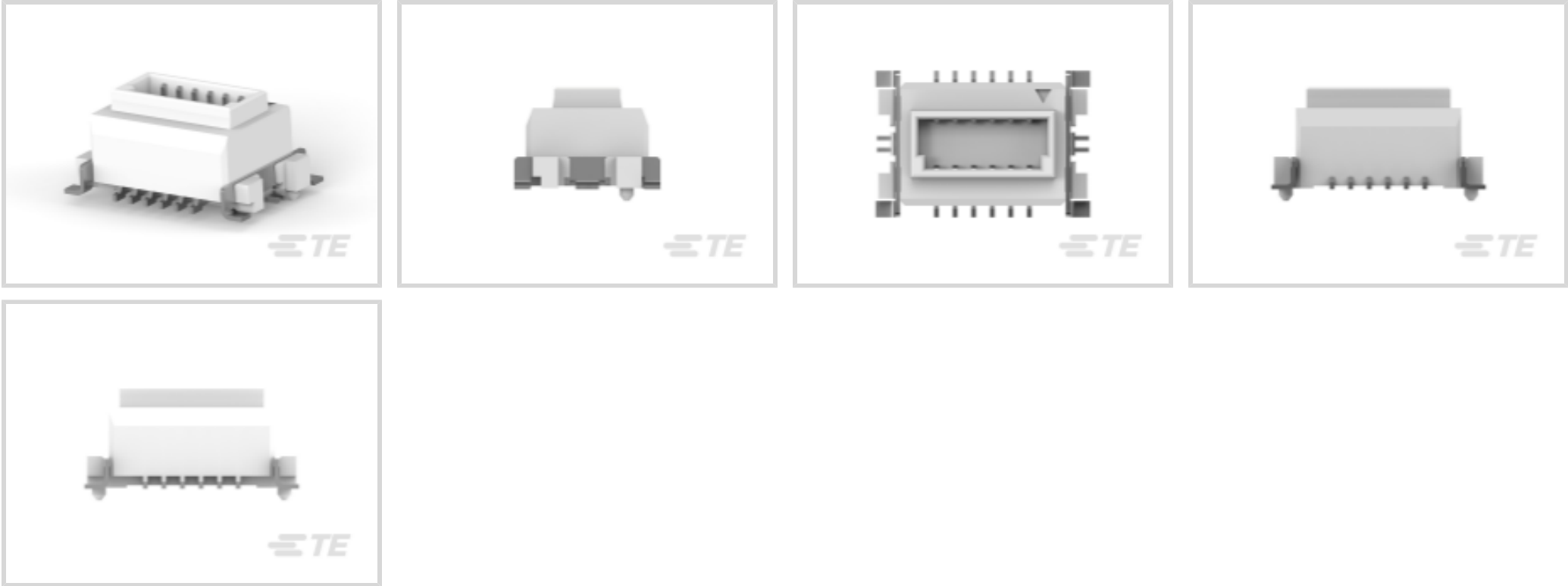

Product Compliance

For compliance documentation, visit the product page on TE.com>

|                                               |                                                                                                                                |
|-----------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                      |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                      |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                        |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JAN 2025 (247)<br>Candidate List Declared Against: JUNE 2024 (241)<br>Does not contain REACH SVHC |
| Halogen Content                               | Not Low Halogen - contains Br or Cl > 900 ppm.                                                                                 |
| Solder Process Capability                     | Reflow solder capable to 245°C                                                                                                 |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought







TE Part #5-103911-3  
60 SYSTEM 50 RCPT ASSY DRR A



TE Part #5-104076-2  
60 SYS50 HDR DRST SHRD W/SL SN

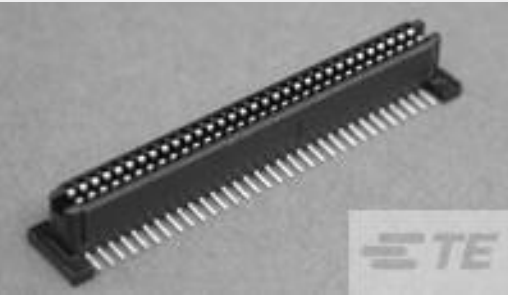


TE Part #5146893-2  
1FHR,84,30A/S,S,C,S08,09,10

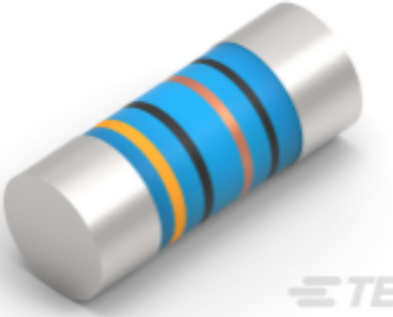

TE Part #2176314-4  
MELF SMA\_A 180R 0.1% 15PPM 0102 0.3W




TE Part #3-1415020-1  
PT570N20

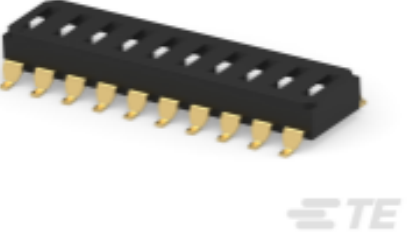


TE Part #3-2319848-1  
END STACK DIP 10P G RECESS SEAL TUBE



TE Part #1-928836-2  
MOD2 PIN WITH A-PIN L/P

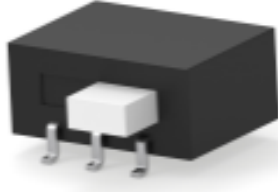

TE Part #1-1437581-1  
ASE22RL=AUTOSLIDE DP

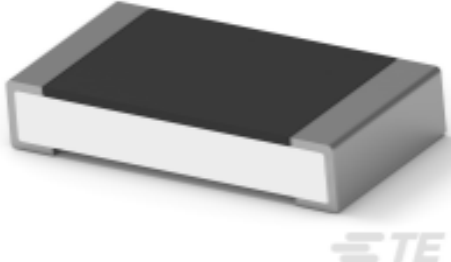

TE Part #4-2176391-7  
RQ 1206 37K4 0.1% 10PPM 5K RL



TE Part #7-2176246-6  
CRGS2512 5% 1M8

Documents

Product Drawings  
0.8FS CAP EMBOSS W BOSS 5H 12POS.  
English

CAD Files  
3D PDF  
English  
Customer View Model  
ENG\_CVM\_1-6376038-2\_O.2d\_dxf.zip  
English  
Customer View Model  
ENG\_CVM\_1-6376038-2\_O.3d\_igs.zip  
English  
Customer View Model  
ENG\_CVM\_1-6376038-2\_O.3d\_stp.zip  
English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Datasheets & Catalog Pages



Fine Pitch Stacking Connector - 0.8mm Fine Stack and Fine Mate Connectors

English

Product Specifications

0.8mm Pitch Fine Stack Connector

Japanese

Product Specification

Japanese

Instruction Sheets

Instruction Sheet (non U.S.)

English

0.8MM F-S CONNECTOR(H 3.0MM) (BOARD TO BOARD SMT TYPE) HANDLING AND OPERATION INSTRUCTION SHEET

English