


Rexel Optimum AutoFeed+ 300M Automatic Micro Cut Paper Shredder

The Optimum AutoFeed+ 300M micro cut shredder automatically shreds up to 300x A4 sheets of paper (80gsm) at a time, into P-5 (2x15mm) micro cut pieces. This auto feed shredder machine is a sophisticated office shredder, featuring a 60L pull out bin. No need to manually feed paper, or remove staples and paper clips first, this automatic paper shredder will do all the work for you.

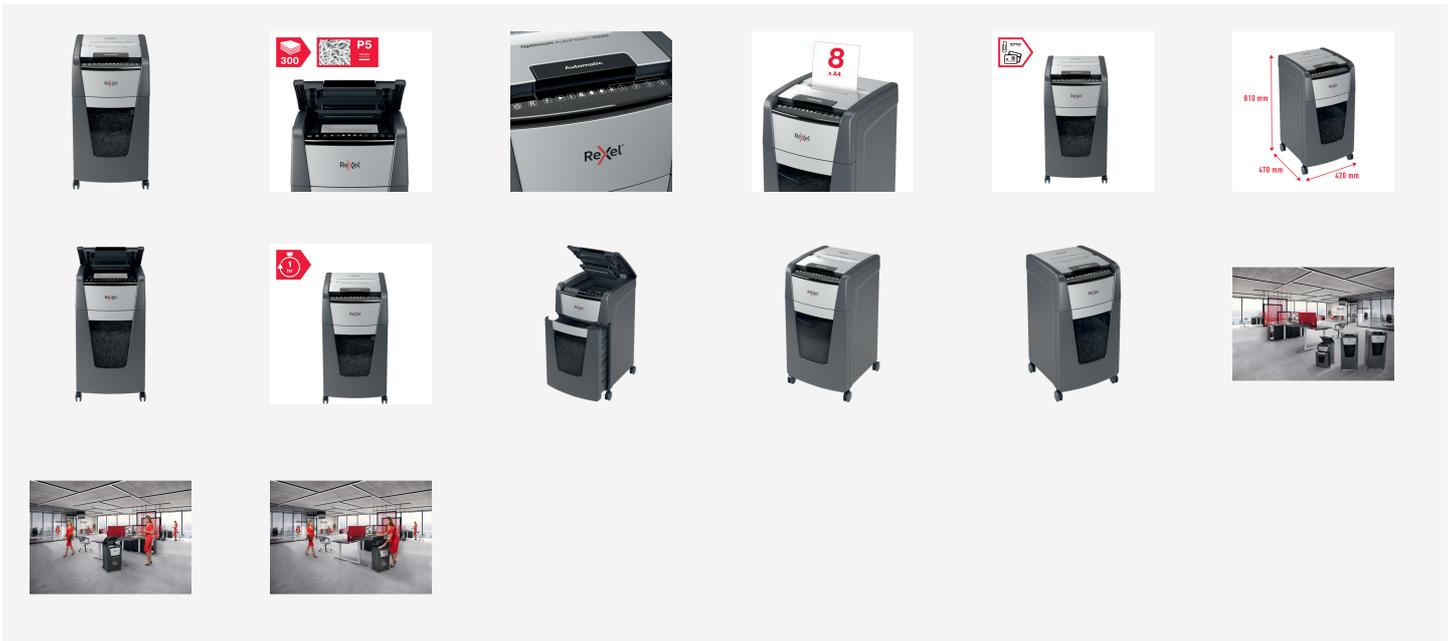

Attributes

- Auto feed up to 300 sheets of A4 paper (80gsm) at a time. Manual slot for up to 8 sheets.
- P-5 micro cut (2x15mm)
- 60L capacity pull out bin. Castor wheels for ease of movement around the workplace.
- Anti-jam technology
- Shreds credit cards, staples and paper clips.
- 60 minutes continuous run time with fan cooling. Sleep mode activates after 3 minutes of non use.
- Touch control panel with pin code lock for ultimate confidence and security.
- 55 dBA ultra-quiet noise level
- Infra red bin full sensor
- 2 year warranty, 2 year cutter warranty



Specifications

Number	2020300M
Colour	Black
Dimensions (W x H x D)	415 x 806 x 465 mm
Cut Type	Micro cut
Maximum Slot Entry Width (mm)	230
Run Time From Cold (min)	60
Shredded Particle Width mm	2x15
Security Level	P-5
Cutting Capacity sheets (70gsm paper)	330
Cutting Capacity sheets (80gsm paper)	300
Container/collection volume in l	60
Shreds	Paper, Credit cards, Paper clips & Staples
Power Consumption (W)	400
Noise Level (dBA)	55
Period of Warranty (Years)	2
*Location	Office
*Number Of Users	5-10
Weight	23000 g
Pallet quantity	0
EAN code	5028252606288