

## Datasheet

# RS Pro Steel Galvanised Adaptable Box, 12 Knockouts 100mm x 100 mm x 50mm 20mm Knockout Size

RS Stock No: **563-905**



## Product Details

RS Pro adaptable box measures 100 x 100 x 50 mm and has galvanised steel construction. It includes 12 knockouts with 20 mm size. The lids are secured by M5 x 8 mm mushroom-head screws.

## Features and Benefits

- 12 knockouts
- 20 mm size
- Galvanised steel



**Specifications:**

Depth	50 mm
Finish	Galvanised
Height	100 mm
Knockout Size	20 mm
Length	100 mm
Material	Steel
Number of Knockouts	12
Width	100 mm
Standards Met	BS4568

Barton Adaptable Boxes are manufactured from steel and are available with plain sides or knock-outs. The standard finishes are Black Enamel and Hot Dipped Galvanised. (Pre-galvanized lids).


Where boxes are supplied with knock-outs the number and size are as follows:

Width of side	Number of K.O.s in each side	Size of K.O.
3"	2	20mm
4"	3	20mm
6"	4	20mm
9"	6	20mm
12"	6	20mm

Flanged lids are fitted as standard to all boxes and are secured by M5 x 8mm mushroom head screws.

The complete range is manufactured in accordance with BS 4568 Part 2.


A range of Pre-Galvanized Adaptable Boxes are also available on request.

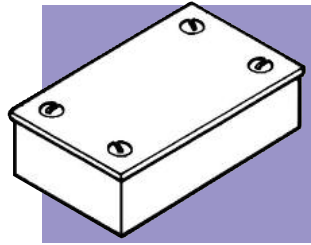

**Adaptable Boxes, Plain**

**R261**

Size	mm		Pack Qty
	mm	Inches	
75 x 75 x 37.5	3 x 3 x 1½	10	
75 x 75 x 50	3 x 3 x 2	10	
75 x 75 x 75	3 x 3 x 3	6	
100 x 75 x 37.5	4 x 3 x 1½	10	
100 x 75 x 50	4 x 3 x 2	10	
100 x 100 x 37.5	4 x 4 x 1½	10	
100 x 100 x 50	4 x 4 x 2	10	
100 x 100 x 75	4 x 4 x 3	6	
150 x 75 x 37.5	6 x 3 x 1½	6	
150 x 75 x 50	6 x 3 x 2	6	
150 x 75 x 75	6 x 3 x 3	6	
150 x 100 x 37.5	6 x 4 x 1½	6	
150 x 100 x 50	6 x 4 x 2	6	
150 x 100 x 75	6 x 4 x 3	6	
150 x 50 x 37.5	6 x 6 x 1½	6	
150 x 50 x 50	6 x 6 x 2	6	
150 x 50 x 75	6 x 6 x 3	4	
150 x 50 x 100	6 x 6 x 4	2	
225 x 75 x 37.5	9 x 3 x 1½	6	
225 x 75 x 50	9 x 3 x 2	6	
225 x 75 x 75	9 x 3 x 3	6	
225 x 150 x 37.5	9 x 6 x 1½	4	
225 x 150 x 50	9 x 6 x 2	4	
225 x 150 x 75	9 x 6 x 3	4	
225 x 150 x 100	9 x 6 x 4	2	
225 x 225 x 50	9 x 9 x 2	2	
225 x 225 x 75	9 x 9 x 3	2	
225 x 225 x 100	9 x 9 x 4	1	
300 x 150 x 50	12 x 6 x 2	2	
300 x 150 x 75	12 x 6 x 3	2	
300 x 150 x 100	12 x 6 x 4	2	
300 x 225 x 50	12 x 9 x 2	2	
300 x 225 x 75	12 x 9 x 3	1	
300 x 225 x 100	12 x 9 x 4	1	
300 x 300 x 50	12 x 12 x 2	2	
300 x 300 x 75	12 x 12 x 3	1	
300 x 300 x 100	12 x 12 x 4	1	

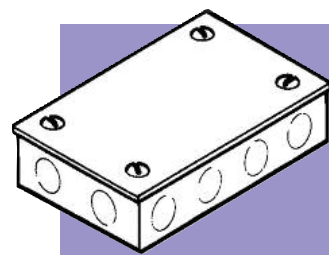

**Adaptable Boxes, with knock-outs**

**R262**