


PXP6012/03P/CR Datasheet

Product Name // **Front Panel Mount Connector PXP6012**
Series 3 Contact Plug Crimp/Solder Termination (contacts available separately) Plastic Body

 [View Product Page](#)

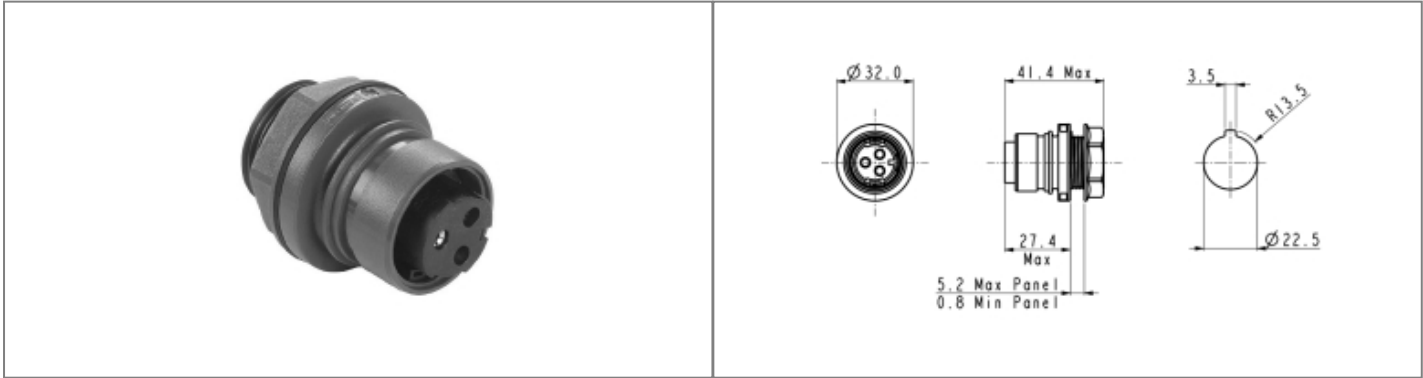

// Product Description:

- Front Panel Mount Connectors
 - Water and dustproof to IP66, IP68, IP69K when mated with compatible connector
 - 30 degree push twist locking, tamperproof lock prevents accidental un-mating
 - Plug
 - 3 Contacts
- Crimp/solder termination with contacts and fitting tool available separately
 - Plastic Body
 - PXP6083 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with PXP6010 Series Flex Connectors

// General Information:

Product Display Title:	Front Panel Mount Connectors
Product Family:	Circular Power Connectors
Product Series:	6000 Series Buccaneer
Approvals:	cUL, UL, VDE
Body Colour:	Grey
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Plug Contact
Coupling Type:	Push-Twist
Current Max:	16A, 11A
Diameter Over Coupling Ring Mm:	32mm
Flamability Rating:	UL94V-0
Function:	Front Panel Mount Connector
Insulation Resistance:	>10 ⁶ MΩ @500V DC
Ip Rating:	IP66, IP68, IP69K
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	14AWG
Max Contact Accomodation Mm2:	0.52mm2
Min Contact Accomodation Mm2:	0.52mm2
Max Operating Temperature:	+120°C
Min Operating Temperature:	-40°C
Max Panel Thickness:	5.2mm
Min Panel Thickness:	0.8mm
Number Of Contacts:	3 Contacts
Panel Cut Out:	22.50xR13.5-3.5mm
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	EN60068-2-52 Test Kb Salt Mist (Cyclic) Marine Severity Level 1
Thread Size:	M22x1.5-6g
Voltage Max:	277V

// Product PDF Links

-  6000 Series power connectors...
-  6000 Series metal body power...

// Product 3D CAD Model Links

-  PXP6012/03P/CR3D CAD Model



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)