

## D-SERIES DRM SCM 4CO ECO

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com



Accessories for D-SERIES relays include:

- Relay bases
- LED / Protective modules
- Metal retaining clips

### General ordering data

Type	SCM 4CO ECO
Order No.	<a href="#">7760056264</a>
Version	D-SERIES DRM, Relay base, Continuous current: 6 A, Screw connection
GTIN (EAN)	6944 169662973
Qty.	10 pc(s).

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technical data****Dimensions and weights**

Width	27 mm	Height	75 mm
Depth	61 mm	Net weight	68 g

**Temperatures**

Humidity	35...85 % rel. humidity, no condensation	Operating temperature	-40 °C...70 °C
Storage temperature	-40 °C...70 °C		

**Output**

Max. switching voltage, AC	300 V	Continuous current	6 A
----------------------------	-------	--------------------	-----

**Insulation coordination**

Creepage and clearance distance input – output	≥ 5.5 mm	Dielectric strength input – output	4 kV <sub>eff</sub> / 1 min
Dielectric strength of neighbouring contacts	4 kV <sub>eff</sub> / 1 min	Impulse withstand voltage	4.8 kV (1.2/50 μs)
Protection degree	IP 20	Pollution severity	2
Surge voltage category	III		

**Further details of approvals / standards**

Certificate No. (cURus)	E312083
-------------------------	---------

**Connection data**

Wire connection method	Screw connection	Stripping length, rated connection	7 mm
Tightening torque, min.	0.5 Nm	Tightening torque, max.	0.7 Nm
Clamping range, rated connection, min.	0.5 mm <sup>2</sup>	Clamping range, rated connection, max.	2.5 mm <sup>2</sup>
Wire cross-section, solid, min.	0.5 mm <sup>2</sup>	Wire cross-section, solid, max.	2.5 mm <sup>2</sup>
Wire connection cross-section, finely stranded, min.	0.5 mm <sup>2</sup>	Wire connection cross section, finely stranded, max.	2.5 mm <sup>2</sup>
Cross-section for connected conductor, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, min.	0.5 mm <sup>2</sup>	Wire connection cross-section, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, max.	2.5 mm <sup>2</sup>
Conductor cross-section, flexible, AEH (DIN 46228-1), min.	0.5 mm <sup>2</sup>	Conductor cross-section, flexible, AEH (DIN 46228-1), max.	2.5 mm <sup>2</sup>
Wire connection cross section, finely stranded, two clampable wires, min.	0.5 mm <sup>2</sup>	Wire cross-section, finely stranded, two clampable wires, max.	1 mm <sup>2</sup>
Blade size	size PH1		

**Classifications**

ETIM 3.0	EC001456	ETIM 5.0	EC001456
ETIM 6.0	EC001456	eClass 6.2	27-37-16-03
eClass 7.1	27-37-16-03	eClass 8.1	27-37-16-03
eClass 9.0	27-37-16-03		

**Data sheet**

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Technical data**

**Approvals**

Approvals




**Downloads**

Declaration of Conformity [K5500215.pdf](#)

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

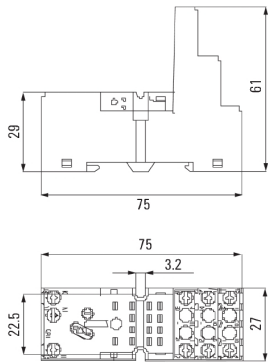

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)****with LED**

Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM570110L	<a href="#">7760056090</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 110 V DC, Continuous current: 5 A, Plug-in connection	4032248855742	20 pc(s).
DRM570012L	<a href="#">7760056087</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 12 V DC, Continuous current: 5 A, Plug-in connection	4032248855773	20 pc(s).
DRM570615L	<a href="#">7760056094</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 115 V AC, Continuous current: 5 A, Plug-in connection	4032248855704	20 pc(s).
DRM570024L	<a href="#">7760056088</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248855766	20 pc(s).
DRM570220L	<a href="#">7760056091</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 220 V DC, Continuous current: 5 A, Plug-in connection	4032248855735	20 pc(s).
DRM570548L	<a href="#">7760056093</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V AC, Continuous current: 5 A, Plug-in connection	4032248855711	20 pc(s).
DRM570524L	<a href="#">7760056092</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V	4032248855728	20 pc(s).

Creation date August 19, 2015 3:35:56 PM CEST

Catalogue status 31.07.2015 / We reserve the right to make technical changes.

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)**

	AC, Continuous current: 5 A, Plug-in connection
DRM570730L <a href="#">7760056095</a>	D-SERIES DRM, Relais, No. 4032248855698 20 pc(s). of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 230 V AC, Continuous current: 5 A, Plug-in connection
DRM570048L <a href="#">7760056099</a>	D-SERIES DRM, Relais, No. 4032248855759 20 pc(s). of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V DC, Continuous current: 5 A, Plug-in connection

**with LED and test button**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM570012L <a href="#">7760056096</a>		D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 12 V DC, Continuous current: 5 A, Plug-in connection	4032248855681 20 pc(s).	
DRM570024L <a href="#">7760056097</a>		D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248855674 20 pc(s).	
DRM570110L <a href="#">7760056099</a>		D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 110 V DC, Continuous current: 5 A, Plug-in connection	4032248855650 20 pc(s).	
DRM570048L <a href="#">7760056098</a>		D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated	4032248855667 20 pc(s).	

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Mating connector (fully pluggable)**

	control voltage: 48 V DC, Continuous current: 5 A, Plug-in connection
DRM570548L7760056102	D-SERIES DRM, Relais, No. 4032248855629 20 pc(s). of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 48 V AC, Continuous current: 5 A, Plug-in connection
DRM570730L7760056104	D-SERIES DRM, Relais, No. 4032248855605 20 pc(s). of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 230 V AC, Continuous current: 5 A, Plug-in connection
DRM570220L7760056100	D-SERIES DRM, Relais, No. 4032248855643 20 pc(s). of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 220 V DC, Continuous current: 5 A, Plug-in connection
DRM570524L7760056101	D-SERIES DRM, Relais, No. 4032248855636 20 pc(s). of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 24 V AC, Continuous current: 5 A, Plug-in connection
DRM570615L7760056103	D-SERIES DRM, Relais, No. 4032248855612 20 pc(s). of contacts: 4, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 115 V AC, Continuous current: 5 A, Plug-in connection

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)****standard relay**

Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM570220	<a href="#">7760056082</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 220 V DC, Continuous current: 5 A, Plug-in connection	4032248855162	20 pc(s).
DRM570012	<a href="#">7760056078</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 12 V DC, Continuous current: 5 A, Plug-in connection	4032248855117	20 pc(s).
DRM570524	<a href="#">7760056083</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V AC, Continuous current: 5 A, Plug-in connection	4032248855186	20 pc(s).
DRM570024	<a href="#">7760056079</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248855124	20 pc(s).
DRM570548	<a href="#">7760056084</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V AC, Continuous current: 5 A, Plug-in connection	4032248855193	20 pc(s).
DRM570730	<a href="#">7760056086</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 230 V AC, Continuous current: 5 A, Plug-in connection	4032248855254	20 pc(s).
DRM570615	<a href="#">7760056085</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 115	4032248855230	20 pc(s).

Creation date August 19, 2015 3:35:56 PM CEST

Catalogue status 31.07.2015 / We reserve the right to make technical changes.



**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)**

	V AC, Continuous current: 5 A, Plug-in connection
DRM570048 <a href="#">7760056080</a>	D-SERIES DRM, Relais, No. 4032248855148 20 pc(s). of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V DC, Continuous current: 5 A, Plug-in connection
DRM570110 <a href="#">7760056081</a>	D-SERIES DRM, Relais, No. 4032248855131 20 pc(s). of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 110 V DC, Continuous current: 5 A, Plug-in connection

**with LED and test button**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green)  
and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM270024L	<a href="#">7760056185</a>	D-SERIES DRM, Relais, No.	4032248922246 20 pc(s).	
Au		of contacts: 2, CO contact with test button, AgNi 5µm Au, Rated control voltage: 24 V DC, Continuous current: 10 A, Plug-in connection		
DRM270730L	<a href="#">7760056186</a>	D-SERIES DRM, Relais, No.	4032248922253 20 pc(s).	
Au		of contacts: 2, CO contact with test button, AgNi 5µm Au, Rated control voltage: 230 V AC, Continuous current: 10 A, Plug-in connection		

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)**
**with LED and free-wheel diode**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM270024LD	<a href="#">760056124</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 10 A, Plug-in connection	4032248855544	20 pc(s).
DRM270024LD	<a href="#">760056077</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 10 A, Plug-in connection	4032248855780	20 pc(s).

**with LED**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM570024L	<a href="#">760056187</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 5µm Au, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248922260	20 pc(s).
DRM570730L	<a href="#">760056188</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 5µm Au, Rated control voltage: 230	4032248922277	20 pc(s).

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)**

V AC, Continuous current: 5  
 A, Plug-in connection

**with LED and test button**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM570024L Au	<a href="#">7760056189</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 5µm Au, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248922284	20 pc(s).
DRM570730L Au	<a href="#">7760056190</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 5µm Au, Rated control voltage: 230 V AC, Continuous current: 5 A, Plug-in connection	4032248922291	20 pc(s).
DRM570220L AU	<a href="#">7760056287</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact with test button, AgNi 5µm Au, Rated control voltage: 220 V DC, Continuous current: 5 A, Plug-in connection	6944169722516	20 pc(s).

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)**
**with LED**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM270730L Au	<a href="#">7760056184</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 5µm Au, Rated control voltage: 230 V AC, Continuous current: 10 A, Plug-in connection	4032248922239 20 pc(s).	
DRM270024L Au	<a href="#">7760056183</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 5µm Au, Rated control voltage: 24 V DC, Continuous current: 10 A, Plug-in connection	4032248922222 20 pc(s).	

**standard relay**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM270048	<a href="#">7760056052</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V DC, Continuous current: 10 A, Plug-in connection	4032248856039 20 pc(s).	
DRM270012	<a href="#">7760056050</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 12 V DC, Continuous current: 10 A, Plug-in connection	4032248856053 20 pc(s).	

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Mating connector (fully pluggable)**

DRM270615 <a href="#">7760056057</a>	D-SERIES DRM, Relais, No. 4032248855988 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 115 V AC, Continuous current: 10 A, Plug-in connection
DRM270220 <a href="#">7760056054</a>	D-SERIES DRM, Relais, No. 4032248856015 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 220 V DC, Continuous current: 10 A, Plug-in connection
DRM270524 <a href="#">7760056055</a>	D-SERIES DRM, Relais, No. 4032248856008 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V AC, Continuous current: 10 A, Plug-in connection
DRM270024 <a href="#">7760056051</a>	D-SERIES DRM, Relais, No. 4032248856046 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 10 A, Plug-in connection
DRM270730 <a href="#">7760056058</a>	D-SERIES DRM, Relais, No. 4032248855971 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 230 V AC, Continuous current: 10 A, Plug-in connection
DRM270110 <a href="#">7760056053</a>	D-SERIES DRM, Relais, No. 4032248856022 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 110 V DC, Continuous current: 10 A, Plug-in connection
DRM270548 <a href="#">7760056056</a>	D-SERIES DRM, Relais, No. 4032248855995 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V AC, Continuous current: 10 A, Plug-in connection

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Mating connector (fully pluggable)**
**with LED and free-wheel diode**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM570024LD	<a href="#">760056105</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248855599	20 pc(s).
DRM570024LD	<a href="#">760056123</a>	D-SERIES DRM, Relais, No. of contacts: 4, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 5 A, Plug-in connection	4032248855551	20 pc(s).

**with LED and test button**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM270220LT	<a href="#">760056072</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 220 V DC, Continuous current: 10 A, Plug-in connection	4032248855834	20 pc(s).
DRM270024LT	<a href="#">760056069</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC,	4032248855865	20 pc(s).

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Mating connector (fully pluggable)**

	Continuous current: 10 A, Plug-in connection
DRM270110L <a href="#">T760056071</a>	D-SERIES DRM, Relais, No. 4032248855841 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 110 V DC, Continuous current: 10 A, Plug-in connection
DRM270524L <a href="#">T760056073</a>	D-SERIES DRM, Relais, No. 4032248855827 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 24 V AC, Continuous current: 10 A, Plug-in connection
DRM270730L <a href="#">T760056076</a>	D-SERIES DRM, Relais, No. 4032248855797 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 230 V AC, Continuous current: 10 A, Plug-in connection
DRM270048L <a href="#">T760056070</a>	D-SERIES DRM, Relais, No. 4032248855858 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 48 V DC, Continuous current: 10 A, Plug-in connection
DRM270615L <a href="#">T760056075</a>	D-SERIES DRM, Relais, No. 4032248855803 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 115 V AC, Continuous current: 10 A, Plug-in connection
DRM270012L <a href="#">T760056068</a>	D-SERIES DRM, Relais, No. 4032248855872 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 12 V DC, Continuous current: 10 A, Plug-in connection
DRM270548L <a href="#">T760056074</a>	D-SERIES DRM, Relais, No. 4032248855810 20 pc(s). of contacts: 2, CO contact with test button, AgNi 0.15 gold flashed, Rated control voltage: 48 V AC, Continuous current: 10 A, Plug-in connection

**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Mating connector (fully pluggable)**
**with LED**


Relay from the D-SERIES DRM.

- 2 or 4 CO contacts
- Compact design
- Wide range of coil voltages
- Optional test button (AC red, DC blue)
- Optional with integrated status display (AC red, DC green) and/or free-wheel diode

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DRM270024L	<a href="#">7760056060</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V DC, Continuous current: 10 A, Plug-in connection	4032248855957	20 pc(s).
DRM270125L	<a href="#">7760056115</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 125 V DC, Continuous current: 10 A, Plug-in connection	4032248883110	20 pc(s).
DRM270110L	<a href="#">7760056062</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 110 V DC, Continuous current: 10 A, Plug-in connection	4032248855933	20 pc(s).
DRM270012L	<a href="#">7760056059</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 12 V DC, Continuous current: 10 A, Plug-in connection	4032248855964	20 pc(s).
DRM270524L	<a href="#">7760056064</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 24 V AC, Continuous current: 10 A, Plug-in connection	4032248855919	20 pc(s).
DRM270220L	<a href="#">7760056063</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 220 V DC, Continuous current: 10 A, Plug-in connection	4032248855926	20 pc(s).
DRM270615L	<a href="#">7760056066</a>	D-SERIES DRM, Relais, No. of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 115	4032248855896	20 pc(s).

Creation date August 19, 2015 3:35:56 PM CEST



**D-SERIES DRM  
SCM 4CO ECO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Mating connector (fully pluggable)**

	V AC, Continuous current: 10 A, Plug-in connection
DRM270048L <a href="#">7760056061</a>	D-SERIES DRM, Relais, No. 4032248855940 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V DC, Continuous current: 10 A, Plug-in connection
DRM270548L <a href="#">7760056065</a>	D-SERIES DRM, Relais, No. 4032248855902 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 48 V AC, Continuous current: 10 A, Plug-in connection
DRM270730L <a href="#">7760056067</a>	D-SERIES DRM, Relais, No. 4032248855889 20 pc(s). of contacts: 2, CO contact, AgNi 0.15 gold flashed, Rated control voltage: 230 V AC, Continuous current: 10 A, Plug-in connection


# Addresses worldwide


Let's connect.


- AE United Arab Emirates**  
Weidmüller Middle East FZE  
Warehouse Q3-79  
SAIF-Zone  
P.O. BOX 8591  
Sharjah  
Telephone number +971 65572723  
Fax number +971 65572724  
wme.info@weidmueller.com
- AO Angola**  
Please contact  
Phambili Interface  
South Africa
- AR Argentina**  
CPI SA  
Bauness 2660  
C1431DOF Buenos Aires  
Telephone number +54 11 4523 8008  
Fax number +54 11 4522 0546  
info@cpi.com.ar  
www.cpi.com.ar
- AT Austria**  
Weidmüller GmbH  
IZ NOE Süd Straße 2b, Obj  
M 59  
2355 Wiener Neudorf  
Telephone number +43 2236 67080  
Fax number +43 2236 6708-899  
office.at@weidmueller.com  
www.weidmueller.com
- AU Australia**  
Weidmüller Pty. Ltd.  
PO BOX 6944  
Huntingwood 2148  
Huntingwood Drive 43  
Huntingwood NSW 2148  
Telephone number +61 2 9671 9999  
Fax number +61 2 9671 9911  
info@weidmuller.com.au  
www.weidmuller.com.au
- AZ Azerbaijan**  
Representative Office  
Weidmüller Interface  
Demirchi Tower, 4th floor  
37, Khojali ave.  
AZ 1025 Baku  
Telephone number +994 12 488 80 36  
Fax number +994 12 488 80 37  
rashad.mahmudov@weidmueller.com
- BA Bosnia and Herzegovina**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia  
  
or  
  
BIG electric d.o.o  
Mladena Stojanovića 117A  
78000 Banja Luka  
Telephone number +387 51926277  
Fax number +387 51926277  
bigelectric@blic.net  
www.bigelectric.ba
- BE Belgium**  
Weidmüller Benelux B. V.  
Mechelsesteenweg 519 bus  
6 an 7  
1930 Nossegem  
Telephone number +32 2 752 40 70  
Fax number +32 2 751 36 06  
info@weidmueller.be  
www.weidmueller.be
- BG Bulgaria**  
Weid-Bul EOOD  
Bul. "Kliment Ohridski" 13  
1756 Sofia  
Telephone number +359 2 963 2560  
Fax number +359 2 963 1098  
sofia@weidbul.com  
www.weidbul.com
- BH Bahrain**  
Khayber Trading Company  
P.O Box 1976  
Manama  
Telephone number +973 720747  
Fax number +973 720331  
khayber@batelco.com.bh
- BR Brazil**  
Weidmüller Conexel do Brasil  
Conexões Elétricas Ltda.  
Av. Presidente Juscelino, 642  
- Piraporinha  
Diadema, São Paulo  
09950-370  
Telephone number +55 (11) 4366-9600  
Fax number +55 (11) 4362-1677  
vendas@weidmueller.com.br  
www.weidmueller.com.br
- BW Botswana**  
Please contact  
Phambili Interface  
South Africa
- BY Belarus**  
TECHNIKON Ltd.  
Nezavisimosti pr. 177-9  
220125 Minsk  
Telephone number +375 17 393-11-77  
Fax number +375 17 3930080  
wm@technikon.by
- CA Canada**  
W Interconnections Canada  
Inc.  
10 Spy Court  
Markham Ontario L3R 5H6  
Telephone number +1 (905) 475-1507 Ext. 9836  
Fax number +1 (905) 475-2798  
support@weidmuller.ca  
www.weidmuller.ca
- CG Congo**  
Please contact  
Phambili Interface  
South Africa
- CH Switzerland**  
Weidmüller Schweiz AG  
Rundbuckstraße 2  
8212 Neuhausen am  
Rheinfall SH  
Telephone number +41 52 674 07 07  
Fax number +41 52 674 07 08  
info@weidmueller.ch  
www.weidmueller.ch
- CL Chile**  
ATS - INTECH  
María Luisa Santander 0475  
Santiago  
Providencia 7500859  
Telephone number +56 2 341 1271  
Fax number +56 2 341 1275  
felipe@atsintech.com  
www.atsintech.com  
  
CPI CHILE LTDA  
Av. Presidente Frei Montalva  
6001, 47 complejo el cortijo  
Santiago - Conchalí  
Telephone number +562 963 8440  
Fax number +562 963 8440  
cpi@cpichile.cl  
www.cpi Chile.cl
- CN China**  
Weidmüller Interface  
(Shanghai) Co. Ltd.  
100 Yutong Road  
25 F, BM Intercontinental  
Business Center  
200070 Shanghai  
Telephone number +86 21-22195008  
Fax number +86 512-68417505  
customer.hotline@weidmueller.com.cn  
www.cnweidmuller.com
- CO Colombia**  
Automatización Avanzada  
S. A.  
Carrera 97 No., 24 c - 23  
Bodega 4  
110911 Bogotá-D.C.  
Telephone number +57 (1) 547-8510  
Fax number +57 (1) 422-3044  
comercial@automatizacionavanzada.com  
www.automatizacionavanzada.com
- CR Costa Rica**  
ELVATRON S. A.  
la Uruca 400 Norte Banco  
Costa Rica  
San Jose Costa Rica  
Telephone number +506 2961-060  
Fax number +506 5200-609  
dirk.haase@elvatron.com  
www.elvatron.com
- CZ Czech Republic**  
Weidmüller s.r.o.  
Lomnického 5/1705  
140 00 Praha 4  
Telephone number +420 244 001 400  
Fax number +420 244 001 499  
office@weidmueller.cz  
www.weidmueller.cz
- DE Germany**  
Weidmüller GmbH & Co. KG  
Ohmstraße 9  
32758 Detmold  
Postfach 30 54  
32720 Detmold  
Telephone number +49 5231 1428-0  
Fax number +49 5231 14-292083  
weidmuller@weidmueller.de  
www.weidmueller.de
- DK Denmark**  
Weidmüller Danmark  
Vallensbækvej 18A  
2605 Brøndby  
Telephone number +45 27747800  
kundeservice@weidmuller.dk  
www.weidmuller.dk
- DZ Algeria**  
SARL INTER ELECTRIC  
1a Angles des Rues Okba Ibn  
Nafaa et Hassi Beida  
2300 Annaba  
Telephone number  
Fax number  
contact@inter-electric.com
- EC Ecuador**  
Elsystec S. A., Electricidad  
Sistemas y Tecnología  
Vasco de Contreras N35-251  
y Manosca  
Quito - Pichincha  
Telephone number +593 22456510  
Fax number +593 22456755  
Elsystec@uio.satnet.net
- EE Estonia**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Latvia  
  
or  
  
Soots Interface OÜ  
Pänu mnt 142  
11317 Tallinn  
Telephone number +372 609 6933  
Fax number  
info@sootsinterface.ee  
www.sootsinterface.ee
- EG Egypt**  
Standard Electric (OMEGA)  
1, Abdelhamid Badawy Street  
Heliopolis  
Cairo  
Telephone number +202 21805111  
Fax number +202 21805600  
stdelec@rite.com
- ES Spain**  
Weidmüller, S. A.  
Narcís Monturiol 11-13, Pol.  
Ind. Sudoeste  
8960 Sant Just  
Desvern - Barcelona  
Telephone number +34 934 803 386  
Fax number +34 933 718 055  
weidmuller@weidmuller.es  
www.weidmuller.es
- FI Finland**  
Weidmüller Suomi,  
Weidmüller Aktiebolagetin  
sivuliike  
Koy Plaza Vivace  
Äyritie 8C  
FI 1510 Vantaa  
Telephone number +358 20 7351300  
Fax number +358 800 114 667  
asiakaspalvelu@weidmuller.fi  
www.weidmuller.fi
- FR France**  
Weidmüller E. U. R. L.  
12, Chaussée Jules César  
BP 263 Osny  
95523 Cergy-Pontoise Cedex  
Telephone number +33 1 34 24 55 00  
Fax number +33 1 34 24 55 01  
mail@weidmuller.fr
- GB Great Britain**  
Weidmüller Ltd.  
Klippon House  
Centurion Court Office Park,  
Meridian East, Meridian  
Business Park  
Leicester  
LE19 1TP  
Telephone number +44 116 282 3470  
Fax number +44 116 289 3582  
marketing@weidmuller.co.uk  
www.weidmuller.co.uk
- GE Georgia**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- GH Ghana**  
Please contact  
Weidmüller Interface GmbH  
& Co. KG  
South Africa
- GR Greece**  
G.A. Solutions  
Ippokratous 11 Metamorfoisi  
144 52 Athen  
Telephone number +30 210 2823233  
Fax number +30 210 2823233  
info@weidmuller.gr  
www.weidmuller.gr
- GT Guatemala**  
Prestelectro, Prestegard  
Electro, S.A.  
Avenida Petapa 44-22,  
Zona 12  
Guatemala City  
Telephone number +502 2442-3346  
Fax number +502 2476-8945  
ventas@prestelectro.com
- HK Hong Kong**  
Weidmüller (Hong Kong)  
Limited Co. Ltd.  
Unit 1617, Metropolis Tower  
No. 10 Metropolis Drive,  
Hung Hom, Kowloon  
Telephone number +852 3154 8088  
Fax number +852 31548099  
Info-hk@weidmueller.com.hk
- HR Croatia**  
ElektroPARTNER d.o.o.  
Slavonska avenija 24/6  
HR-10000 Zagreb  
Telephone number +385 (1) 6184 793  
Fax number +385 (1) 6184 795  
elektropartner@zg.t-com.hr  
www.elektropartner.hr
- HU Hungary**  
Weidmüller Kereskedelmi Kft.  
Budapest  
Gubacsi út 6.  
1097  
Telephone number +36 1 382 7700  
Fax number +36 1 382 7701  
info@weidmueller.hu  
www.weidmueller.hu
- ID Indonesia**  
PT. Nego Electrindo  
Ruko Mega Grosir Cempaka  
Mas Blok I No. 20 – 22  
Jakarta 10640  
Telephone number +62 21 42882255  
Fax number +62 21 42882266  
sales@negoelectrindo.co.id
- IE Ireland**  
Please contact  
Weidmüller Ltd.  
Great Britain
- IL Israel**  
A. U. Shay Ltd.  
23/25, Embarr Street  
49222 Petach-Tikva  
P.O. Box 1 00 49  
49222 Petach-Tikva  
Telephone number +972 3-923-3601  
Fax number +972 3-923-4601  
shay@uriel-shay.com  
www.uriel-shay.com  
  
ATEKA Ltd.  
4, Ha Tavor lane Industrial  
area Segula  
49691 Petach-Tikva  
P.O. Box 4710  
Petach-Tikva  
Telephone number +972 73-200-1311  
Fax number +972 3-924 4245  
marketing@ateka.co.il  
www.ateka.co.il
- IN India**  
Representative Office  
Weidmüller Electronics India  
Pvt. Ltd.  
12th Lane North Avenue, Opp  
Joggers Park,  
Kalyani Nagar, Pune  
411 006  
Telephone number +91 20-41290090  
wmi.pune@weidmueller.in  
www.weidmueller.com
- IS Iceland**  
Samey Automation Center  
Lýngas 13  
210 Garoabaer  
Telephone number +354 510 5200  
Fax number +354 510 5201  
Samey@samey.is  
www.samey.is
- IT Italy**  
Weidmüller S. r.l.  
Via Albert Einstein 4  
20092 Cinisello  
Balsamo Milano  
Telephone number +39 02 660681  
Fax number +39 02 6124945  
weidmuller@weidmuller.it  
www.weidmuller.it
- JM Jamaica**  
Please contact  
W Interconnections Inc.  
United States
- JO Jordan**  
Trans Jordan for Electro  
PO Box 33 06 07  
Amman  
Telephone number +962 6 533 2020  
Fax number +962 6 533 5800  
transjordan@batelco.jo



You can find all Weidmüller addresses and your local contact on the internet at: [www.weidmueller.com/countries](http://www.weidmueller.com/countries)

Sales company 

Representation abroad 

without representation abroad 

Let's connect.

- JP Japan**  
Nihon Weidmüller Co. Ltd.  
Sphere Tower Tennoz 2-2-8  
Higashi-Shinagawa,  
Shinagawa-ku  
Tokyo  
140-0002  
Telephone number +81 3  
6711 5300  
Fax number +81 3 6711  
5333  
weidmullerjapan@weidmuller.  
co.jp  
www.weidmuller.co.jp
- KE Kenya**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.
- KR Korea**  
Weidmüller Korea Co. Ltd.  
9th floor, Wonbang B/D  
Samseong 2-Dong, Gangnam-  
Gu  
Seoul 143-42  
Telephone number +82  
2-516-0003  
Fax number +82 2-516-0090  
info@weidmuller.co.kr  
www.weidmuller.co.kr
- KW Kuwait**  
Kana Controls General Trading  
& Contracting Co. W. L. L.  
Al Rai Industrial Area, Plot  
28-30, St. 31  
13016 Safat  
B.P. 25593  
Telephone number +965  
4741373  
Fax number +965 4741537  
info@kanacontrols.com
- KZ Kazakhstan**  
Please contact  
Weidmüller Group  
Russia
- LB Lebanon**  
Progress Engineering &  
Trading Enterprises  
Al Nahr Street  
Beirut 11-1111  
Telephone number +961 1  
444 664  
Fax number +961 1 561 880  
progress@inco.com.lb
- LT Lithuania**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Latvia  
or  
ELEKTROS IRANGA  
Tinklų g. 29 a  
LT-5319 Panevezys  
Telephone number +370 (45)  
582 828  
Fax number  
info@eliranga.lt
- LU Luxembourg**  
Please contact  
Weidmüller Benelux B. V.  
Netherlands
- LV Latvia**  
SIA Abi4  
Daugavgrivas 31b  
Rīga, LV-1007  
Telephone number +371 674  
70999  
Fax number +371 676  
24562  
abi\_4@tvnet.lv  
Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Udens str. 12-118  
Rīga, LV-1007  
Telephone number +371  
29254766  
Fax number +371 674  
65637  
lgonis.rudaks@weidmueller.  
com  
www.weidmueller.com
- MA Morocco**  
Sofimed  
137, Bd Moulay Ismail Roches  
Noires  
20290 Casablanca  
Telephone number  
Telephone number  
Fax number  
contact@sofimedmaroc.com
- MD Moldova**  
BERHORD A & D srl  
79/1. str. Milescu Spartaru  
MD-2075 Chisinau  
Moldova  
Telephone number +373 (22)  
815002  
Fax number +373 (22)  
815007  
atuleanu@berhord.com  
www.ad.berhord.com
- ME Montenegro**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia.
- MG Madagascar**  
Please contact  
Phambili Interface  
South Africa
- MK Macedonia**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia  
or  
ELEKTRO - SMK doool  
UL. III Makedonska brigada  
b.b.  
1000 Skopje  
Telephone number +389  
22460295  
Fax number  
Elektro-smk@telelab.net.mk
- MT Malta**  
E. S. S., Electrical Supplies &  
Services Ltd.  
San Gwakkin Road  
Mriehel  
Telephone number +356  
21255777  
Fax number +356 21255999  
robert.agius@ess.com.mt
- MU Mauritius**  
Mubelo Electrical Ltd.  
Office 26, Gateway building,  
St Jean Road  
Quatre Bornes  
Mauritius  
Telephone number +230  
4670989  
Fax number +230 4654051  
richard.mubelo@orange.mu
- MW Malawi**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.
- MX Mexico**  
W Interconnections S. A.  
DE C. V.  
Blvd. Hermanos Serdán 698,  
Col. San Rafael Oriente  
72029 Puebla  
Telephone number +52 (222)  
268 6227  
Fax number +52 (222) 286  
6242  
clientes@weidmuller.com.mx
- MY Malaysia**  
Connect Plus Technology  
Sdn Bhd  
No. 43, Jalan PJS 11/22,  
Bandar Sunway  
46150 Petaling Jaya  
Selangor Darul Ehsan  
Telephone number +60 3  
5633 7363  
Fax number +60 3 5633  
6562  
paul@cptech.com.my  
www.cptech.com.my
- MZ Mozambique**  
Please contact  
Phambili Interface  
South Africa
- NA Namibia**  
Please contact  
Phambili Interface  
South Africa
- NG Nigeria**  
Please contact  
Weidmüller Interface GmbH  
& Co. KG  
South Africa
- NL Netherlands**  
Weidmüller Benelux B. V.  
Franciscusweg 221  
1216 SE Hilversum  
P.O. Box 1505  
1200 BM Hilversum  
Telephone number +31 35  
626 12 61  
Fax number +31 35 623  
20 44  
info@weidmuller.nl  
www.weidmuller.nl
- NO Norway**  
Sivilingeniør J.F. Knudtzen AS  
Billingstadsletta 97  
1396 Billingstad  
PO Box 160  
1378 Nesbru  
Telephone number +47 66  
98 33 50  
Fax number +47 66 98 09 55  
firmapost@fknudtzen.no  
www.fknudtzen.no
- NZ New Zealand**  
Cuthbert S. Steward Ltd.  
27 Te Puni Street  
Petone  
PO Box 38496  
Wellington Mail Centre 5054  
Telephone number (04) 568  
6156  
Fax number (09) 489 1752  
csl@cuthbertstewart.co.nz  
Cuthbert S. Steward Ltd  
4 Fred Thomas Drive  
Aon Building, Ground Floor,  
South Entry  
Takapuna  
PO Box 100 338  
North Shore City 745  
Telephone number (09) 489  
1751  
Fax number (04) 568 6056  
cslak@cuthbertstewart.co.nz
- OM Oman**  
DAN INTERNATIONAL LLC.  
Ghala St. 111  
BP 2901  
Seeb  
Telephone number +968  
5036 77  
Fax number +968 5037 55  
yedu@danint.com
- PE Peru**  
IMPEXINCA S.A.C.  
Calle Ortiz de Zevallos No.  
105, Urb. San Antonio  
18  
Lima, Miraflores  
Telephone number +51 1  
447 5608  
info@impexinca.pe  
www.impexinca.pe  
J & W CIA. S.A.  
Calle 6 Mz. D Lte. 23, Urb.  
Ind. Grimanesa  
01  
Callao  
Telephone number +51 1  
572 2539  
Fax number +51 1 572 0152  
contacto@jwcia.com  
www.jwcia.com
- PH Philippines**  
Enclosure Systems Specialists  
Inc.  
2276 Don Chino Roces  
Avenue Extension  
Room 103/105 Narra Building  
1231 Makati City  
Telephone number +63 2  
813 8580  
Fax number +63 2 813 8596  
sales\_encsys@pltds.net  
www.enclosuresystemsp.  
com
- PK Pakistan**  
Automation Controls (Pak)  
Apartment No. 33 C III,  
Chenab Block, Allama Iqbal  
Town  
Lahore  
Telephone number +92 42  
37809948  
Fax number +92 42  
37809950  
nadeem@acpak.com.pk  
www.acpak.com.pk
- PL Poland**  
Weidmüller Sp. z o. o.  
ul. Ogrodowa 58  
00-876 Warszawa  
Telephone number +48 22  
510 09 40  
Fax number +48 22 510  
09 41  
biuro@weidmuller.com.pl  
www.weidmuller.pl
- PR Puerto Rico**  
Please contact  
W Interconnections Inc.  
United States
- PT Portugal**  
Weidmüller Sistemas de  
Interface S. A.  
Estrada Outeiro Polima, R.  
Augusto Dias da Silva, Lote  
B - Esct. 2  
São Domingos de Rana  
2785-515 Abóboda  
Telephone number +351 214  
459 191  
Fax number +351 214  
455 871  
weidmuller@weidmuller.pt  
www.weidmuller.pt
- PY Paraguay**  
Please contact  
CPI SA  
Argentina
- QA Qatar**  
Doha Motors  
PO Box 145  
Telephone number +974  
4651441  
Fax number +974 4654579  
dmtctech@qatar.net.qa  
http://www.dohamotorsgroup.  
com/td.html  
Petroleum Technology Co.  
W.L.L.  
PO Box 16069  
5th Floor Toyota tower  
Telephone number +974  
44419603  
Fax number +974 44419604  
petrotec@qatar.net.qa  
www.petrotec.com.qa
- RO Romania**  
Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Ionescu Crum Street, No.  
1, 1st Tower, 1st Floor,  
Office 4  
500446 Brasov - Brasov  
Business Park  
Telephone number +40 (268)  
446 222  
Fax number +40 (262)  
205 410  
claudiu.totea@weidmueller.  
com  
www.weidmueller.com
- RS Serbia**  
Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Ustanicka 189, III sprat  
lokal 7a  
11050 Beograd  
Telephone number +381  
112885274  
Fax number +381  
112885274  
zoran.rabrenovic@  
weidmueller.com  
TeLa Elektrik d.o.o.  
Ul. Dr. Drage Ljočić 6  
Beograd  
Telephone number +381 11  
2772 415  
Fax number +381 11 2772  
850  
office@tela.rs  
www.tela.rs
- RU Russia**  
Weidmüller Group  
7/10 Khlebozavodskiy  
Passage,  
Moskau  
115230  
Telephone number +7 495  
280 72 71  
Fax number +7 495 280  
72 71  
Info@weidmueller.ru  
www.weidmueller.ru
- SA Saudi Arabia**  
Al Abdulkarim Holding Co.  
P.O. Box 4  
Dammam 31411  
Telephone number +966 3  
8337110  
Fax number +966 3  
8829547  
E-mail salehsk@akh.com.sa  
www.weidmueller.ae  
Saudi Electric Supply  
Company (SESCO)  
P.O. Box 32 98  
Al Khobar 31952  
Telephone number +966 3  
8829546 Ext. 3030  
Fax number  
www.sesco-gex.com  
www.sesco-gex.com
- SE Sweden**  
Weidmüller AB  
Axel Danielssons väg 271  
BOX 31025  
SE-200 49 Malmö  
Telephone number +46 77-  
143 00 44  
Fax number +46 40-37 48 60  
info@weidmuller.se  
www.weidmuller.se
- SG Singapore**  
Weidmüller Pte. Ltd.  
70 Bendemeer Road  
# 04-03 Luzerne Building  
Singapore 339940  
Telephone number +65 6841  
5311  
Fax number +65 6841 5377  
info@weidmuller.com.sg  
www.weidmuller.com.sg
- SI Slovenia**  
Elektrospoji d. o. o.  
Stegne 27  
Sl- 1000 Ljubljana  
Osrednjėslovenska  
Telephone number +386 1  
511 3810  
Fax number +386 1 511  
1604  
info@elektrospoji.si  
www.elektrospoji.si
- SK Slovakia**  
ELEKTRIS s.r.o.  
Elektrárėnská 1  
831 04 Bratislava  
Telephone number +421  
2/4920 0113  
Fax number +421 2/4920  
0119  
bratislava@elektris.sk
- SV El Salvador**  
Prestegard Electro  
11 Avenida Norte No. 240  
Edificio Salazar No. 2  
San Salvador  
Telephone number +503  
2271 1690  
Fax number +503 2221  
3851  
prestegard@navegante.com.sv
- SY Syria**  
Please contact  
Weidmüller Middle East FZE  
United Arab Emirates
- SZ Swaziland**  
Please contact  
Phambili Interface  
South Africa

# Addresses worldwide

Let's connect.

**TH Thailand**  
Pisanu Engineering Co. Ltd.  
Kwang Dingaeng, Khet  
Dingaeng  
800/2 Soi Trakulsuk, Asoke-  
dindaeng Road  
Dindaeng, Bangkok  
10400  
Telephone number +66 2  
248 2896  
Fax number +662 105 6301  
ecsales@pisanu.co.th  
www.pisanu.co.th

Representative Office  
Weidmüller Pte. Ltd.  
37/F, Sathorn Square Building  
98 North Sathorn Road  
Bangkok, Silom Bangrak  
10500  
Telephone number +66 2  
105 6300  
Fax number +66 2 642 9220  
info@weidmuller.com.sg

**TN Tunisia**  
Please contact  
Weidmüller E. U. R. L.  
France

**TR Turkey**  
Weidmüller Elektronik Ticaret  
Ltd. Sirketi  
Kavacik Mah. Orhan Veli Kanik  
Caddesi 9/1  
34810 Beykoz / Istanbul  
Telephone number +90 (216)  
537 10 70  
Fax number +90 (216) 537  
10 77  
info@weidmuller.com.tr  
www.weidmuller.com.tr

**TW Taiwan**  
Weidmuller (Hong Kong)  
Limited  
No. 3, Lane 89, ChungYang  
N. Rd  
24148 SanChuang City,  
Taipei  
Telephone number +886 921  
949 751  
roy.lin@weidmueller.com.hk

**TZ Tanzania**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.

**UA Ukraine**  
LLC WM UKRAINE  
Levanevskogo str. 6  
Kiev  
3058  
Telephone number +38 044  
490 32 48  
Fax number  
info@wm-ua.com.ua  
wm-ua.com.ua/

Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Z, office 303  
7-D, Zdobunivska str.  
Kiev, 2081  
Telephone number  
(mobile) +38 050 440 25 24  
info.ua@weidmueller.com

**US United States**  
W Interconnections Inc.  
821 Southlake Boulevard  
Richmond Virginia 23236  
Telephone number +1 (804)  
794-2877  
Fax number +1 (804) 379-  
2593  
info@weidmuller.com  
www.weidmuller.com

**UY Uruguay**  
REWO Uruguay S. A.  
AV. Bolivia 2001Esq  
Rocafuerte  
11300 Carrasco Montevideo  
Telephone number +598  
2604 8439  
Fax number +598 2604  
8439  
rewo@rewo Uruguay.com.uy

**UZ Republic of Uzbekistan**  
Please contact  
Weidmüller Group  
Russia

**VE Venezuela**  
Somerinca C. A.  
Corazon de Jesus - 3ra  
Transversal con calle el  
Carmen- Los Dos Caminos  
Caracas 1070-A  
Telephone number +58  
2122352748  
Fax number +58  
2122399341  
klocmoeller@cantv.net  
www.somerinca.com

**VN Vietnam**  
AUMI Industrial Equipment &  
Automation Company Limited  
E1, La Thanh Hotel  
218 Doi Can Street  
Lieu Giai Ward, Ba Dinh  
District  
Hanoi City  
Telephone number +84 4  
37628601  
Fax number +84 4  
6266 1391  
aumi@aumi.com.vn  
www.aumi.com.vn

Representative Office  
Weidmüller Pte. Ltd.  
Level 16 Saigon Tower  
Building  
29 Le Duan Street  
District 1  
Ho Chi Minh  
Telephone number +848  
3520 7717  
Fax number +848 3520  
7604  
info@weidmuller.com.sg

**ZA South Africa**  
Phambili Interface  
PO Box 193  
1609 Johannesburg, Edenvale  
5 Bundo Road, Sebenza  
1610 Johannesburg  
Telephone number +27 (11)  
4521930  
Fax number  
info@weidmuller.co.za  
www.weidmuller.co.za

Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
210 Amarand  
Avenue, Pegasus Building  
181 Pretoria, waterkloof Glen  
ext 2 -  
Telephone number +27 12  
003 2906  
Fax number +27 (11)  
4526455  
Jacques.Vosloo@weidmueller.  
com  
www.weidmueller.com

**ZM Zambia**  
Please contact  
Phambili Interface  
South Africa

**ZW Zimbabwe**  
Please contact  
Phambili Interface  
South Africa