
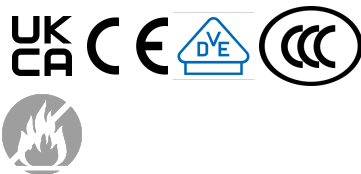


## 60227IEC02(RV) CCC VDE RoHS 1X1.5 YE

**Article No.:** 3911111

单芯线; 1X1.5; 黄色; 卷;  $U_0/U$ : 450/750 V; PVC; 固定敷设

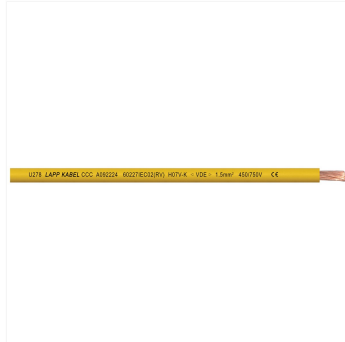

### Details

#### Benefits

- PVC-insulated, non-sheathed single core cable with a flexible conductor and 450 /750V voltage.
- Reduced risk of flame propagation in event of fire; flame-retardant according to IEC 60332-1-2.
- Good electrical conductivity due to fine wire copper conductor, according to class 5 of VDE 0295, IEC 60228 and GB/T 3956.
- Complies with CCC certification issued by China Quality Certification Centre, according to IEC 60227-3 and GB/T 5023.3.
- VDE certified according to EN 50525-2-31.

#### Application

- For use in factory wiring and field wiring, such as the internal wiring of devices and control cabinets.
- Suitable for laying in tubes, exposed or buried in plaster, and in closed installation ducts.
- Suitable for direct laying on racks, troughs and tubes as a potential equalisation conductor.
- Suitable for use in fixed installations with a temperature of  $-40^{\circ}\text{C}$  to  $+80^{\circ}\text{C}$ .

**Notes**

图形照片不能缩放也不能代表各自产品的详细图像

如适用价格为纯金属价格不含附加费和增值税仅向商业客户销售

除非另有说明所有显示的产品参数值均为室温下的额定值有关值的更多信息例如公

差可应要求提供如果可用并允许公布

**Remarks**

## Technical Data

**General information**

产品类型	单芯线
铜号	14.4 kg/km
单芯线包装类型	卷

**Electrical parameters**

额定电压	$U_0/U$ : 450/750 V AC rms 后 IEC
测试电压	2.5 kV

**Product design**

统一协调设计	H07V-K
电缆尺寸	1X1.5

导体截面积平方毫米	1.5 mm <sup>2</sup>
导体材料	裸铜
导体结构	IEC 60228 类别 5细丝绞合线
芯线数量	1
额定外径	3.1 mm
电缆形状	圆形
芯材隔热基材	聚氯乙烯
芯材隔热基材简称	PVC
单芯颜色	黄色
单芯线识别	单色

#### Product features

应用领域	固定敷设
最小弯曲半径固定敷设	5 x 外径
最小弯曲半径毫米静态	15.5 mm
温度固定敷设	-40 °C 至 80 °C 后 IEC
最低安装温度	-5 °C
安装温度最大	70 °C

---

阻燃	是
阻燃性符合	IEC 60332-1-2
抗紫外线	否
耐气候	否
耐臭氧	否
无卤	否
耐油	否
无 PWIS	是

---

**Certifications and standards**

CE 标志	是
UKCA 标识	是
VDE 认证	是
HAR 认证	否
产品标准 DIN / EN	EN 50525-2-31

---

**60227IEC02(RV) 450/750V H07V-K**

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3911001	60227IEC02(RV) CCC VDE RoHS 1X1.5 GNYE	1.5 mm <sup>2</sup>	绿色-黄色	卷			14.4 kg/km	
3911002	60227IEC02(RV) CCC VDE RoHS 1X2.5 GNYE	2.5 mm <sup>2</sup>	绿色-黄色	卷			24 kg/km	
3911003	60227IEC02(RV) CCC VDE RoHS 1X4 GNYE	4 mm <sup>2</sup>	绿色-黄色	卷			38.4 kg/km	
3911004	60227IEC02(RV) CCC VDE RoHS 1X6 GNYE	6 mm <sup>2</sup>	绿色-黄色	卷			57.6 kg/km	
3911005	60227IEC02(RV) CCC VDE RoHS 1X10 GNYE	10 mm <sup>2</sup>	绿色-黄色	盘装			96 kg/km	
3911006	60227IEC02(RV) CCC VDE RoHS 1X16 GNYE	16 mm <sup>2</sup>	绿色-黄色	盘装			153.6 kg/km	
3911011	60227IEC02(RV) CCC VDE RoHS 1X1.5 BK	1.5 mm <sup>2</sup>	黑色	卷			14.4 kg/km	
3911012	60227IEC02(RV) CCC VDE RoHS 1X2.5 BK	2.5 mm <sup>2</sup>	黑色	卷			24 kg/km	
3911013	60227IEC02(RV) CCC VDE RoHS 1X4 BK	4 mm <sup>2</sup>	黑色	卷			38.4 kg/km	
3911014	60227IEC02(RV) CCC VDE RoHS 1X6 BK	6 mm <sup>2</sup>	黑色	卷			57.6 kg/km	
3911015	60227IEC02(RV) CCC VDE RoHS 1X10 BK	10 mm <sup>2</sup>	黑色	盘装			96 kg/km	
3911016	60227IEC02(RV) CCC VDE RoHS 1X16 BK	16 mm <sup>2</sup>	黑色	盘装			153.6 kg/km	
39110211	60227IEC02(RV) CCC VDE RoHS 1X1.5 BU	1.5 mm <sup>2</sup>	蓝色	卷			14.4 kg/km	
39110221	60227IEC02(RV) CCC VDE RoHS 1X2.5 BU	2.5 mm <sup>2</sup>	蓝色	卷			24 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
39110231	60227IEC02(RV) CCC VDE RoHS 1X4 BU	4 mm <sup>2</sup>	蓝色	卷			38.4 kg/km	
39110241	60227IEC02(RV) CCC VDE RoHS 1X6 BU	6 mm <sup>2</sup>	蓝色	盘装			57.6 kg/km	
39110251	60227IEC02(RV) CCC VDE RoHS 1X10 BU	10 mm <sup>2</sup>	蓝色	盘装			96 kg/km	
39110261	60227IEC02(RV) CCC VDE RoHS 1X16 BU	16 mm <sup>2</sup>	蓝色	盘装			153.6 kg/km	
3911031	60227IEC02(RV) CCC VDE RoHS 1X1.5 BN	1.5 mm <sup>2</sup>	褐色	卷			14.4 kg/km	
3911032	60227IEC02(RV) CCC VDE RoHS 1X2.5 BN	2.5 mm <sup>2</sup>	褐色	卷			24 kg/km	
3911033	60227IEC02(RV) CCC VDE RoHS 1X4 BN	4 mm <sup>2</sup>	褐色	卷			38.4 kg/km	
3911034	60227IEC02(RV) CCC VDE RoHS 1X6 BN	6 mm <sup>2</sup>	褐色	卷			57.6 kg/km	
3911035	60227IEC02(RV) CCC VDE RoHS 1X10 BN	10 mm <sup>2</sup>	褐色	盘装			96 kg/km	
3911036	60227IEC02(RV) CCC VDE RoHS 1X16 BN	16 mm <sup>2</sup>	褐色	盘装			153.6 kg/km	
3911041	60227IEC02(RV) CCC VDE RoHS 1X1.5 RD	1.5 mm <sup>2</sup>	红色	卷			14.4 kg/km	
3911042	60227IEC02(RV) CCC VDE RoHS 1X2.5 RD	2.5 mm <sup>2</sup>	红色	卷			24 kg/km	
3911043	60227IEC02(RV) CCC VDE RoHS 1X4 RD	4 mm <sup>2</sup>	红色	卷			38.4 kg/km	
3911044	60227IEC02(RV) CCC VDE RoHS 1X6 RD	6 mm <sup>2</sup>	红色	卷			57.6 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3911045	60227IEC02(RV) CCC VDE RoHS 1X10 RD	10 mm <sup>2</sup>	红色	盘装			96 kg/km	
3911046	60227IEC02(RV) CCC VDE RoHS 1X16 RD	16 mm <sup>2</sup>	红色	盘装			153.6 kg/km	
3911051	60227IEC02(RV) CCC VDE RoHS 1X1.5 WH	1.5 mm <sup>2</sup>	白色	卷			14.4 kg/km	
3911052	60227IEC02(RV) CCC VDE RoHS 1X2.5 WH	2.5 mm <sup>2</sup>	白色	卷			24 kg/km	
3911053	60227IEC02(RV) CCC VDE RoHS 1X4 WH	4 mm <sup>2</sup>	白色	卷			38.4 kg/km	
3911054	60227IEC02(RV) CCC VDE RoHS 1X6 WH	6 mm <sup>2</sup>	白色	卷			57.6 kg/km	
3911055	60227IEC02(RV) CCC VDE RoHS 1X10 WH	10 mm <sup>2</sup>	白色	盘装			96 kg/km	
3911056	60227IEC02(RV) CCC VDE RoHS 1X16 WH	16 mm <sup>2</sup>	白色	盘装			153.6 kg/km	
3911061	60227IEC02(RV) CCC VDE RoHS 1X1.5 GY	1.5 mm <sup>2</sup>	灰色	卷			14.4 kg/km	
3911062	60227IEC02(RV) CCC VDE RoHS 1X2.5 GY	2.5 mm <sup>2</sup>	灰色	卷			24 kg/km	
3911063	60227IEC02(RV) CCC VDE RoHS 1X4 GY	4 mm <sup>2</sup>	灰色	卷			38.4 kg/km	
3911064	60227IEC02(RV) CCC VDE RoHS 1X6 GY	6 mm <sup>2</sup>	灰色	卷			57.6 kg/km	
3911065	60227IEC02(RV) CCC VDE RoHS 1X10 GY	10 mm <sup>2</sup>	灰色	盘装			96 kg/km	
3911066	60227IEC02(RV) CCC VDE RoHS 1X16 GY	16 mm <sup>2</sup>	灰色	盘装			153.6 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3911071	60227IEC02(RV) CCC VDE RoHS 1X1.5 VT	1.5 mm <sup>2</sup>	紫色	卷			14.4 kg/km	
3911072	60227IEC02(RV) CCC VDE RoHS 1X2.5 VT	2.5 mm <sup>2</sup>	紫色	卷			24 kg/km	
3911073	60227IEC02(RV) CCC VDE RoHS 1X4 VT	4 mm <sup>2</sup>	紫色	卷			38.4 kg/km	
3911074	60227IEC02(RV) CCC VDE RoHS 1X6 VT	6 mm <sup>2</sup>	紫色	卷			57.6 kg/km	
3911075	60227IEC02(RV) CCC VDE RoHS 1X10 VT	10 mm <sup>2</sup>	紫色	盘装			96 kg/km	
3911076	60227IEC02(RV) CCC VDE RoHS 1X16 VT	16 mm <sup>2</sup>	紫色	盘装			153.6 kg/km	
3911081	60227IEC02(RV) CCC VDE RoHS 1X1.5 PK	1.5 mm <sup>2</sup>	粉红色	卷			14.4 kg/km	
3911082	60227IEC02(RV) CCC VDE RoHS 1X2.5 PK	2.5 mm <sup>2</sup>	粉红色	卷			24 kg/km	
3911083	60227IEC02(RV) CCC VDE RoHS 1X4 PK	4 mm <sup>2</sup>	粉红色	卷			38.4 kg/km	
3911084	60227IEC02(RV) CCC VDE RoHS 1X6 PK	6 mm <sup>2</sup>	粉红色	盘装			57.6 kg/km	
3911085	60227IEC02(RV) CCC VDE RoHS 1X10 PK	10 mm <sup>2</sup>	粉红色	盘装			96 kg/km	
3911086	60227IEC02(RV) CCC VDE RoHS 1X16 PK	16 mm <sup>2</sup>	粉红色	盘装			153.6 kg/km	
3911091	60227IEC02(RV) CCC VDE RoHS 1X1.5 OG	1.5 mm <sup>2</sup>	橙色	卷			14.4 kg/km	
3911092	60227IEC02(RV) CCC VDE RoHS 1X2.5 OG	2.5 mm <sup>2</sup>	橙色	卷			24 kg/km	



Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3911093	60227IEC02(RV) CCC VDE RoHS 1X4 OG	4 mm <sup>2</sup>	橙色	卷			38.4 kg/km	
3911094	60227IEC02(RV) CCC VDE RoHS 1X6 OG	6 mm <sup>2</sup>	橙色	盘装			57.6 kg/km	
3911095	60227IEC02(RV) CCC VDE RoHS 1X10 OG	10 mm <sup>2</sup>	橙色	盘装			96 kg/km	
3911096	60227IEC02(RV) CCC VDE RoHS 1X16 OG	16 mm <sup>2</sup>	橙色	盘装			153.6 kg/km	
3911111	60227IEC02(RV) CCC VDE RoHS 1X1.5 YE	1.5 mm <sup>2</sup>	黄色	卷			14.4 kg/km	
3911112	60227IEC02(RV) CCC VDE RoHS 1X2.5 YE	2.5 mm <sup>2</sup>	黄色	卷			24 kg/km	
3911113	60227IEC02(RV) CCC VDE RoHS 1X4 YE	4 mm <sup>2</sup>	黄色	卷			38.4 kg/km	
3911114	60227IEC02(RV) CCC VDE RoHS 1X6 YE	6 mm <sup>2</sup>	黄色	卷			57.6 kg/km	
3911115	60227IEC02(RV) CCC VDE RoHS 1X10 YE	10 mm <sup>2</sup>	黄色	盘装			96 kg/km	
3911116	60227IEC02(RV) CCC VDE RoHS 1X16 YE	16 mm <sup>2</sup>	黄色	盘装			153.6 kg/km	
3911121	60227IEC02(RV) CCC VDE RoHS 1X1.5 GN	1.5 mm <sup>2</sup>	绿色	卷			14.4 kg/km	
3911122	60227IEC02(RV) CCC VDE RoHS 1X2.5 GN	2.5 mm <sup>2</sup>	绿色	卷			24 kg/km	
3911123	60227IEC02(RV) CCC VDE RoHS 1X4 GN	4 mm <sup>2</sup>	绿色	卷			38.4 kg/km	
3911124	60227IEC02(RV) CCC VDE RoHS 1X6 GN	6 mm <sup>2</sup>	绿色	卷			57.6 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3911125	60227IEC02(RV) CCC VDE RoHS 1X10 GN	10 mm <sup>2</sup>	绿色	盘装			96 kg/km	
3911126	60227IEC02(RV) CCC VDE RoHS 1X16 GN	16 mm <sup>2</sup>	绿色	盘装			153.6 kg/km	
39111411	60227IEC02(RV) CCC VDE RoHS 1X1.5 DKBU	1.5 mm <sup>2</sup>	深蓝色	卷			14.4 kg/km	
39111421	60227IEC02(RV) CCC VDE RoHS 1X2.5 DKBU	2.5 mm <sup>2</sup>	深蓝色	卷			24 kg/km	
39111431	60227IEC02(RV) CCC VDE RoHS 1X4 DKBU	4 mm <sup>2</sup>	深蓝色	卷			38.4 kg/km	
39111441	60227IEC02(RV) CCC VDE RoHS 1X6 DKBU	6 mm <sup>2</sup>	深蓝色	卷			57.6 kg/km	
39111451	60227IEC02(RV) CCC VDE RoHS 1X10 DKBU	10 mm <sup>2</sup>	深蓝色	盘装			96 kg/km	
3911946	60227IEC02(RV) CCC VDE RoHS 1X16 DKBU	16 mm <sup>2</sup>	深蓝色	盘装			153.6 kg/km	
3912001	60227IEC02(RV) CCC VDE RoHS 1X25 GNYE	25 mm <sup>2</sup>	绿色-黄色	盘装			240 kg/km	
3912002	60227IEC02(RV) CCC VDE RoHS 1X35 GNYE	35 mm <sup>2</sup>	绿色-黄色	盘装			336 kg/km	
3912003	60227IEC02(RV) CCC VDE RoHS 1X50 GNYE	50 mm <sup>2</sup>	绿色-黄色	盘装			480 kg/km	
3912004	60227IEC02(RV) CCC VDE RoHS 1X70 GNYE	70 mm <sup>2</sup>	绿色-黄色	盘装			672 kg/km	
3912005	60227IEC02(RV) CCC VDE RoHS 1X95 GNYE	95 mm <sup>2</sup>	绿色-黄色	盘装			912 kg/km	
3912006	60227IEC02(RV) CCC VDE RoHS 1X120 GNYE	120 mm <sup>2</sup>	绿色-黄色	盘装			1,152 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912007	60227IEC02(RV) CCC VDE RoHS 1X150 GNYE	150 mm <sup>2</sup>	绿色-黄色	盘装			1,440 kg/km	
3912008	60227IEC02(RV) CCC VDE RoHS 1X185 GNYE	185 mm <sup>2</sup>	绿色-黄色	盘装			1,776 kg/km	
3912009	60227IEC02(RV) CCC VDE RoHS 1X240 GNYE	240 mm <sup>2</sup>	绿色-黄色	盘装			2,304 kg/km	
3912011	60227IEC02(RV) CCC VDE RoHS 1X25 BK	25 mm <sup>2</sup>	黑色	盘装			240 kg/km	
3912012	60227IEC02(RV) CCC VDE RoHS 1X35 BK	35 mm <sup>2</sup>	黑色	盘装			336 kg/km	
3912013	60227IEC02(RV) CCC VDE RoHS 1X50 BK	50 mm <sup>2</sup>	黑色	盘装			480 kg/km	
3912014	60227IEC02(RV) CCC VDE RoHS 1X70 BK	70 mm <sup>2</sup>	黑色	盘装			672 kg/km	
3912015	60227IEC02(RV) CCC VDE RoHS 1X95 BK	95 mm <sup>2</sup>	黑色	盘装			912 kg/km	
3912016	60227IEC02(RV) CCC VDE RoHS 1X120 BK	120 mm <sup>2</sup>	黑色	盘装			1,152 kg/km	
3912017	60227IEC02(RV) CCC VDE RoHS 1X150 BK	150 mm <sup>2</sup>	黑色	盘装			1,440 kg/km	
3912018	60227IEC02(RV) CCC VDE RoHS 1X185 BK	185 mm <sup>2</sup>	黑色	盘装			1,776 kg/km	
3912019	60227IEC02(RV) CCC VDE RoHS 1X240 BK	240 mm <sup>2</sup>	黑色	盘装			2,304 kg/km	
3912031	60227IEC02(RV) CCC VDE RoHS 1X25 BN	25 mm <sup>2</sup>	褐色	盘装			240 kg/km	
3912032	60227IEC02(RV) CCC VDE RoHS 1X35 BN	35 mm <sup>2</sup>	褐色	盘装			336 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912033	60227IEC02(RV) CCC VDE RoHS 1X50 BN	50 mm <sup>2</sup>	褐色	盘装			480 kg/km	
3912034	60227IEC02(RV) CCC VDE RoHS 1X70 BN	70 mm <sup>2</sup>	褐色	盘装			672 kg/km	
3912035	60227IEC02(RV) CCC VDE RoHS 1X95 BN	95 mm <sup>2</sup>	褐色	盘装			912 kg/km	
3912036	60227IEC02(RV) CCC VDE RoHS 1X120 BN	120 mm <sup>2</sup>	褐色	盘装			1,152 kg/km	
3912037	60227IEC02(RV) CCC VDE RoHS 1X150 BN	150 mm <sup>2</sup>	褐色	盘装			1,440 kg/km	
3912038	60227IEC02(RV) CCC VDE RoHS 1X185 BN	185 mm <sup>2</sup>	褐色	盘装			1,776 kg/km	
3912039	60227IEC02(RV) CCC VDE RoHS 1X240 BN	240 mm <sup>2</sup>	褐色	盘装			2,304 kg/km	
3912041	60227IEC02(RV) CCC VDE RoHS 1X25 RD	25 mm <sup>2</sup>	红色	盘装			240 kg/km	
3912042	60227IEC02(RV) CCC VDE RoHS 1X35 RD	35 mm <sup>2</sup>	红色	盘装			336 kg/km	
3912043	60227IEC02(RV) CCC VDE RoHS 1X50 RD	50 mm <sup>2</sup>	红色	盘装			480 kg/km	
3912044	60227IEC02(RV) CCC VDE RoHS 1X70 RD	70 mm <sup>2</sup>	红色	盘装			672 kg/km	
3912045	60227IEC02(RV) CCC VDE RoHS 1X95 RD	95 mm <sup>2</sup>	红色	盘装			912 kg/km	
3912046	60227IEC02(RV) CCC VDE RoHS 1X120 RD	120 mm <sup>2</sup>	红色	盘装			1,152 kg/km	
3912047	60227IEC02(RV) CCC VDE RoHS 1X150 RD	150 mm <sup>2</sup>	红色	盘装			1,440 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912048	60227IEC02(RV) CCC VDE RoHS 1X185 RD	185 mm <sup>2</sup>	红色	盘装			1,776 kg/km	
3912049	60227IEC02(RV) CCC VDE RoHS 1X240 RD	240 mm <sup>2</sup>	红色	盘装			2,304 kg/km	
3912051	60227IEC02(RV) CCC VDE RoHS 1X25 WH	25 mm <sup>2</sup>	白色	盘装			240 kg/km	
3912052	60227IEC02(RV) CCC VDE RoHS 1X35 WH	35 mm <sup>2</sup>	白色	盘装			336 kg/km	
3912053	60227IEC02(RV) CCC VDE RoHS 1X50 WH	50 mm <sup>2</sup>	白色	盘装			480 kg/km	
3912054	60227IEC02(RV) CCC VDE RoHS 1X70 WH	70 mm <sup>2</sup>	白色	盘装			672 kg/km	
3912055	60227IEC02(RV) CCC VDE RoHS 1X95 WH	95 mm <sup>2</sup>	白色	盘装			912 kg/km	
3912056	60227IEC02(RV) CCC VDE RoHS 1X120 WH	120 mm <sup>2</sup>	白色	盘装			1,152 kg/km	
3912057	60227IEC02(RV) CCC VDE RoHS 1X150 WH	150 mm <sup>2</sup>	白色	盘装			1,440 kg/km	
3912058	60227IEC02(RV) CCC VDE RoHS 1X185 WH	185 mm <sup>2</sup>	白色	盘装			1,776 kg/km	
3912059	60227IEC02(RV) CCC VDE RoHS 1X240 WH	240 mm <sup>2</sup>	白色	盘装			2,304 kg/km	
3912061	60227IEC02(RV) CCC VDE RoHS 1X25 GY	25 mm <sup>2</sup>	灰色	盘装			240 kg/km	
3912062	60227IEC02(RV) CCC VDE RoHS 1X35 GY	35 mm <sup>2</sup>	灰色	盘装			336 kg/km	
3912063	60227IEC02(RV) CCC VDE RoHS 1X50 GY	50 mm <sup>2</sup>	灰色	盘装			480 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912064	60227IEC02(RV) CCC VDE RoHS 1X70 GY	70 mm <sup>2</sup>	灰色	盘装			672 kg/km	
3912065	60227IEC02(RV) CCC VDE RoHS 1X95 GY	95 mm <sup>2</sup>	灰色	盘装			912 kg/km	
3912066	60227IEC02(RV) CCC VDE RoHS 1X120 GY	120 mm <sup>2</sup>	灰色	盘装			1,152 kg/km	
3912067	60227IEC02(RV) CCC VDE RoHS 1X150 GY	150 mm <sup>2</sup>	灰色	盘装			1,440 kg/km	
3912068	60227IEC02(RV) CCC VDE RoHS 1X185 GY	185 mm <sup>2</sup>	灰色	盘装			1,776 kg/km	
3912069	60227IEC02(RV) CCC VDE RoHS 1X240 GY	240 mm <sup>2</sup>	灰色	盘装			2,304 kg/km	
3912071	60227IEC02(RV) CCC VDE RoHS 1X25 VT	25 mm <sup>2</sup>	紫色	盘装			240 kg/km	
3912072	60227IEC02(RV) CCC VDE RoHS 1X35 VT	35 mm <sup>2</sup>	紫色	盘装			336 kg/km	
3912073	60227IEC02(RV) CCC VDE RoHS 1X50 VT	50 mm <sup>2</sup>	紫色	盘装			480 kg/km	
3912074	60227IEC02(RV) CCC VDE RoHS 1X70 VT	70 mm <sup>2</sup>	紫色	盘装			672 kg/km	
3912075	60227IEC02(RV) CCC VDE RoHS 1X95 VT	95 mm <sup>2</sup>	紫色	盘装			912 kg/km	
3912076	60227IEC02(RV) CCC VDE RoHS 1X120 VT	120 mm <sup>2</sup>	紫色	盘装			1,152 kg/km	
3912077	60227IEC02(RV) CCC VDE RoHS 1X150 VT	150 mm <sup>2</sup>	紫色	盘装			1,440 kg/km	
3912078	60227IEC02(RV) CCC VDE RoHS 1X185 VT	185 mm <sup>2</sup>	紫色	盘装			1,776 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912079	60227IEC02(RV) CCC VDE RoHS 1X240 VT	240 mm <sup>2</sup>	紫色	盘装			2,304 kg/km	
3912081	60227IEC02(RV) CCC VDE RoHS 1X25 PK	25 mm <sup>2</sup>	粉红色	盘装			240 kg/km	
3912082	60227IEC02(RV) CCC VDE RoHS 1X35 PK	35 mm <sup>2</sup>	粉红色	盘装			336 kg/km	
3912083	60227IEC02(RV) CCC VDE RoHS 1X50 PK	50 mm <sup>2</sup>	粉红色	盘装			480 kg/km	
3912084	60227IEC02(RV) CCC VDE RoHS 1X70 PK	70 mm <sup>2</sup>	粉红色	盘装			672 kg/km	
3912085	60227IEC02(RV) CCC VDE RoHS 1X95 PK	95 mm <sup>2</sup>	粉红色	盘装			912 kg/km	
3912086	60227IEC02(RV) CCC VDE RoHS 1X120 PK	120 mm <sup>2</sup>	粉红色	盘装			1,152 kg/km	
3912087	60227IEC02(RV) CCC VDE RoHS 1X150 PK	150 mm <sup>2</sup>	粉红色	盘装			1,440 kg/km	
3912088	60227IEC02(RV) CCC VDE RoHS 1X185 PK	185 mm <sup>2</sup>	粉红色	盘装			1,776 kg/km	
3912089	60227IEC02(RV) CCC VDE RoHS 1X240 PK	240 mm <sup>2</sup>	粉红色	盘装			2,304 kg/km	
3912091	60227IEC02(RV) CCC VDE RoHS 1X25 OG	25 mm <sup>2</sup>	橙色	盘装			240 kg/km	
3912092	60227IEC02(RV) CCC VDE RoHS 1X35 OG	35 mm <sup>2</sup>	橙色	盘装			336 kg/km	
3912093	60227IEC02(RV) CCC VDE RoHS 1X50 OG	50 mm <sup>2</sup>	橙色	盘装			480 kg/km	
3912094	60227IEC02(RV) CCC VDE RoHS 1X70 OG	70 mm <sup>2</sup>	橙色	盘装			672 kg/km	

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912095	60227IEC02(RV) CCC VDE RoHS 1X95 OG	95 mm <sup>2</sup>	橙色	盘装			912 kg/km	
3912096	60227IEC02(RV) CCC VDE RoHS 1X120 OG	120 mm <sup>2</sup>	橙色	盘装			1,152 kg/km	
3912097	60227IEC02(RV) CCC VDE RoHS 1X150 OG	150 mm <sup>2</sup>	橙色	盘装			1,440 kg/km	
3912098	60227IEC02(RV) CCC VDE RoHS 1X185 OG	185 mm <sup>2</sup>	橙色	盘装			1,776 kg/km	
3912099	60227IEC02(RV) CCC VDE RoHS 1X240 OG	240 mm <sup>2</sup>	橙色	盘装			2,304 kg/km	
3912111	60227IEC02(RV) CCC VDE RoHS 1X25 YE	25 mm <sup>2</sup>	黄色	盘装			240 kg/km	
3912112	60227IEC02(RV) CCC VDE RoHS 1X35 YE	35 mm <sup>2</sup>	黄色	盘装			336 kg/km	
3912113	60227IEC02(RV) CCC VDE RoHS 1X50 YE	50 mm <sup>2</sup>	黄色	盘装			480 kg/km	
3912114	60227IEC02(RV) CCC VDE RoHS 1X70 YE	70 mm <sup>2</sup>	黄色	盘装			672 kg/km	
3912115	60227IEC02(RV) CCC VDE RoHS 1X95 YE	95 mm <sup>2</sup>	黄色	盘装			912 kg/km	
3912116	60227IEC02(RV) CCC VDE RoHS 1X120 YE	120 mm <sup>2</sup>	黄色	盘装			1,152 kg/km	
3912117	60227IEC02(RV) CCC VDE RoHS 1X150 YE	150 mm <sup>2</sup>	黄色	盘装			1,440 kg/km	
3912118	60227IEC02(RV) CCC VDE RoHS 1X185 YE	185 mm <sup>2</sup>	黄色	盘装			1,776 kg/km	
3912119	60227IEC02(RV) CCC VDE RoHS 1X240 YE	240 mm <sup>2</sup>	黄色	盘装			2,304 kg/km	



Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912121	60227IEC02(RV) CCC VDE RoHS 1X25 GN	25 mm <sup>2</sup>	绿色	盘装				240 kg/km
3912122	60227IEC02(RV) CCC VDE RoHS 1X35 GN	35 mm <sup>2</sup>	绿色	盘装				336 kg/km
3912123	60227IEC02(RV) CCC VDE RoHS 1X50 GN	50 mm <sup>2</sup>	绿色	盘装				480 kg/km
3912124	60227IEC02(RV) CCC VDE RoHS 1X70 GN	70 mm <sup>2</sup>	绿色	盘装				672 kg/km
3912125	60227IEC02(RV) CCC VDE RoHS 1X95 GN	95 mm <sup>2</sup>	绿色	盘装				912 kg/km
3912126	60227IEC02(RV) CCC VDE RoHS 1X120 GN	120 mm <sup>2</sup>	绿色	盘装				1,152 kg/km
3912127	60227IEC02(RV) CCC VDE RoHS 1X150 GN	150 mm <sup>2</sup>	绿色	盘装				1,440 kg/km
3912128	60227IEC02(RV) CCC VDE RoHS 1X185 GN	185 mm <sup>2</sup>	绿色	盘装				1,776 kg/km
3912129	60227IEC02(RV) CCC VDE RoHS 1X240 GN	240 mm <sup>2</sup>	绿色	盘装				2,304 kg/km
3912910	60227IEC02(RV) CCC VDE RoHS 1X25 BU	25 mm <sup>2</sup>	蓝色	盘装				240 kg/km
3912911	60227IEC02(RV) CCC VDE RoHS 1X25 DKBU	25 mm <sup>2</sup>	深蓝色	盘装				240 kg/km
3912912	60227IEC02(RV) CCC VDE RoHS 1X35 BU	35 mm <sup>2</sup>	蓝色	盘装				336 kg/km
3912913	60227IEC02(RV) CCC VDE RoHS 1X50 BU	50 mm <sup>2</sup>	蓝色	盘装				480 kg/km
3912914	60227IEC02(RV) CCC VDE RoHS 1X50 DKBU	50 mm <sup>2</sup>	深蓝色	盘装				480 kg/km

Article No.	Name	导体截面积平方毫米	单芯颜色	单芯线包装类型	最小外径	最大外径	铜号	重量
3912915	60227IEC02(RV) CCC VDE RoHS 1X70 BU	70 mm <sup>2</sup>	蓝色	盘装			672 kg/km	
3912916	60227IEC02(RV) CCC VDE RoHS 1X70 DKBU	70 mm <sup>2</sup>	深蓝色	盘装			672 kg/km	
3912917	60227IEC02(RV) CCC VDE RoHS 1X95 BU	95 mm <sup>2</sup>	蓝色	盘装			912 kg/km	
3912918	60227IEC02(RV) CCC VDE RoHS 1X120 BU	120 mm <sup>2</sup>	蓝色	盘装			1,152 kg/km	
3912919	60227IEC02(RV) CCC VDE RoHS 1X120 DKBU	120 mm <sup>2</sup>	深蓝色	盘装			1,152 kg/km	
3912920	60227IEC02(RV) CCC VDE RoHS 1X95 DKBU	95 mm <sup>2</sup>	深蓝色	盘装			912 kg/km	
3912921	60227IEC02(RV) CCC VDE RoHS 1X150 DKBU	150 mm <sup>2</sup>	深蓝色	盘装			1,440 kg/km	
3912922	60227IEC02(RV) CCC VDE RoHS 1X185 BU	185 mm <sup>2</sup>	蓝色	盘装			1,776 kg/km	
3912923	60227IEC02(RV) CCC VDE RoHS 1X185 DKBU	185 mm <sup>2</sup>	深蓝色	盘装			1,776 kg/km	
3912924	60227IEC02(RV) CCC VDE RoHS 1X240 BU	240 mm <sup>2</sup>	蓝色	盘装			2,304 kg/km	
3912926	60227IEC02(RV) CCC VDE RoHS 1X240 DKBU	240 mm <sup>2</sup>	深蓝色	盘装			2,304 kg/km	
3912927	60227IEC02(RV) CCC VDE RoHS 1X35 DKBU	35 mm <sup>2</sup>	深蓝色	盘装			336 kg/km	
3912929	60227IEC02(RV) CCC VDE RoHS 1X150 BU	150 mm <sup>2</sup>	蓝色	盘装			1,440 kg/km	