

247 - Nail sets





Standards:

NF E 71-211, DIN 6458, ASME B107.410

Description:

- Octagon-shaped body.
- Shank hardened to 54 - 58 HRc.
- Zinc-plated finish.

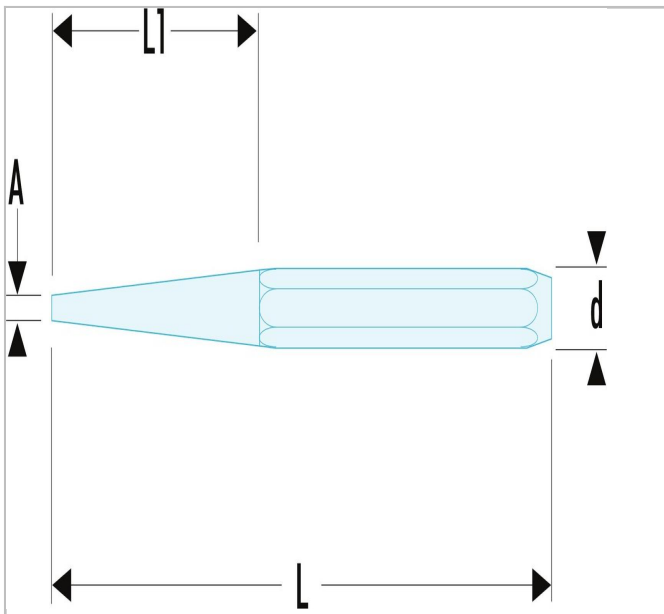

	A [mm]	Diameter [mm]	Length L [mm]	Length L1 [mm]	Weight [g]
247.2	2.0	10.0	120.0	40.0	62.0
247.3	3.0	10.0	120.0	40.0	63.0
247.4	4.0	10.0	120.0	40.0	65.0
247.5	5.0	10.0	120.0	40.0	65.0
247.6	6.0	10.0	120.0	40.0	70.0
247.8	8.0	12.0	120.0	40.0	100.0