



GOST

### Special Features

- Compact & economical
- Reliable
- Field adjustable
- Auto reset

### Applications


- Boilers
- Water treatment
- Fire fighting systems
- Compressors

### Specifications

#### Standard Version

Repeatability	: ± 2% F. S.
Accuracy	: ± 5% F. S.
Scale unit	: bar with psi
Range	: Refer "How to order"
Differential	: Adjustable
Mounting	: Bottom / Panel
Mounting accessories	: Mounting bracket with screws
Process connection	: 1/4" BSP (F)
Enclosure protection	: IP 32
Enclosure material	: Steel (plated) with plastic cover
Maximum process temperature	: 100 °C
Ambient temperature	: -10 to 60 °C
Switch	: 1 SPDT
Switch rating	: 15 A, 220 VAC & 10 A, 24 VDC
Sensing element	: Phosphor bronze bellows
Process medium	: Air, oil & water

### Dimensional Details

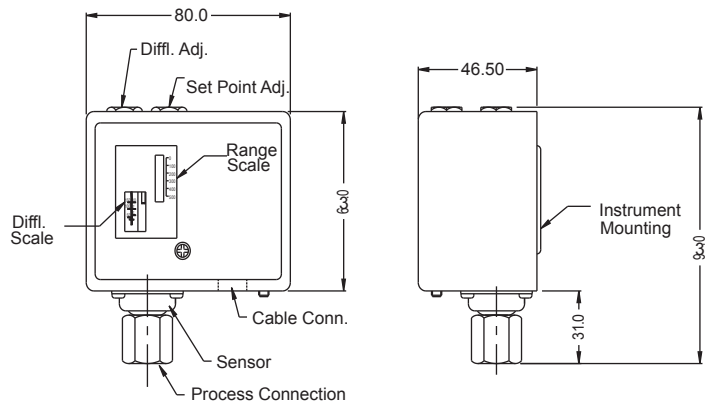

Notes : • Drawings are not to scale. • All Dimensions are in mm.

### How To Order

#### Basic model

#### Range

Ordering Code	Model No.	Range (bar)		Differential (bar)	
		Min	Max	Min	Max
3	UT3	0	3	0.25	1.5
6	UT6	0	6	0.6	3
10	UT10	0	10	1	3
16	UT16	3	16	1	4
20	UT20	5	20	2	5
30	UT30	5	30	5	12

#### Options (\* through adaptors)

**PW** Calibration certificate    **2NM** 1/4" NPT (M)\*    **2NF** 1/4" NPT (F)\*    **SX** SS Tag plate

#### Ordering example: UT . X or XX . XX

Note : Specifications and dimensions given in this product catalogue represents the state of engineering at the time of printing. Modifications may take place and materials specified may be replaced by others without prior notice.

### Example

UT

X  
OR  
XX

XX