


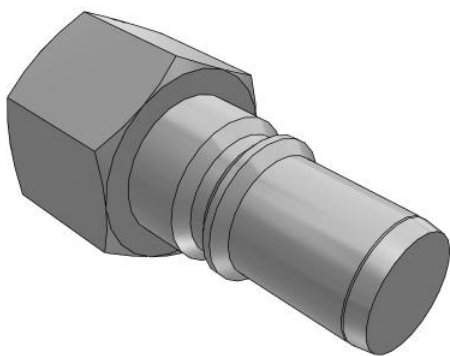

KK*P-*F, S-Couplers, Female Thread

KK4P-03F


Datasheet

- Female Thread.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Port Size: M5, Rc1/8, Rc1/4, Rc3/8, Rc1/2.

Standard specifications

Body Size	4 (1/4)
Piping Port Size	Rc 3/8
-	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	0 kPa
Proof pressure	1.5 MPa
Effective Area	39 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.024 Kg

Dimensions

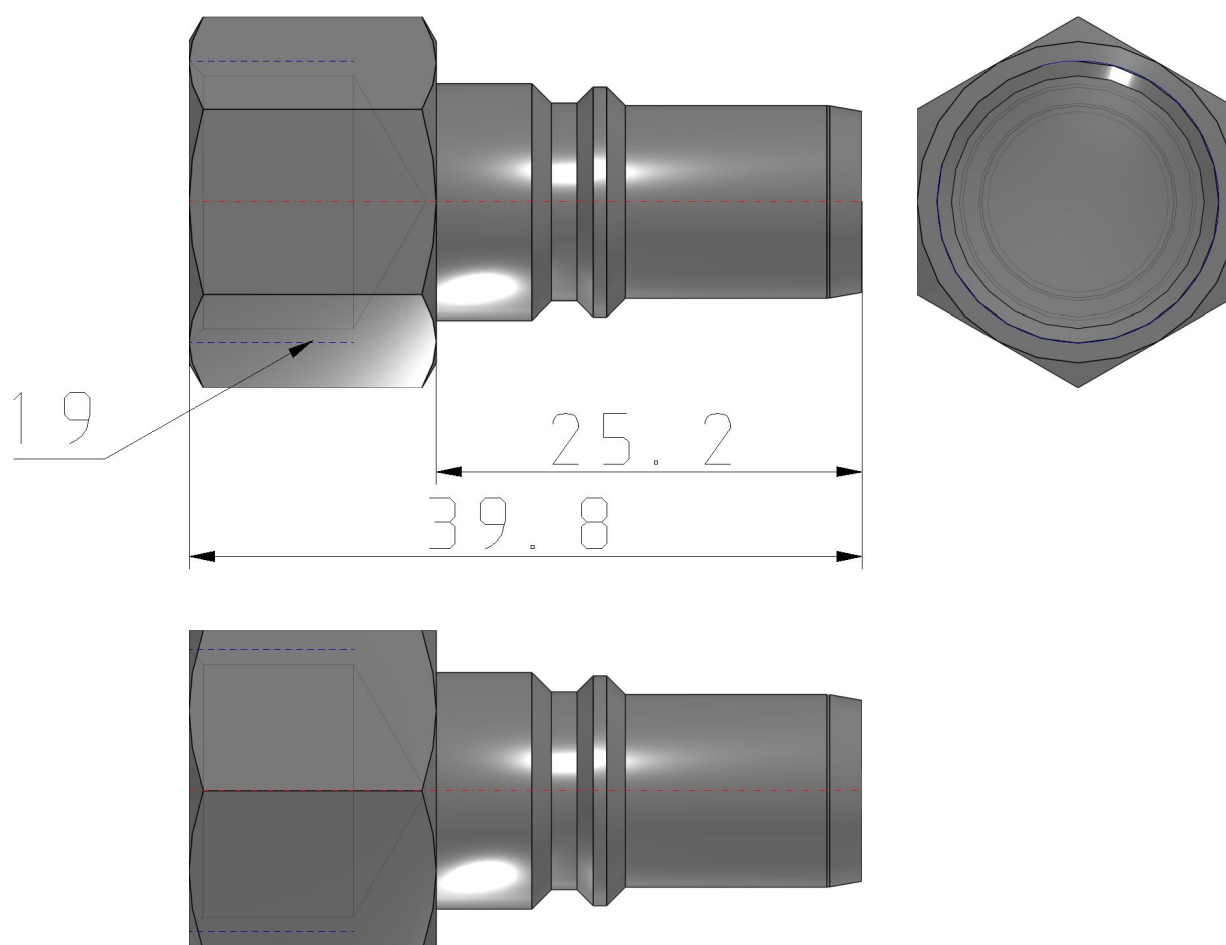

Additional information

Catalogue

[KK-C_EU.pdf](#)