


Technical Data

- Max. 250mA/120V/9W AC/6W DC
- 2 pole
- momentary or alternate
- 8 contact functions
- temperature range:
 - low temp: -40/+75°C
 - high temp: -40/+160°C
- through-hole version

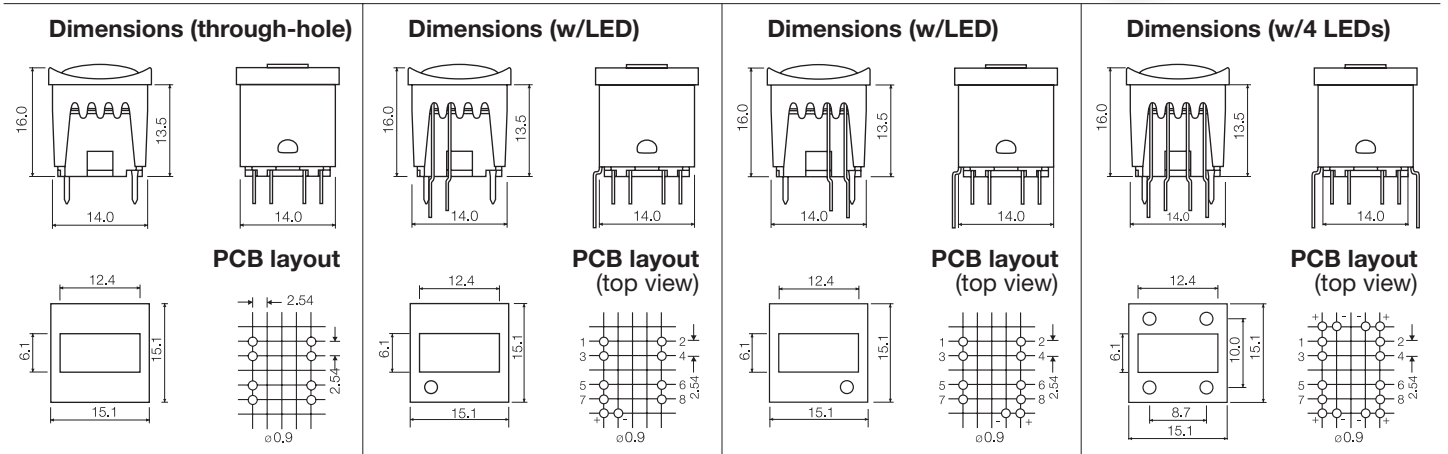

How to order

	1 5	+	1 6 3 0 0	+	1 6 3 1 0	For 16300 and 16310 only
	Switch 15501 mom. silver 15551 alt. silver 15502 mom. gold 15552 alt. gold 15500 silent silver 15401 mom. silver high temp. 15402 mom. gold high temp. 15420 silent gold high temp. 15451 alt. silver high temp.	Cap 00 blue 01 brown 02 green 03 grey 04 yellow 05 golden 06 white 07 orange 08 red 09 black	Bezel 00 blue 01 brown 02 green 03 grey 04 yellow 05 golden 06 white 07 orange 08 red 09 black	30 ultra blue 40 dusty blue 42 aqua blue 32 mint green 33 tele grey 34 melon 38 noble red 50 metal dark blue 53 metal light grey 57 metal dark grey 58 metal bordeaux		

	1 5	+	1 6 3 0 0	+	[] [] [] [] [] [] [] []	+	1 6 9 2 1
	Switch	Cap 	Bezel 16311 	LED 16921 02 green 04 yellow 08 red			
			[] [] [] [] [] [] [] []	+	1 6 9 2 0		LED 16920 02 green 04 yellow 08 red
			Bezel 16312 	LED 16920	LED 16921 1 required 1 required		
			Bezel 16314 				
			Bezel 16315 	LED 16920 2 required	LED 16921 2 required		

Ordering example: 15501 + 1630003 + 1631408 + 1692008 + 1692108

For updates of products and/or changes of specifications please see www.mec.dk