


Expression Home XP-225

DATASHEET

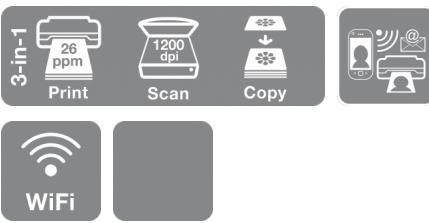

The Expression Home XP-225 is part of Epson's smallest ever range of small-in-one home inkjets. It offers cost-effective printing for home users with inks that can be replaced individually. This compact printer, scanner and copier also features the added benefits of Wi-Fi connectivity and mobile printing from anywhere¹.

Efficient & affordable

Epson's Claria Home Ink is ideal for affordable and reliable printing, producing crisp, clear text documents and glossy, lab-quality photos. With individual ink cartridges you only have to replace the colour used, saving you money.

Easy set-up

The automatic Wi-Fi set-up² makes configuring laptops and computers to print and scan wirelessly extremely easy. You don't need to know your network settings, as the XP-225 automatically finds the relevant connection settings to configure itself.

Mobile printing

The XP-225 comes with Epson Connect¹ which consists of Epson iPrint¹ – for easy wireless printing from smartphones and tablets; Epson Creative Print¹ – print photos directly from Facebook and Epson Email print¹ – print from anywhere in the world by emailing photos and documents directly to the printer.

Simple to maintain

Claria Home Ink cartridges are available in standard and XL sizes. Identifying the right ink cartridge for your printer couldn't be simpler – just look out for the Daisy image.

KEY FEATURES

- **Small-in-one**
Save space, save money, save time
- **Epson Connect¹**
Freedom to print and scan from anywhere
- **Wi-Fi**
Easy wireless printing and scanning
- **Individual Inks**
Only replace the colour used
- **Claria Home Ink**
Crisp, clear text and glossy photos



PRODUCT SPECIFICATIONS

TECHNOLOGY

Printing Method	Epson Micro Piezo™ print head
Nozzle Configuration	128 Nozzles black, 42 Nozzles per colour
Minimum Droplet Size	3 pl, With Variable-Sized Droplet Technology
Ink Technology	Claria™ Home Ink
Printing Resolution	5,760 x 1,440 dpi
All-in-One Functions	Print, Scan, Copy
Category	Consumer

PRINT

Printing Speed ISO/IEC 24734	6.2 Pages/min Monochrome, 3.1 Pages/min Color
Maximum Printing Speed	26 Pages/min Monochrome (plain paper), 13 Pages/min Color (plain paper), 54 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper)
Colours	Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

SCAN

Single-sided scan speed (A4 black)	300 dpi 2.4 msec/line
Single-sided scan speed (A4 colour)	300 dpi 9.5 msec/line
Scanning Resolution	1,200 dpi x 2,400 dpi (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

PAPER / MEDIA HANDLING

Number of paper trays	1
Paper Formats	A4, A5, A6, B5, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter Legal, 9 x 13 cm, 10 x 15 cm, 13 x 18 cm, 13 x 20 cm, 20 x 25 cm, 100 x 148 mm, 16:9
Duplex	Manual
Print Margin	0 mm top, 0 mm right, 0 mm bottom, 0 mm left (Wherever margin is defined. Otherwise 3mm top, left, right, bottom.)
Paper Tray Capacity	50 Sheets Standard, 10 Photo Sheets

GENERAL

Energy Use	11 W (standalone copying, ISO/IEC 24712 pattern), 1.6 W (sleep mode), ENERGY STAR® qualified
Supply Voltage	AC 220 V - 240 V
Product dimensions	390 x 300 x 145 mm (Width x Depth x Height)
Product weight	3.9 kg

Noise Level 5.3 B (A) with Epson Premium Glossy Photo Paper / Photo RPM mode - 41 dB (A) with Epson Premium Glossy Photo Paper / Photo RPM mode

LOGISTICS INFORMATION

SKU	C11CD91401
EAN code	8715946539621
Dimensions Single Carton	458 x 196 x 368 mm
Carton Weight	4.9 Kg
Multiple Order Quantity	1 Units
Country of Origin	Philippines
Pallet Size Euro	49 Units
Pallet Size Block	66 Units



For more information please contact:

Telephone: 01952 607111 (UK)+
01 436 7742 (Republic of Ireland)
E-mail: enquiries@epson.co.uk
Chat: etalk.epson-europe.com
Fax: 0871 222 6740
+ Local call rate.

Web: www.epson.co.uk
www.epson.ie

Expression Home XP-225

WHAT'S IN THE BOX

- Individual Ink Cartridges
- Software (CD)
- Setup guide
- Power cable
- Main unit
- Warranty document

INK CARTRIDGE COMPATIBILITY

- 18
- 18
- 18
- 18
- 18
- 18
- 18
- 18



- 18XL



INK YIELD DATA



18XL 18 18XL

● 470 pages* 175 pages*

● 180 pages* 450 pages*

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. – Epson iPrint and Epson Creative Print require a wireless connection and the Epson printing apps. Email print and Epson Remote Print Driver require an internet connection. For more information, supported languages and devices, please visit www.epsonconnect.eu 2 – Automatic set-up compatible with Windows 8, Windows 7, Windows Vista and Mac OS. Initial Wi-Fi set-up requires a USB cable for Windows XP users – not included

EPSON®

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.