


Braking resistor

CACR-KL2-33-W2400

Part number: 1336619

FESTO

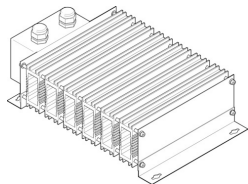

 General operating condition

Data sheet

Feature	Value
Size	600
Mounting position	Free convection Vertical
Pulse energy for braking resistor at 380 V	21600 Ws
Pulse energy for braking resistor at 780 V	21600 Ws
Performance at 35% duty cycle and 20°C	3600 W
Brake resistance rating	1440 W
Nominal power braking resistor at 380 V	1440 W
Nominal power braking resistor at 780 V	1440 W
Resistance value	33 Ohm
Approval	c CSA us (OL) c UL us - Recognized (OL)
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65
Ambient temperature	0 °C ... 50 °C
Product weight	8000 g
Type of mounting	With through-hole With accessories Either:
Note on materials	RoHS-compliant