


**Cast resin joint, Parallel P, 4 x 35mm<sup>2</sup> to 4 x 150mm<sup>2</sup>,  
L=300mm, 1950 ml, Polyurethane resin (PUR) green  
Art.-No. 435-12073 | PAH-2 / SF-PUR-GN | **




- Colour changes from blue to green whilst mixing
- Impact-proof, transparent moulding shell
- Compact, optimized dimensions
- Longitudinally and transversely watertight
- SF-system
- Joint can be submerged directly after casting
- 
- 

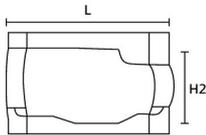

More products in this product group:  
[Parallel branch cable joints house connections >](#)

Application	<p>The parallel branch joint PAH is a universal straight-through and branch joint. Suitable as single branch joint with various commercially available branch clamping rings. For polymeric cables and wires made of PVC, XLPE, PE, EPR and utility cables.</p> <p>Application: Especially designed branch joint for building and domestic connections to the low-voltage electrical network. Underground, submerged, outdoor, indoor.</p>
Colour	Green (GN)
Content	<p>Cast resin PUR 33</p> <p>In a two-chamber pouch</p> <p>Transparent moulding shell</p> <p>Foam seal, protective gloves, emery cloth</p> <p>Cleaning cloth, cable kit, installation instructions</p> <p>SF-nozzle (two-chamber pouch)</p>
Material	Polyurethane resin (PUR)
No. of Wires	4
PART DESCRIPTION	PAH-2 / SF-PUR-GN
Pack Content	1 Set
Package Content packed in	set
Product Family	RELICON PAH-2 with PUR 33
Product Group	Parallel branch cable joints house connections
Type	PAH-2 / SF
Variant	Cast resin


## Product Dimensions

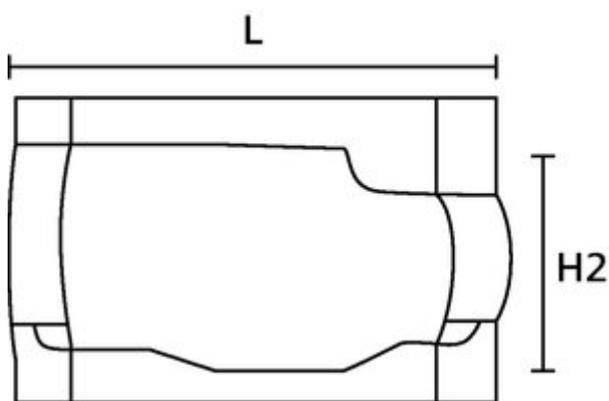

Branch Cable min	4 x 6 mm <sup>2</sup>
Branch Cable max	4 x 70 mm <sup>2</sup>
Height (H2)	130 mm
Length (L)	300 mm
Main Cable max	4 x 150 mm <sup>2</sup>
Main Cable min	4 x 35 mm <sup>2</sup>

ELV Compliant (Article 4 - 2)	YES
Halogen-free	No
Hazardous Goods	No
Operating Temperature	-25 °C to +120 °C
ROHS compliant	Yes
Shelf Life	48 months
Specifications	

## Logistics and Packaging

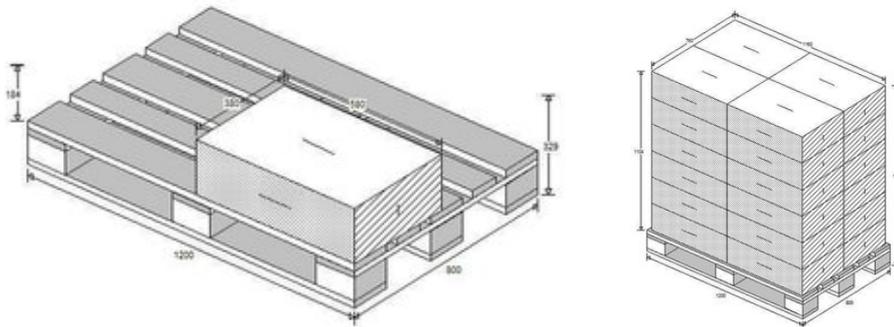

GTIN-13 / EAN	4031026626901
Packaging 3 - Height (m)	0.184 m
Packaging 3 - Length (m)	0.58 m
Packaging 3 - Qty	1
Packaging 3 - Type	box
Packaging 3 - Volume (m <sup>3</sup> )	0.0406 m <sup>3</sup>
Packaging 3 - Weight (kg)	4.163 kg
Packaging 3 - Width (m)	0.38 m
Packaging 4 - Height (m)	1.095 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	45
Packaging 4 - Type	pallet
Packaging 4 - Volume (m <sup>3</sup> )	1.051 m <sup>3</sup>
Packaging 4 - Weight (kg)	208.335 kg
Packaging 4 - Width (m)	0.8 m
Storage Temperature	+4 °C to +40 °C

## More Information

