




Connectors > Circular Connectors > Circular Connector Accessories > Unscreened Circular Connector Backshells & Clamps > CPC CABLE CLAMPS

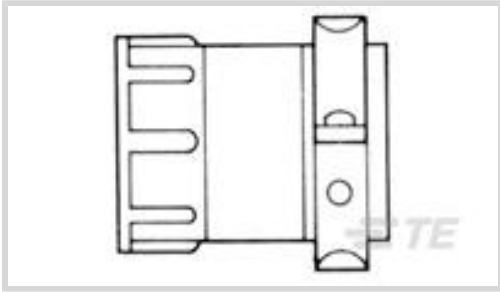

Backshell & Clamp Accessory Type: **Cable Clamp**
Compatible With Circular Connector Shell Size: **23**
Body Orientation: **Straight**
Accepts Cable Diameter (Max): **28.58 mm [1.125 in]**
Protective Cover: **Without**

[All CPC CABLE CLAMPS \(25\)](#)

Features

Product Type Features

Product Type	Accessory
Backshell & Clamp Accessory Type	Cable Clamp
Protective Cover	Without

Body Features

Cable Clamp Material	Thermoplastic
Cable Clamp Flammability Rating	UL 94V-0
Cable Clamp Color	Black

Mechanical Attachment

Screw & Hole Thread Size	1-3/8-18 UNEF-2B
--------------------------	------------------

Housing Features

Body Orientation	Straight
------------------	----------

Dimensions

Accepts Cable Diameter (Max)	28.58 mm[1.125 in]
------------------------------	--------------------

Operation/Application

Compatible With Circular Connector Shell Size	23
---	----

Packaging Features

Packaging Quantity	75
--------------------	----



Packaging Method	Bulk
Other	
Comment	Cable clamp inserts are not sold separately., Cable clamps can be threaded directly onto plugs or receptacles, or onto back-shell extenders., Clamping areas adjustable by inverting or changing inserts., Components for all cable clamps are packaged unassembled. This includes the cable clamp, two screws, and the clamping inserts., Replacement screws are available in the following sizes: 9.52mm [3 /8 in.] -P/N 19024-1, 12.7mm [1/2 in.] -P/N 19024-2, 15.88]mm [5/8 in.] -P/N 19024-3, 25.4mm [1 in.] -P/N 19024-4, 19.05mm [3/4 in.] -P/N 19024-5.

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2022 (223) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

 TE Part # CAT-AM71-C83998BB CPC SERIES 3	 TE Part # CAT-AM71-C83998M CPC SERIES 2	 TE Part # CAT-AM71-C83998J CPC SERIES 1	 TE Part # CAT-AM71-C83998F CPC SERIES 1 POSTED
 TE Part # CAT-AM71-C83998CC CPC SERIES 4	 TE Part # CAT-AM71-C83998E CPC SERIES 2 POSTED	 TE Part # CAT-AM71-C83998K CPC SERIES 6	 TE Part # CAT-AM71-C83998Y CPC SERIES 1 SEALED ONE-PIECE
 TE Part # 206306-2 23-37 F H RECEPT REV SEX	 TE Part # 206306-5 CPC RECEPT ASSEMBLY SIZE 23-37	 TE Part # 206306-1 23-37 RECEPT REV SEX	 TE Part # 1-206934-1 CPC RECPT ASSEMBLY SIZE 23-37
 TE Part # CAT-AM71-C83998GG CPC SERIES 1 POSTED	 TE Part # 1-206934-7 CPC RECPT ASSEMBLY SIZE 23-37	 TE Part # 206934-5 CPC RECPT ASSEMBLY SIZE 23-37	

Also in the Series | AMP CPC

 Circular Connector Adapters(7)	 Circular Connector Boots & Strain Relief(6)	 Circular Connector Caps & Covers(16)	 Circular Connector Hardware(3)
---	---	---	---



Circular Connector Keying Plugs(2)



Circular Connector Seals(36)



Circular Power Connectors(518)



Insertion & Extraction Tools(1)



Power Contacts(6)




Sealing Sleeves(2)



Unscreened Circular Connector Backshells & Clamps(56)


Customers Also Bought

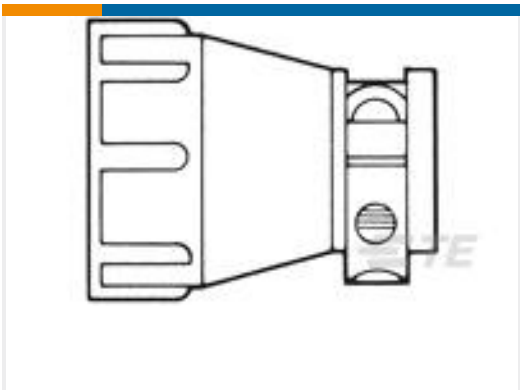

TE Part #1-206138-0
CABLE CLAMP ASSY,BULK PACKED



TE Part #770064-1
01P .093 COMM P&S PLUG HSG

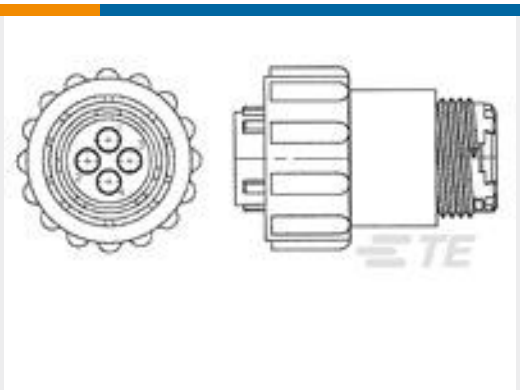

TE Part #796288-1
PLUG.ASSY,23-37STD SEX THRD AD




TE Part #2428-025-1805
BKSHL, 18SZ, BLK, ST, L024, HDP




TE Part #HDC26-24
DUST CAP, 24SZ, REC, BLK, HDP



TE Part #2040594-2
SEAL CAP HSG 3P, AMPSEAL16 SEA

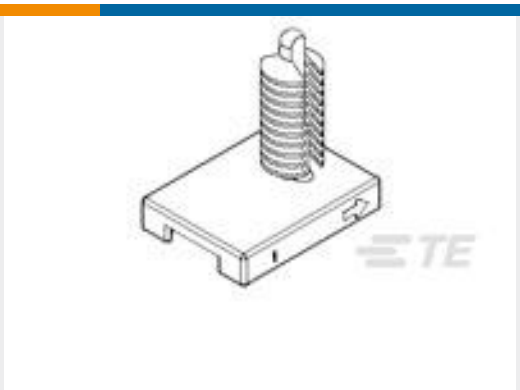


TE Part #1924487-1
MOUNTING CLIP, AMPSEAL 16

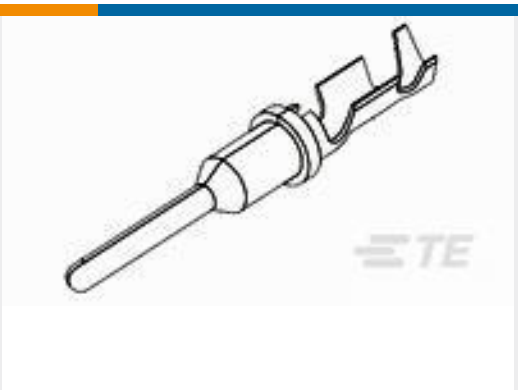

TE Part #638078-3
PIN, SF, SIZE 16, 14-18 AWG, NI/SN



TE Part #HD34-24-91PE-059
REC,9P,AL,E,CBLCLMPBT,DRAIN,8/12 /16,P,MC

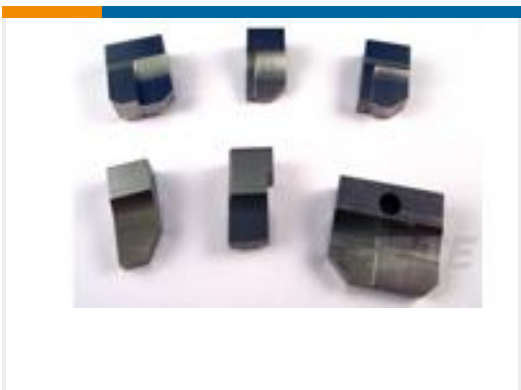

TE Part #5-683403-1
ANVIL, COMBINATION

Documents



Product Drawings

LARGE CABLE CLAMP KIT,BULK PKG

English

CAD Files

Customer View Model

ENG_CVM_CVM_206512-6_K.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_206512-6_K.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_206512-6_K.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMP Circular Connectors for Commercial Signal & Power Applications

English

Agency Approvals

CSA Certificate

English