

Sockets & Accessories

Sidchrome socket sets give you the choice of socket you need to get the job done. Our sets have been designed with flexibility, quality and portability in mind.

You can easily carry a set anywhere around the workshop or take it in a vehicle to a worksite and be assured all your tools are secured and protected in compact and sturdy boxes. Socket Sets have been designed as the ideal addition to Sidchrome tool chests. You can choose and build your collection with unnecessary duplication.

FEATURING TORQUEPLUS™

Sidchrome hand sockets incorporating the TORQUEPLUS™ fastening system are identified in each product section of this catalogue. Apart from allowing extra torque, TORQUEPLUS™ also reduces the risk of fastener rounding, provides a greater opportunity to turn worn, rounded fasteners and meets aerospace specification. The Sidchrome range of sockets, ratchets and accessories offer design and durability to give you the professional advantage. All Sidchrome hand sockets are manufactured to rigid industrial specifications ensuring: concentric openings; large clearance holes; tight nut end tolerances.




Torque Plus

3

Torque Plus

TORQUEPLUS™ delivers power where you need it

With TorquePlus™ technology, our sockets grip fasteners tighter than a conventional socket can, enabling you to solidly seal fasteners and more easily break stubborn fasteners free.

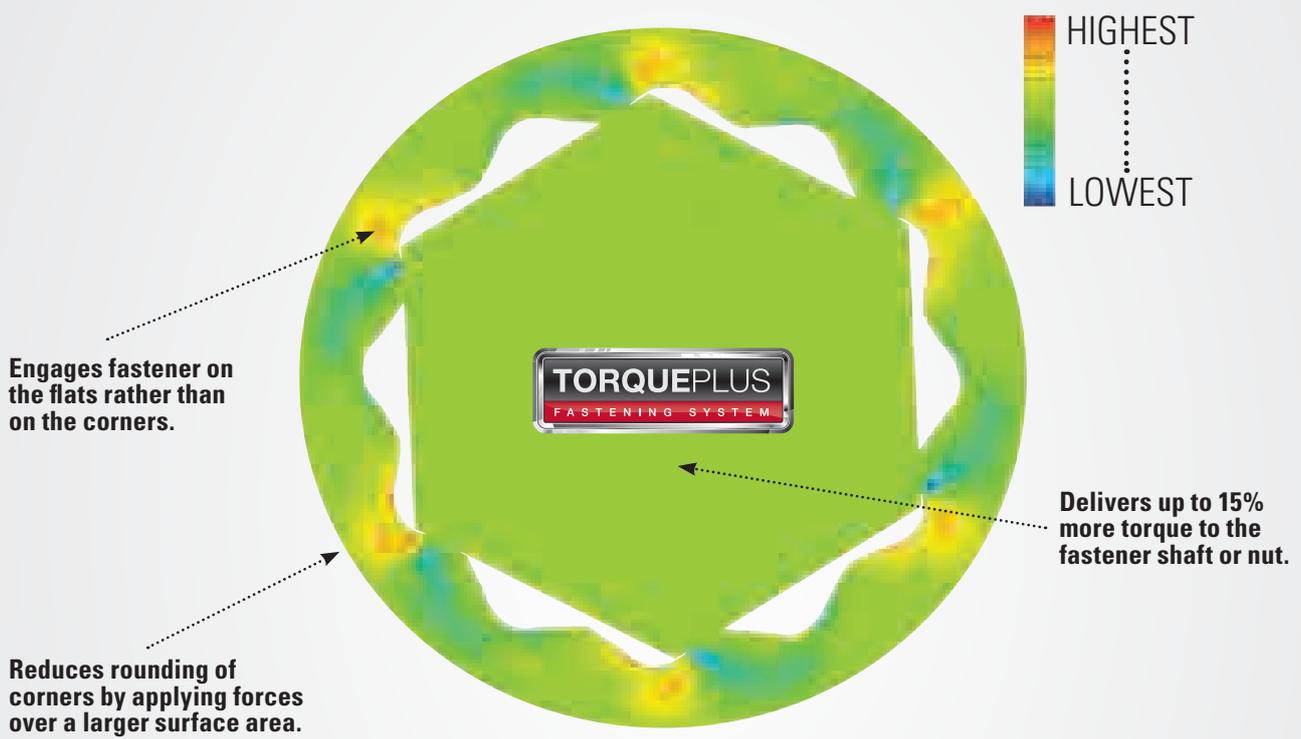

Conventional Sockets vs TORQUEPLUS™

The difference is in the points. A TorquePlus™ socket features rounded points which allow the socket walls to contact the fastener walls, keeping pressure off the points. This engineering change helps the socket find a longer, better grip on the flat of the fastener head. All Sidchrome® hand sockets feature the innovative TorquePlus™ design.



Pear Head Ratchets

3 Pear Head Ratchets

Sealed and Robust

Ultra-Resistant and Sealed Head for Longer Life

- Double sealing gasket: mechanism sealed and dust free.
- Maintenance free.
- Tested in aggressive conditions.



High Precision

- SCMT14970
1/2Dr 72 teeth for 5" increments dimensions 120mmL x 20mmW
- SCMT13970
3/8DR 72 teeth for 5" increments dimensions 210mmL x 25mmW
- SCMT12970
1/4DR 52 teeth for 7" increments dimensions 260mmL x 38mmW

Reduced Fatigue:

- Lighter ratchets (Than traditional lever ratchets.)
- Center of gravity moved towards the head for easier increment movements.

Palm Control System

- For more powerful loosening.



Recessed Reverse Lever

- Avoids accidental reversal and is easier to operate with gloved hands.



Comfortable:

- No discontinuity between the plastic and metal sections.


Hook Eye



The Fast Ratchet With Rotating Handle

Work Twice As Fast With The Rotating Handle

- The rotating handle allows fast access to improve productivity.
- Gain time, especially in confined work spaces.

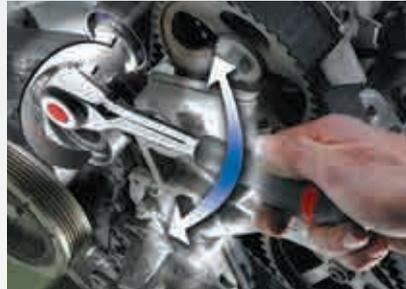

Maximum Comfort

- No need to hold the socket in the access phase = just place the socket on the screen and turn the handle.
- More comfort and access, especially in confined work spaces.

Socket Locking

- No need to secure the socket by hand when tightening threads or nuts with little or no locking.



Palm Control

- Ratchet head can be pressed for more powerful (un)tightening.



Also Available in NANO and DETECTION BOXES.



The Nano Concept

Ultra-Complete: 100% Bolting-Tightening

- Up to 38 tools, 1/4" drive square, in metric or inch dimensions, 6-or 12- point sockets, with standard / pear head / fast ratchet.



Ultra-Compact

- 50% more compact than 1/4" sets in regular box.



Practical: Save Time

- Easy set and tool selection thanks to tool pattern tag.
- Thanks to 3-sided set identification sticker.



Easy Tool Picking

- Bit strips rise automatically when opening the set.



- Socket picking by tilting.



- Auto-closing clasp: closes instantly.



Sockets, Bits, and Accessories held in case of tipping



Strength and Comfort by Sidchrome

- Sturdy closing system: metal clasp and hinge rod
- Bi-material body: - Box frame in PC/B > Rigid and unbreakable.
 - Skin in TPU = soft anti-slip > Good grip
 - > Does not slip on work surface
 - > Does not scratch the intervention zone (bodywork...)
- Plastic resistant to workshop solvents.

Detection Box Concept

Reinforced Safety

- The "Detection BOX" concept ensures instant availability check even when the box is closed.



Easy to Store

- Easy storage in all roller cabinet drawers (including 60 mm high).
- Adapts to 1/3 width of a roller cabinet module.
- Holds vertically.
- Does not slide, even on a smooth surface.



Easy to Carry

- With the extension used as a handle.

Practical

- Sockets locked securely in their slots and stay in place even when set is tipped over.

High Strength

- Thanks to their bi-material shell, metal clasps and metal hinge pins.





SCMT10175

60 Piece Metric/AF 1/4" & 1/2" Drive Socket & Spanner Set

Barcode: 9311927101758

1/4" Drive Sockets & Accessories

- 7 Metric Sockets - Standard: 4, 5, 6, 7, 8, 9, 10mm
- 7 AF Sockets - Standard: 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8"
- 3 Socket Accessories
- Ratchet, Reversible Male, 145mm
- Extension, Male & Female, 50mm
- Universal Joint

1/2" Drive Sockets & Accessories

- 12 Metric Sockets - Standard: 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 9 AF Sockets - Standard: 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"
- Spark Plug: 5/8 & 13/16"
- 4 Socket Accessories
- Ratchet, Reversible Male, 250mm
- Extension, Male & Female, 65mm
- Extension, Male & Female, 125mm
- Sliding T Handle, 240mm

Ring & Open End Spanner

- 10 Metric Ring & Open End Spanners: 8, 10, 11, 12, 13, 14, 15, 16, 17, 19mm
- 8 AF Ring & Open End Spanners: 1/4, 5/16, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16"

SCMT51141 Replacement Box Only

490 x 205 x 50mm



SCMT10184

35 Piece Metric/AF 1/2" Drive Socket & Spanner Set

Barcode: 9311927101840

1/2" Drive Sockets & Accessories

- 10 Metric Sockets - Standard: 8, 10, 12, 13, 14, 15, 16, 17, 18, 19mm
- 9 AF Sockets - Standard: 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 15/16"
- 4 Socket Accessories
- Ratchet, Reversible Male, 250mm
- Extension, Male & Female, 125mm
- Sliding T Handle, 240mm
- Universal Joint, Ball Type

Ring & Open End Spanner

- 6 Metric Spanners: 8, 10, 12, 13, 14, 17mm
- 6 AF Spanners 3/8, 7/16, 1/2, 9/16, 5/8, 3/4"

SCMT51141 Replacement Box Only

490 x 205 x 50mm



SCMT10236

31 Piece Metric 1/2" Drive Socket & Spanner Set

Barcode: 9311927102366

1/2" Drive Sockets & Accessories

- 14 Sockets - Standard: 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- Spark Plug: 5/8 & 13/16"
- 5 Socket Accessories
- Ratchet, Reversible Male, 250mm
- Extension, Male & Female, 125mm
- Extension, Male & Female, 250mm
- Adjustable Offset Handle, 375mm
- Universal Joint, Ball Type

Ring & Open End Spanner

- 12 Metric Spanners: 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm

SCMT51141 Replacement Box Only

490 x 205 x 50mm



SCMT10355

60 Piece Metric/AF 1/4" Drive Socket Set

Barcode: 9311927103554

1/4" Drive Sockets & Accessories

Metric Sockets

Standard:

10 4, 5, 6, 7, 8, 9, 10, 11, 12, 13mm

9 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2"

Deep:

10 4, 5, 6, 7, 8, 9, 10, 11, 12, 13mm

9 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2"

Socket Accessories

3 Ratchet, Flex handle, Universal Joint,

2 Extension: 50mm & 150mm

16 Ratchet Screwdriver bits

- Phillips: 1, 2, 3

- Pozidrive®: 1, 2, 3

- TORX®: 15, 20, 25

- Slotted: 4, 5.5

- Hex Head: 3, 4, 5

- 1/4" hex - 1/4" Square Drive adaptor

1 200mm Adjustable wrench

SCMT51116 Replacement Box Only

425 x 175 x 52mm



SCMT10356

42 Piece Metric/AF 1/2" Drive Socket Set

Barcode: 9311927103561

1/2" Drive Sockets & Accessories

19 8, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22, 23, 24, 27, 30, 32mm

15 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 7/8, 15/16, 1, 1-1/16, 1-1/8,

1-3/16, 1-1/4"

2 Spark Plug: 5/8" & 13/16"

3 Ratchet, 375mm Flex handle, Universal Joint,

2 Extension: 125mm & 250mm

1 200mm Adjustable Wrench

SCMT51141 Replacement Box Only

490 x 205 x 50mm



SCMT12105

30 Piece Metric/AF 1/4" Drive Socket & Spanner Set

Barcode: 9311927121053

1/4" Drive Sockets & Accessories

10 4, 5, 6, 7, 8, 9, 10, 11, 12, 13mm

9 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2"

2 Ratchet, Flex Handle,

2 Extension: 50mm & 150mm

Flex Head Spanner

7 8, 9, 10, 11, 12, 13, 14



SCMT10178

56 Piece Metric/AF 1/4" & 1/2" Drive Socket & Spanner Set

Barcode: 9311927101789

1/4" Drive Sockets & Accessories

- 7 4, 5, 6, 7, 8, 9, 10mm
- 7 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8"
- 3 Ratchet, Universal Joint, Extension: 50mm

1/2" Drive Sockets & Accessories

- 12 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 2 Spark Plug: 5/8" & 13/16"
- 2 Ratchet, Flex Handle,
- 2 Extension: 65mm & 125mm

Ring & Open End Spanner

- 12 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 9 1/4, 5/16, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"



SCMT13115

68 Piece Metric/AF 3/8" Drive Socket & Spanner Set

Barcode: 9311927131151

3/8" Drive Sockets & Accessories

Standard:

- 18 5, 6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22mm
- 11 1/4, 5/16, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 7/8"
- 2 Spark Plug: 5/8" & 13/16"

Deep:

- 10 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 7 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"

8 Socket Accessories

- 3 Ratchet, Flex Handle, Universal Joint
- 3 Extension: 75mm, 150mm & 250mm
- 2 3/8" Female to 1/4" Male, 3/8" Female to 1/2" Male

Ring & Open End Spanner

- 12 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm



SCMT14115

52 Piece Metric/AF 1/2" Drive Socket & Spanner Set

Barcode: 9311927141150

1/2" Drive Sockets & Accessories

- 16 8, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 23, 24, 25mm
- 11 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 7/8, 15/16, 1"
- 2 Ratchet, Flex Handle,
- 2 Extension: 125mm & 250mm

Ring & Open End Spanner

- 12 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 9 1/4, 5/16, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"



SCMT10800

79 Piece Metric/AF 1/4" & 1/2" Drive Tool Set

Barcode: 9311927108009

1/4" Drive Sockets & Accessories

- 7 4, 5, 6, 7, 8, 9, 10mm
- 7 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8"
- 4 Reversible Ratchet, 50mm Extension, Universal Joint Bit holder, Bit Holder
- 18 Screwdriver bits 1, 2, 3, 3, 4, 4, 4.5, 5, 5.5, 6, 7, 8, 10, 15, 20, 25, 30, 40

1/2" Drive Sockets & Accessories

- 12 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 7 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"
- 2 5/8", 13/16" Spark Plug
- 2 Reversible Ratchet, 220mm Adjustable Offset Handle
- 2 Extension: 65 & 125mm

Ring & Open End Spanner

- 10 8, 10, 11, 12, 13, 14, 15, 16, 17, 19mm
- 8 1/4, 5/16, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16"

Comes in blow moulded case



SCMT10801

61 Piece Metric 1/2" Drive Socket Set

Barcode: 9311927108016

1/2" Drive Sockets & Accessories

- 18 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 23, 24, 26, 27, 30, 32mm
- 15 5/8, 9/16, 1/2, 7/16, 3/8, 11/16, 3/4, 13/16, 7/8, 15/16, 1, 1-1/16, 1-1/8, 1-3/16, 1-1/4"
- 2 5/8, 13/16 Spark Plug
- 2 Reversible Ratchet, 220mm Adjustable Offset Handle
- 2 Extension: 125 & 250mm

1/4" Drive Bits

- 3 Bit Holder, Spinner Handle, Universal Joint
- 18 Screwdriver bits 1, 2, 3, 3, 4, 4, 4.5, 5, 5.5, 6, 7, 8, 10, 15, 20, 25, 30, 40

Comes in blow moulded case



SCMT10803

36 Piece Metric/AF 1/4" Drive Socket & Spanner Set

Barcode: 9311927108030

1/4" Drive Sockets & Accessories

- 10 4, 5, 6, 7, 8, 9, 10, 11, 12, 13mm
- 9 3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2"
- 4 Flex Handle, Ratchet, Extension: 50mm & 150mm

Ring & Open End Spanner

- 8 6, 7, 8, 9, 10, 11, 12, 13mm
- 5 1/4, 5/16, 3/8, 7/16, 1/2"

Comes in blow moulded case



SCMT10810

57 Piece Metric/AF 1/4" Drive Socket & Spanner Set

Barcode: 9311927108108

1/4" Drive Sockets & Accessories

- 10 4, 5, 6, 7, 8, 9, 10, 11, 12, 13
- 9 3/16, 7/32, 1/4, 9/32, 11/32, 3/8, 7/16, 1/2"
- 4 Reversible Ratchet, 50 & 150mm Extension, Adjustable Offset Handle

Screwdrivers

- 3 Tee Handle Ratchet Screwdriver, 50mm & 150mm Extension
- 18 Screwdriver bits
 - 1/4" Hex to 1/4" Square Drive Adaptor
 - Slotted 4, 5, 6
 - Hex, 3, 4, 5
 - Phillips 1, 2, 3
 - Pozidrive 1, 2, 3
 - Torx, T10, T15, T20, T25, T27

Ring & Open End Spanner

- 8 6, 7, 8, 9, 10, 11, 12, 13
- 5 1/4, 5/16, 3/8, 7/16, 1/2"

Comes in blow moulded case



SCMT10811

69 Piece Metric/AF 3/8" Drive Tool Set

Barcode: 9311927108115

3/8" Drive Sockets & Accessories

- 10 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- 9 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 7/8"
- 3 Ratchet, Universal Joint, Extension: 150mm

Ring & Open End Spanner

- 10 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm

Hex Key

- 9 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm
- 9 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

- 1 Inspection Mirror
- 1 Magnetic Pick Up Tool
- 1 250mm Adjustable Wrench
- 16 Ratchet Screwdriver bits
 - Phillips: 1, 2, 3
 - Pozidrive®: 1, 2, 3
 - TORX®: 15, 20, 25
 - Slotted: 4, 5.5
 - Hex Head: 3, 4, 5
 - 1/4" hex - 1/4" Square Drive adaptor

Comes in blow moulded case



SCMT10353

28 Piece Metric 1/2" Drive Tool Set

Barcode: 9311927103530

1/2" Drive Sockets & Accessories

- 19 8, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 23, 24, 26, 27, 30, 32mm
- 2 Ratchet, Flex handle,
- 3 Extension: 65mm, 125mm & 125mm

Pliers

- 3 Combination Plier 200mm, Diagonal Cutting 200mm, Long Nose 200mm
- 1 250mm Adjustable Wrench

Comes in blow moulded case