

Features

- Length: 1m
- Power: 240W
- Data rate: 20Gbps
- E-Marker chip
- 1 Right Angled Connector

RS PRO 1m USB4 20Gbps EPR Cable - Right Angled Connector

RS Stock No.: 0839501



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

USB4™ is the most recent update in the evolution of USB. USB4 is available with a bandwidth of 40Gbps or 20Gbps (this range supports 20Gbps). It is based on Thunderbolt 3 technology ensuring greater compatibility with all USB Type C and Thunderbolt 3 devices.

This cable supports Extended Power Range at 240W.

General Specifications


USB Type	USB4 20Gbps
Connector A	USB-C
Connector A Gender	Male
Connector A Style	Plug, straight
Connector B	USB-C
Connector B Gender	Male
Connector B Style	Plug, right angled
Data Transfer Rate	20Gbps
Outer Sheath Material	PVC
Sheath Colour	Black
Connector Plating	Nickel
Length	1m
Power	240W EPR

Approvals

Standards Met	CE UKCA ROHS REACH
---------------	--------------------

Similar Products

Stock No.	Brand	Product Name
0839496	RS PRO	1m USB4 40Gbps 240W EPR Cable - R/A Connector
0839501	RS PRO	1m USB4 20Gbps 240W EPR Cable - R/A Connector
0839503	RS PRO	2m USB4 20Gbps 240W EPR Cable - R/A Connector

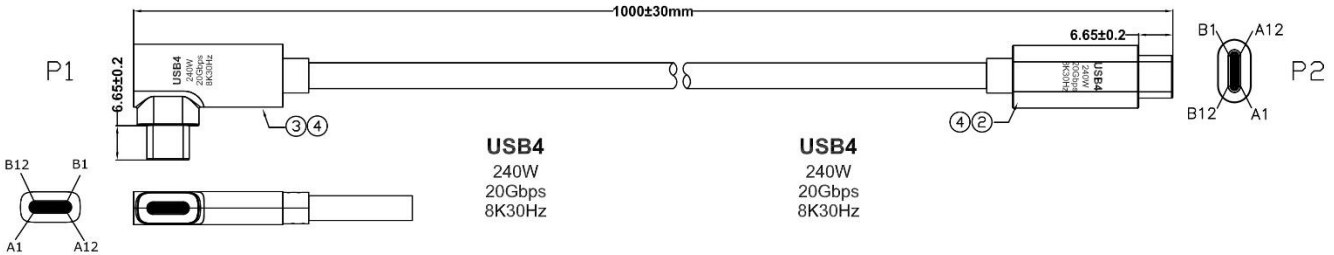

4	PVC~BLACK	10	G
3	USB4~CONNECTOR~WITH IC~NI PLATED	1	PCS
2	USB4~CONNECTOR~WITHOUT IC~NI PLATED	1	PCS
1	31AWG*4P+32AWG*1P+34AWG*4C+23AWG*1C+A2EB(85%TC)~OD:4.9MM~BLACK~PVC	1.0	m
NO.	DESCRIPTION	Q'TY	UNIT

