

Passlight LED

Wall mounted luminaires with downward light distribution

- Body and frame in strong pressure die-cast LM6M high corrosion resistance aluminium. Textured black full polyester powder finish
- Cover frame retained on two stainless steel safety chains
- Covers in prismatic polycarbonate or 9mm thick (nominal) thermally shock resistant borosilicate glass
- Fixings outside gasket line to preserve IP rating
- Clip-on nylon coated steel wire guard available
- Optional photocell control
- Tamper-resistant cover screws available
- High power white LEDs
- Fully electronic LED drivers
- Aluminium gear tray with LED bar
- High ambient temperature versions (details available on request)

IP65  

Ra	°K	L70/B10	P/U	%	R/Rx	PF	LL/W
70	4000	>60K	P	>85	R	>0.95	82.55




Retro-fit gear tray



Wire Guard

Range

LAMP	CAT. No.	APPROX. kg
POLYCARBONATE COVER		
24W LED	PL 14897	4.4
38W LED	PL 14899	4.4
GLASS COVER		
24W LED	PL 14898	6.6
38W LED	PL 14900	6.6
RETRO-FIT GEAR TRAYS		
24W LED	PL 14930	1.6
38W LED	PL 14931	1.6

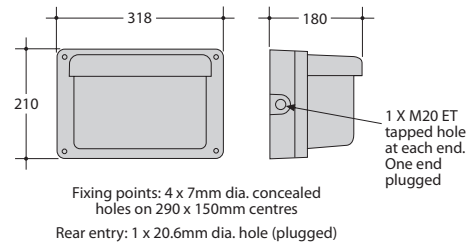

Accessories


DESCRIPTION	CAT. No.
Steel wire guard (black nylon coated)	WG 6237
Tamper-resistant screw kit	SCR 6758
Key for tamper-resistant screw kit	KY 6759

Options

DESCRIPTION	SUFFIX	CAT. No.
Photocell	PC	PL 14897PC etc.


Photometric Guide

POLYCARBONATE COVER

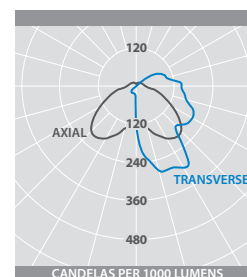

Luminaire Lumen Output
24W - 1520lm
38W - 2060lm

GLASS COVER

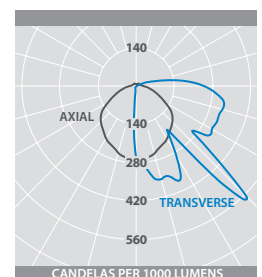

Luminaire Lumen Output
24W - 1650lm
38W - 2240lm