


NTN BEARING CORPORATION OF AMERICA

Head Office

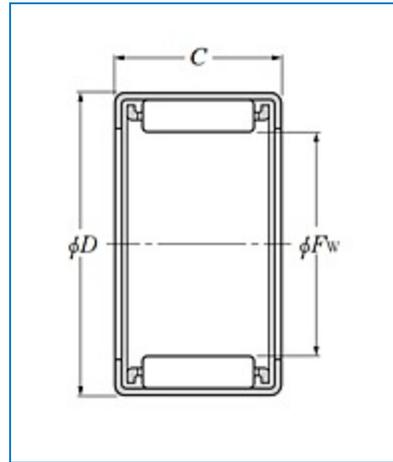
1600 E. Bishop Court, P.O. Box 7604

Mount Prospect, IL 60056-7604, U.S.A.

Phone: 847-298-7500

Fax: 847-699-9744

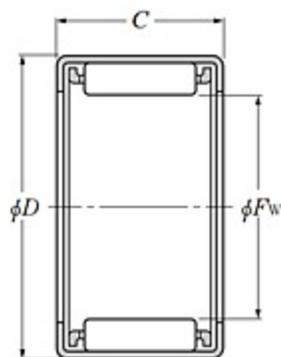
Toll Free: 800-323-2358

Email: mkt@ntnamerica.com
Website: www.ntnamericas.com
Item # HK3020D, Drawn Cup Needle Roller Bearing - HK, HMK Type

[Order Now](#) | [Technical Specifications](#) | [Dimensional Specifications](#)
Order Now
Ordering Options
FIND A DISTRIBUTOR
CONTACT NTN CUSTOMER SUPPORT SPECIALIST
ORDER THROUGH NTN DOL (AUTHORIZED DISTRIBUTORS ONLY)
Technical Specifications
Type

Drawn Cup Needle Roller Bearing

Bore Type	Round
Material	Steel
Cage Material	Steel
Limiting Speed - Oil	8000.0 RPM
Limiting Speed - Grease	5500 RPM
Bearing Type	Needle Roller Bearing
Configuration	One
Enclosure	Open
Radial Internal Clearance	CN
Precision	ISO Class 0
Oil Hole	w/ Oil Hole
Static Load Rating	8880 lbf 39500 N 39.50 kN
Dynamic Load Rating	5013 lbf 22300 N 22.30 kN
Weight	0.088 lb 0.040 kg
Operating Temperature Range	-40 to 250 °F -40 to 120 °C

Dimensional Specifications



Drawn Cup Needle Roller Bearing - HK, HMK Type - Dimensions

Fw	1.1810 in 30.000 mm
D	1.4567 in 37.000 mm
C	0.7874 in 20.000 mm