
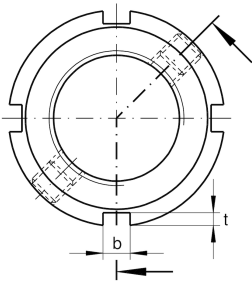


ZM30

Precision locknut

Precision locknut ZM, accessory ZM..

Technical information

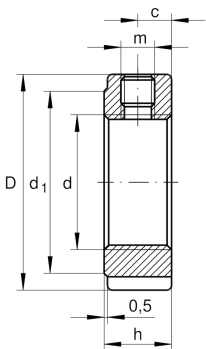

Main Dimensions & Performance Data

d	M30X1,5	Thread
D	45 mm	Outside diameter
h	12 mm	Height
M _A	5 Nm	Mounting torque set screw
F _{aB}	112,000 N	Breaking load, axial
M _L	70 Nm	Breakawag
M _{AL}	32 Nm	Mounting torque reference
M _M	0.304 kg*cm ²	Mass moment of inertia

≈m 76.458 g Weight

Dimensions

d ₁	40 mm	Plant diameter outside
t	2 mm	Hight retaining slot
b	5 mm	Width retaining slot
c	6 mm	Distance bore
m	M6	Threaded - threaded pin