


 
TD-51 (+)00 Precision Micro Screwdriver

For ultra precision and small screws

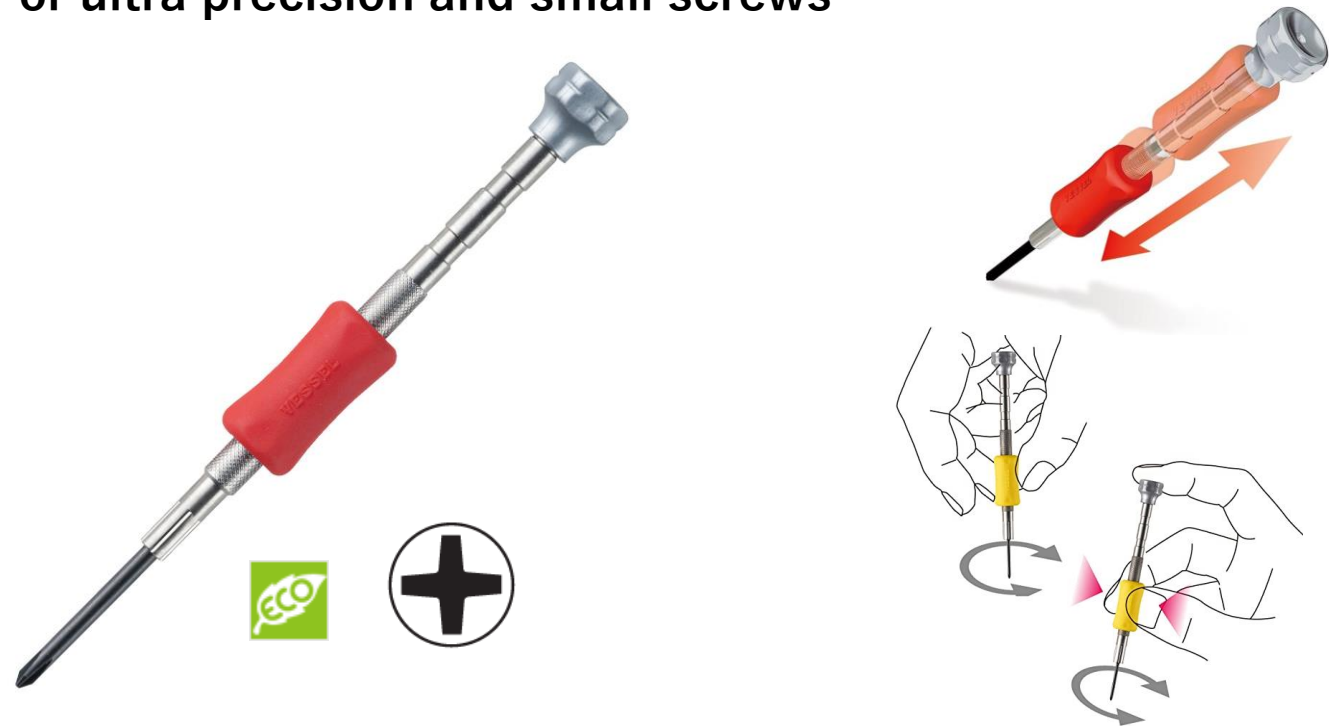

- Precision Phillips Tip; +0000, Perfect for world’s smallest screws PH 0000
- VESSEL's original Phillips tip profile for best fitting especially with Japanese(JCIS) screws
- The main body is made of stainless steel
- Rotative plastic en cap
- Anti-corrosion fully black oxide blade
- Stainless-made Knurled main body
- Color-code adjustable cushion grip at your useful position
- Both cushion grip and knurled section to be used for quick tightening
- For assembly, repair, and disassembly of precision devices, cameras, watches, glasses, etc.

PRODUCT SPECIFICATION

Index	Modèle	Product	Tip		Color Grip	Inner C/T unit	Outer C/T unit	EAN
251394	TD-51 (+)0000	Precision Screwdriver TD-51 PH 0000	PH 0000	17 1.4 97		10	100	4907587009289
251393	TD-51 (+)000	Precision Screwdriver TD-51 PH 000	PH 000	20 1.6 100		10	100	4907587009012
251357	TD-51 (+)00	Precision Screwdriver TD-51 PH 00	PH 00	24 2.5 104		10	100	4907587009029
251358	TD-51 (+)0	Precision Screwdriver TD-51 PH 0	PH 0	26 3.0 106		10	100	4907587009036
251359	TD-51 (+)1	Precision Screwdriver TD-51 PH 1	PH 1	26 3.0 106		10	100	4907587009043