



Store 'n' Go M.2 NVMe SSD Enclosure Kit

PN: 32261

The Store 'n' Go M.2 NVMe SSD enclosure is designed to unlock the full potential of NVMe technology, delivering fast and reliable performance for demanding storage tasks. With data transfer rates of up to 10Gbps and read/write speeds reaching up to 1000MB/s*, it is ideal for transferring large files, backing up data or expanding storage for laptops and desktop PCs.

Whether used for work, creative projects or general file storage, this enclosure provides a smooth and responsive external SSD experience in a compact, portable form.

- External M.2 NVMe SSD enclosure for PCIe-based SSDs
- USB 3.2 Gen 2 interface delivering data transfer speeds of up to 10Gbps
- High-performance external NVMe SSD enclosure with read/write speeds up to 1000MB/s*
- Tool-free design for fast and easy SSD installation
- Supports NVMe PCIe M-Key and B+M Key SSDs
- Compatible with M.2 SSD sizes: 2230 / 2242 / 2260 / 2280
- Supports UASP and TRIM for improved efficiency and SSD lifespan
- Integrated red rubber cable tidy keeps the cable neatly secured while travelling
- Optional heatsink included. This can be attached to the SSD to help maintain optimal operating temperatures



PN: 32261


System Requirements

- Windows 11 / Windows 10
- macOS
- Linux
- Android
- iOS
- USB-C or USB-A port

Specifications

- Interface: USB-C
- USB standard: USB 3.2 Gen 2
- Data transfer rate: Up to 10Gbps
- Read/write speed: Up to 1000MB/s*
- Supported SSD type: M.2 NVMe PCIe (M-Key, B+M Key)
- Supported SSD sizes: 2230 / 2242 / 2260 / 2280
- UASP & TRIM support: Yes
- Power: Via USB port
- Enclosure material: ABS + PC
- Colour: Black / Red
- Operating temperature: 0°C to +45°C
- Storage temperature: -20°C to +65°C
- Operating humidity: 20% – 65% RH

*For optimal performance, the drive must be connected to a USB 3.2 Gen 2 host controller or higher.

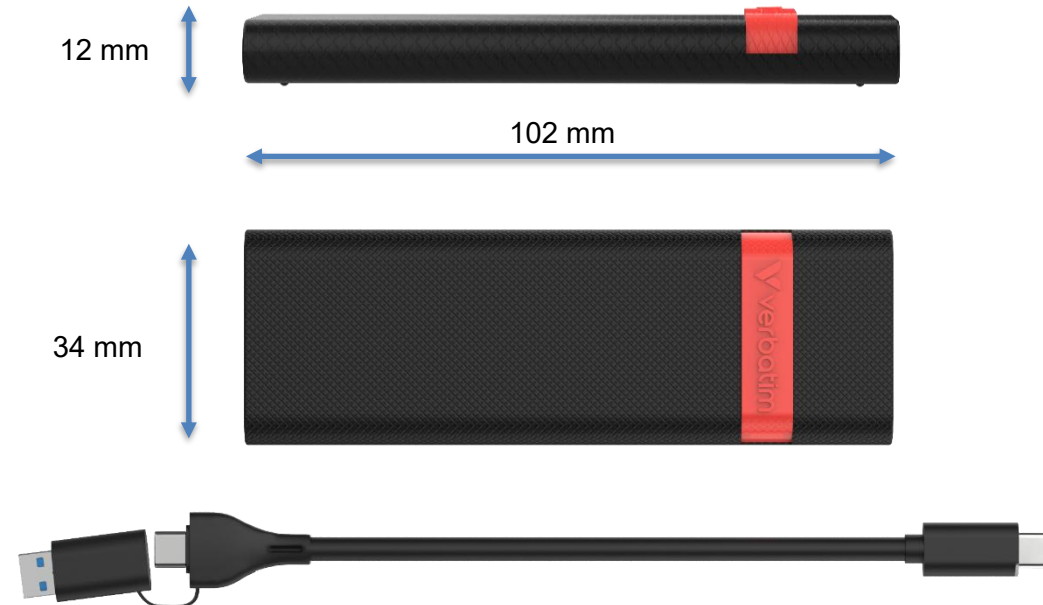

Languages

Front of pack: English

Back of pack: English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese

Pack Contents

- Store 'n' Go M.2 NVMe USB 3.2 Gen2 SSD Enclosure Kit
- USB-C to USB-C cable with attached USB-C to USB-A adapter
- Optional heatsink
- Quick Start Guide

Reorder No.	Description	Tariff Code	Barcode	EAN-128	EAN-14
32261	Verbatim Store 'n' Go M.2 NVMe USB 3.2 Gen 2 SSD Enclosure Kit	84733080	0023942322610	(02)00023942322610(37)10(91)468	50023942322615

Logistic Info	
Product Dimensions L x W x H	102 x 34 x 12 mm
Product Weight	18 g (without cable), 32 g (with cable)
Units per Pack	1
Pack Dimensions L x W x H	110 without hanger / 130 with hanger x 70 x 20 mm
Pack Weight	55 g
Units per Inner Carton	n/a
Inner Carton Dimensions L x W x H	n/a
Inner Carton Weight	n/a
Units per Outer Carton (MOQ)	10
Outer Carton Dimensions L x W x H	235 x 153 x 103
Outer Cartons Weight	740
Outer Cartons per Layer	30
Layers per Pallet	9
Units per Pallet	2700