

Universe	Professional
Type	Verticality
Category	Helmets
Subcategory	Comfortable helmets




VERTEX®

The VERTEX helmet is very comfortable, thanks to its six-point textile suspension and CENTERFIT and FLIP&FIT systems, which guarantee that the helmet fits securely on the head. The adjustable-strength chinstrap makes it ideal for both work at height and on the ground. The unventilated outer shell protects against electrical hazards, molten metal splash and flames. With its potential for integration of a Petzl headlamp, hearing protection, and multiple accessories, it is an entirely modular helmet, thus meeting the specific additional needs of professionals.



The six-point webbing suspension system adapts to the shape of the head to provide maximum comfort.

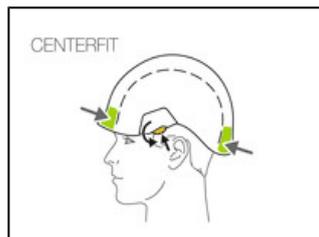

The CENTERFIT feature allows perfect centering of the helmet on the head, thanks to its two side adjustment wheels.



The clip of the DUAL chinstrap allows the worker to adjust chinstrap strength in order to adapt the helmet to different environments: work at height (EN 12492) or on the ground (EN 397).



With its potential for integration of a Petzl headlamp, hearing protection, and multiple accessories, it is an entirely modular helmet, thus meeting the specific additional needs of professionals.

Short Description Comfortable helmet

Selling Points

- Very comfortable:
 - six-point textile suspension adapts perfectly to the shape of the head
 - CENTERFIT feature allows perfect centering of the helmet on the head, thanks to its two side adjustment wheels
 - FLIP&FIT system allows the headband to be positioned in a low position, guaranteeing that the helmet fits securely on the head. The system folds into the shell for easy storage and transport
 - comes with interchangeable standard comfort foam
- Protection designed for work at height and on the ground:
 - DUAL chinstrap allows the worker to adjust chinstrap strength in order to adapt the helmet to different environments: work at height (EN 12492) or on the ground (EN 397). The clip has two positions, corresponding to two uses: high strength, limiting the risk of losing the helmet during a fall, and low strength, limiting the risk of strangulation if the helmet is snagged while the user is on the ground
 - shock absorption achieved through deformation of the outer shell
 - unventilated outer shell protects against electrical hazards, molten metal splash and flames
- Modular accessories:
 - eye shield with EASYCLIP side attachment system for easy installation
 - Petzl headlamp with mounts, or headlamp with elastic headband
 - helmet protector keeps the shell free from soiling and paint splash
 - nape protector provides effective sun and rain protection for the nape of the neck
 - nametag holder allows user to be easily identified
 - changeable chinstrap and foam
 - hearing protection
 - available in seven colors: white, yellow, red, black, orange, blue and green
 - also comes in two high-visibility versions: yellow and orange

Specification

- Head circumference: 53-63cm
 - Weight: 490g
 - Material(s): ABS (acrylonitrile butadiene styrene), nylon, polycarbonate, high-strength polyester, polyethylene
 - Certification(s): CE, EN 397, EN 12492 (1), EN 50365, ANSI Z89.1 Type I Class E, EAC, AS/NZS 1801
 - (1) meets all requirements of the EN 12492 standard, except the ventilation requirement.
-

Specifications by reference

Reference(s)	A010AA00	A010AA01	A010AA02	A010AA03
				
Color(s)	white	yellow	red	black
Made in	FR	FR	FR	FR
Guarantee	3 years	3 years	3 years	3 years
Packing	1	1	1	1
Case quantity	8	8	8	8
EAN	3342540827257	3342540827264	3342540827271	3342540827288

Reference(s)	A010AA04	A010AA05	A010AA06
			
Color(s)	orange	blue	green
Made in	FR	FR	FR
Guarantee	3 years	3 years	3 years
Packing	1	1	1
Case quantity	8	8	8
EAN	3342540827295	3342540827301	3342540827318