


Solid black standard Rubber Trolley Wheel 125mm Hub 12, 130kg

Standard Rubber-tyred wheel

PRODUCT

Article number

1250512

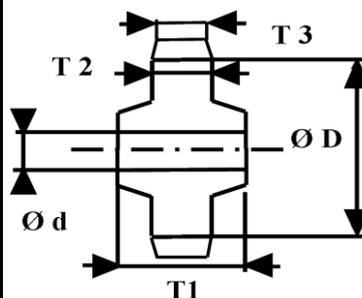

Product Details

Wheel Rim : riveted steel plates. Bright zinc-plated protection.

Tyre : solid, black standard rubber.

Hub : symmetrical, with roller bearing.

Specifications

| | |
|----------------------------|----------------|
| Wheel Diameter - ØD ± 1% | 125 mm |
| Hub Type | Roller bearing |
| Hub Length T1 | 45 mm ±1 |
| Width of Tread T2 | 38 mm ±1 |
| Width of Tread-on floor T3 | 28 mm ±1 |
| Axle Hole Ø d | Ø 12 mm |
| Hardness of tread A ±4 | A 82 Shore |
| Load capacity | 130 Kg |
| Temperature | -20 / +60 °C |
| Weight | 0,5 Kg |
| | |
| | |
| | |

TECHNICAL DATA

Applications :

Quiet materials handling with horizontal effort.

Resistance to tyre shedding and side impact.

Lightweight.

Suitable for trolleys on industrial floors (factory, warehouse, sack truck, ...)