



PRODUCT DATASHEET

Datasheet creation date: 2025/05/28 10:42 (UTC)

MOTION & CONTROL
NSK



23120CE4

Spherical Roller Bearings

Boundary Dimensions


d	100	mm	Bore diameter
D	165	mm	Outside diameter
B	52	mm	Width
r (min.)	2	mm	Chamfer dimension

Basic Load Ratings

Cr	345000	N	Basic dynamic load rating
C0r	530000	N	Basic static load rating

Speeds

Thermal Speed Rating (Oil-bath)	2800	min-1	Oil-bath lubrication subject to conditions outlined in ISO 15312
Grease	1700	min-1	Grease lubrication
Oil (Oil-bath)	2200	min-1	Oil-bath lubrication

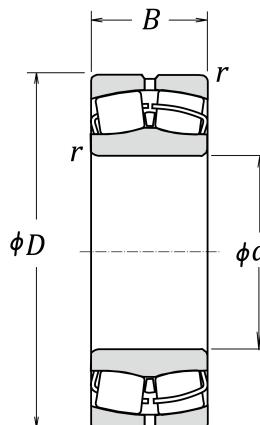

Abutment and Fillet Dimensions

da (min.)	110	mm	Diameter of shaft abutment
da (max.)	113	mm	Diameter of shaft abutment
Da (min.)	144	mm	Diameter of housing abutment
Da (max.)	155	mm	Diameter of housing abutment
ra (max.)	2	mm	Radius of shaft or housing fillet

Calculation factors

e	0.3	Constant
Y2	3.4	Axial load Factors
Y3	2.3	Axial load Factors
Y0	2.2	Axial load Factors

Mass

Mass approx.	4.38	kg	Mass approx.
--------------	------	----	--------------

