




Product Datasheet

ENGLISH

Polyamide Terminal Blocks with Vertical Plug

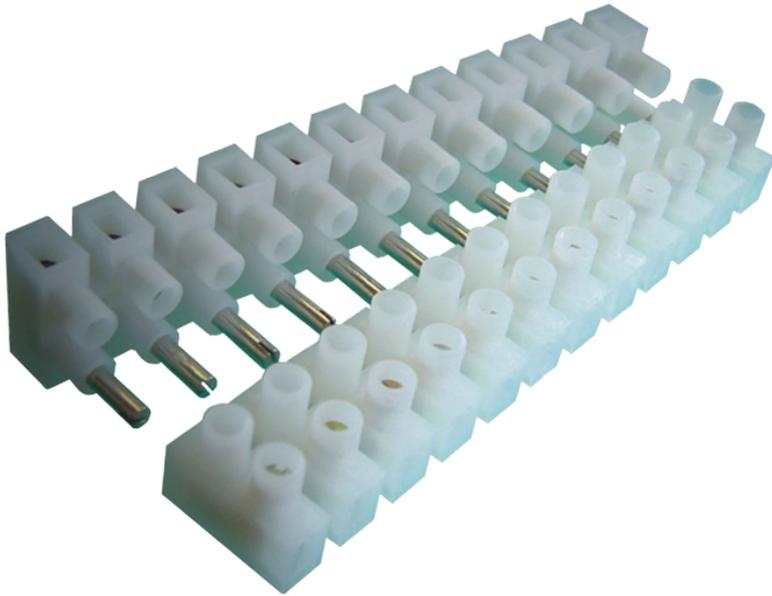

Specification

HOUSING: POLYAMIDE (PA 66)

INSERTS: NICKEL PLATED BRASS

SCREWS: GALVANISED STEEL

TEMP.: 105°C

COLOR: NATURAL

Standard: VDE & MULTI-APPROVALS

Features:

SEMI-RIGID;

FLAME RETARDANT.;


HIGH TEMPERATURE;

ALL SCREWS ARE CAPTIVE & RAISED FOR EASY WIRING

Dimensions



Dimensions

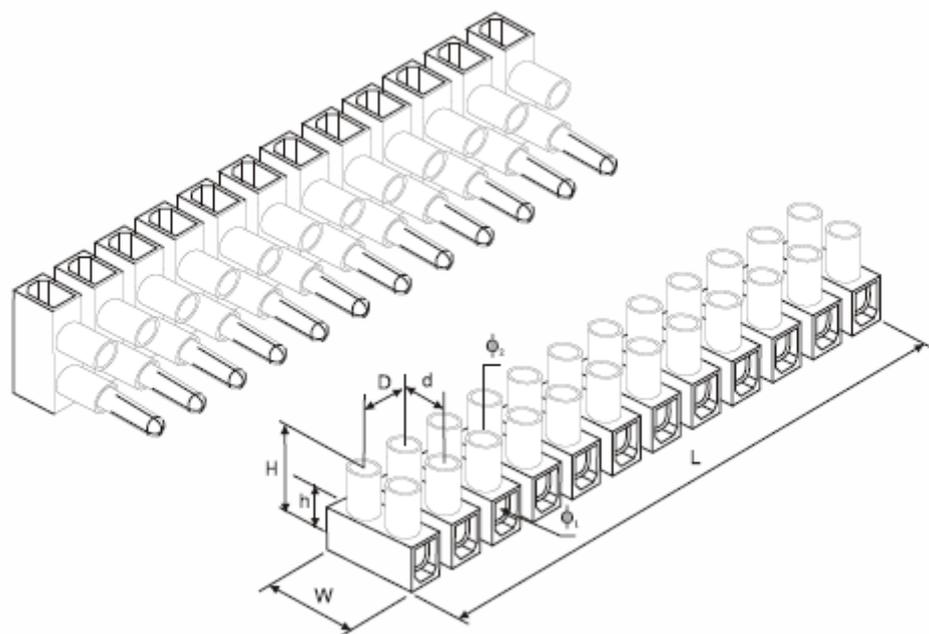

RS CODE	CROSS SECTION	CURRENT RANGE	RATED VOLTAGE	DIMENSIONS (mm)							
				W	L	Φ1	Φ2	D	d	H	h
8869245	2.5 mm ²	2.5~20A	450V	18	94	2.8	2.5	7.2	5.6	13	7
8869248	4 mm ²	3~24A	450V	20	115	3.5	3.2	10	8	15	8
8869242	6 mm ²	5~32A	450V	24	138	4.2	3.5	12	9.5	19	10

Cross Section: rated for rigid wire and cables (if for flexible wire, it should be reduced one-step, i.e. 6mm² is 4mm²)
Φ1 wire entry hole diameter **Φ2** fixing hole diameter