



Right-Angle Shapes, VG style/MIL style


Helashrink 1100 Series, with rib, low profile

Features and Benefits


- Lightweight, low profile, compact strain relief and mechanical protection
- Typically used on airborne harnesses



1123-1-G Supplied and recovered.

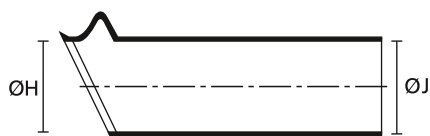

a: Expanded form (supplied)

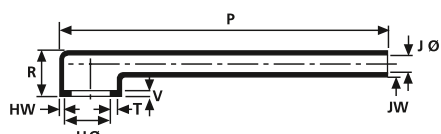

b: Fully recovered form (after heating)



For Material / Adhesive information please refer to page 244.

TYPE	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10%	R ± 10%	HW ± 20%	JW ± 30%	T ± 10%	V ± 10%	Designation as per VG-Norm	Article-No.
1121-1-G	22.0	12.0	22.0	6.5	70.0	19.0	1.5	1.1	1.0	3.0	VG95343T06F001A	411-21180
1122-1-G	25.5	15.0	25.0	7.5	79.0	20.0	1.5	1.1	1.0	3.0	VG95343T06F002A	411-22180
1123-1-G	29.0	19.0	29.0	8.5	89.0	21.0	1.8	1.1	1.0	3.0	VG95343T06F003A	411-23180
1124-1-G	34.0	23.0	34.0	10.0	102.0	22.0	1.8	1.1	1.0	3.0	VG95343T06F004A	411-24180
1125-1-G	37.0	30.0	37.0	11.0	108.0	24.0	2.0	1.1	1.7	3.0	VG95343T06F005A	411-25180
1126-1-G	43.5	34.0	43.5	12.0	121.0	27.0	2.0	1.1	1.7	3.0	VG95343T06F006A	411-26180
1127-1-G	50.0	41.5	50.0	14.5	132.0	30.0	2.3	1.4	1.7	3.0	VG95343T06F007A	411-27180
1128-1-G	62.5	47.0	62.5	18.0	133.0	33.0	2.5	1.4	2.0	3.0	VG95343T06F008A	411-28180
1129-1-G	69.0	60.0	69.0	20.0	137.0	35.0	2.5	1.4	2.0	3.0	VG95343T06F009A	411-29180
1141-1-G	82.0	67.0	82.0	23.0	140.0	45.0	2.5	1.4	2.0	3.0	VG95343T06F010A	411-41180

All dimensions in mm. Subject to technical changes.