

## Datasheet

### **RS Pro P13.5s Filament Indicator Lamp, Clear, 2.4 V, 835 mA, 15h**

RS Stock No: **655-9148**



## Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 2.4 V and current rating of 835 mA. The lamp has 15 h life.

## Features and Benefits

- Olive shape B3 - 11 mm glass
- Alternative to vacuum types
- P13.5s prefocus base



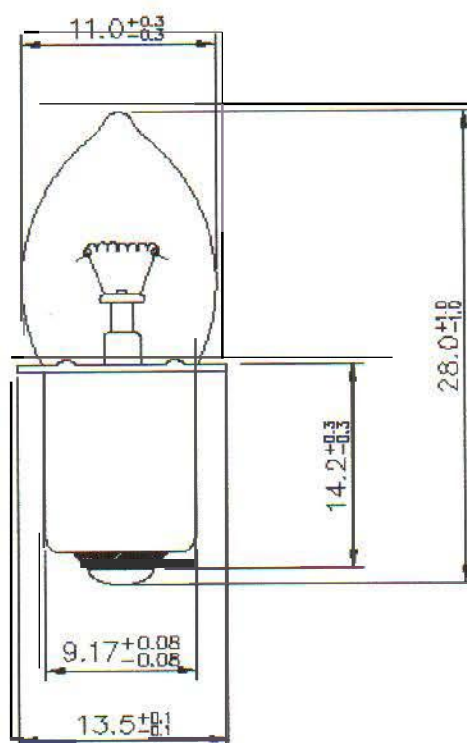
ENGLISH

### Specifications:

Current Rating	835 mA
Diameter	11.3 mm
Lamp Base	P13.5s
Lamp Size	B3 1/2
Length	29 mm
Lens Colour	Clear
Life Hours	15 h
Luminosity	19 lm
Voltage Rating	2.4 V

RS Stock No.

6559148

*DRAWING - I*


Unit : mm

1. Structure	Bulb Type	B3 1/2
	Bulb Diameter	Ø 11.3Max.
	Length	29.0Max
	Base Type	P13.5s KRP
2. Design Characteristics	Voltage	2.4V
	Amperage	835mA± 10%
	Gas Type	Krypton gas-filled
	Luminous Flux	19Lm± 20%
	Life Hours	15Hrs