


# FOOT M10 D90 GD L=88

Article Nr. 21.1862/0

[See the product on the website →](#)

[Download CAD Files →](#)

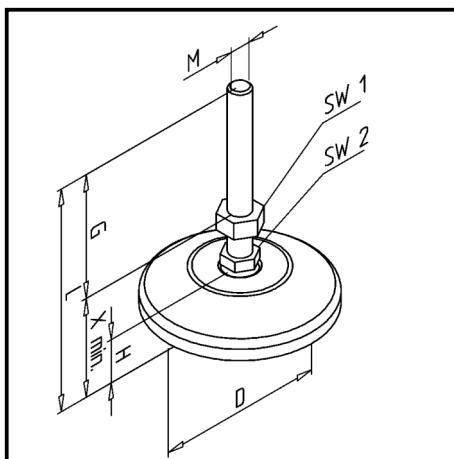

## TECHN. DATA / ITEMS SUPPLIED

- Plate die-cast aluminum powder-coated, grey
- Anti-slip license NBR, black
- Spindle steel, galvanized
- Lock nut steel, galvanized
- Angular compensation up to 3°
- D = 90 mm  
H = 27 mm  
Load capacity max. 4000 kg
- Dimension G = 52.6 mm  
Dimension X = 37.5 mm  
SW1 = 17 mm  
SW2 = 17 mm  
Dimension L = 89,5 mm
- Weight = 0.259 kg/piece

## APPLICATIONS

- Height adjustable constructions of all kinds
- Protective equipment, tables, showcases
- Conveyors, system workstations

## ASSEMBLY

- Direct in central drilling of the profiles
- For threads larger than M12, the hinged feet must be mounted in conjunction with the connection plate
- For profiles 45 x 90 und 90 x 90 a base and transport plate is required, if the feet are to be positioned centrally.