
 


 



 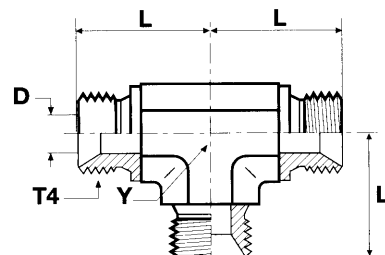


 
# JMK4



 T4 BSPP	XXXXX-XX-XX	 PN	 P <sub>max</sub>	D (mm)	L (mm)	Y (mm)		
							S	SS
1/8	<b>2JMK4</b>	350	500	3,5	16,6	11	●	
1/4	<b>4JMK4</b>	350	500	4,7	27,8	19	●	
3/8	<b>6JMK4</b>	350	500	7,9	31,7	22	●	
1/2	<b>8JMK4</b>	200	260	11,1	37,0	27	●	
5/8	<b>10JMK4</b>	200	260	14,3	39,0	27	●	
3/4	<b>12JMK4</b>	200	260	16,7	41,6	33	●	
1	<b>16JMK4</b>	120	180	22,2	49,7	41	●	
1 1/4	<b>20JMK4</b>	105	150	28,6	54,4	48	●	
1 1/2	<b>24JMK4</b>	105	150	33,3	53,7	48	●	
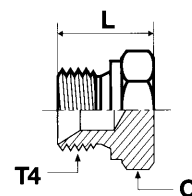
# PNMK4



 T4 BSPP	XXXXX-XX-XX	 PN	 P <sub>max</sub>	C (mm)	L (mm)		
						S	SS
1/8	<b>2PNMK4</b>	350	500	14	14,3	●	
1/4	<b>4PNMK4</b>	350	500	19	18,8	●	
3/8	<b>6PNMK4</b>	350	500	22	20,5	●	
1/2	<b>8PNMK4</b>	200	260	27	24,0	●	
5/8	<b>10PNMK4</b>	200	260	30	24,0	●	
3/4	<b>12PNMK4</b>	200	260	32	26,5	●	
1	<b>16PNMK4</b>	120	180	41	30,2	●	
1 1/4	<b>20PNMK4</b>	105	150	50	38,7	●	
1 1/2	<b>24PNMK4</b>	105	150	55	42,7	●	
2	<b>32PNMK4</b>	70	90	70	48,2	●	

Complétez la référence avec la lettre correspondant à la matière choisie:

S = Acier SS = Acier inoxydable

(Exemple: **4JMK4S**)