


Product data sheet

Characteristics

NSYCVF65M230PF

Climasys forced vent. 65 m3/hour, 230V, with outlet grille plastic and filter

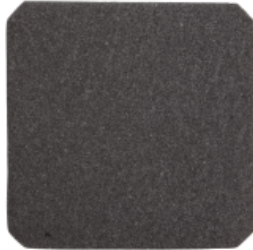

Main

Range	ClimaSys
Product name	ClimaSys CV
Product or component type	Fan
Type of ventilation filter	Standard
Air flow	Free flow rate without filter or grille: 170 m3/h Free flow rate with standard filter: 65 m3/h at 50 Hz
Input voltage	230 V 50/60 Hz

Complementary

Height	External: 124 mm
Width	External: 124 mm
Depth	External: 55 mm
Cut-out dimensions	Ø 108 mm
Material	ABS (acrylonitrile butadiene-styrene) for outlet grille Polyurethane foam for filter
Colour	Outlet grille: black Filter: black
IP degree of protection	IP20
Device composition	1 outlet grille front 1 axial motor 2 protective grille on the front and rear surfaces 1 filter front of axial motor

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0940 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months 18 months
-----------------	---------------------