

# ALPHA

## 3470IDP100P62

EAN TBA

Swivel housing made of pressed steel, zinc electroplated, double ball bearing swivel head, wheel axle with crimp nut and bolt. Lubricated with high temperature food grade grease. Wheel made of die cast aluminum. Tread: Heat resistant non-toxic synthetic material and non-marking. Bearing: Precision bearing, lubricated with high temperature food grade grease.



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

|                        |                  |
|------------------------|------------------|
| Wheel diameter         | 100 mm           |
| Wheel width            | 30 mm            |
| Size of Plate          | 105 x 80 mm      |
| Plate hole centres     | 82/72 x 62/52 mm |
| Plate hole             | 10 mm            |
| Offset                 | 40 mm            |
| Swivel Interference    | 180 mm           |
| Overall height         | 128 mm           |
| Temperature            | - 30 / + 280 °C  |
| Standard               | EN_12532         |
| Weight                 | 0.98 kg          |
| Swivel Radius          | 90 mm            |
| Hardness of tread      | Shore A 80       |
| Load capacity          | 200 kg           |
| Load capacity (static) | 400 kg           |

### Dimensions

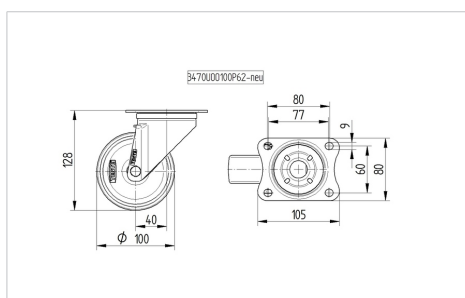

### Advantages at a glance

|                      |           |
|----------------------|-----------|
| Roll performance     | ● ● ● ● ● |
| Movement noise       | ● ● ● ○ ○ |
| Attrition            | ● ● ● ● ○ |
| Corrosion resistance | ● ● ● ● ○ |