


Fire Rated LED downlight with adjustable Colour Temperature



MLA part code	FR8WT
Description	Fire Rated LED downlight with adjustable Colour Temperature
ErP Class	A+
Weight (kg)	0.33
Wattage (W)	8
Lumens (lm) Warm white	620
Lumens (lm) Cool white	630
Lumens (lm) Daylight	640
Efficacy (lm/W) Warm white	77
Efficacy (lm/W) Cool white	78
Efficacy (lm/W) Daylight	80
P.F	>0.9
Overall dimensions (mm)	87 (d) 90 (r)
Cut Out (mm)	65
CCT	3000K, 4000K and 6000K
LED Colours	Warm white, Cool white and Day Light
CRI	>80
Beam angle:	60°
Life span (Hrs)	30,000
Input Voltage	Mains 230V 50Hz
Construction	Metal
Class	Class II
IP rating	IP65
Warranty	5 Years
Additional accessories	<ul style="list-style-type: none"> • FR8WTBEXC (Chrome bezel) • FR8WTBEZCBR (Brushed chrome bezel) • FR8WTBEZW (White bezel)
Photometric data	Yes
Dimmable	Yes
Origin of Manufacture	China
Quality assurance system	ISO9001
Declaration of Conformity (held on file)	Yes
Manufactured in accordance with	EN60598

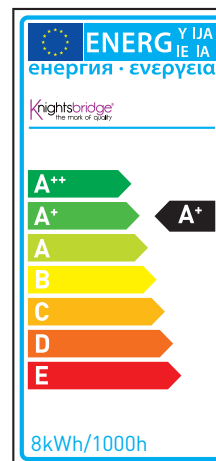