

AI 10-12 RD-2500 - Ferrule

2100041

<https://www.phoenixcontact.com/gb/products/2100041>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Ferrule, Length contact range: 12 mm, sleeve length: 22 mm, color: red

Your advantages

- The ferrules with plastic sleeve are made from soft tin-plated electrolytic copper
- The insulation reliability of close connections is increased and the splicing of wires is prevented

Commercial data

Item number	2100041
Packing unit	2,500 pc
Minimum order quantity	10,000 pc
Sales key	BH3411
Product key	BH3411
GTIN	4067923215108
Weight per piece (excluding packing)	22.22 g
Customs tariff number	85369010
Country of origin	DE

AI 10-12 RD-2500 - Ferrule



2100041


<https://www.phoenixcontact.com/gb/products/2100041>

Technical data

Product properties

Product type	Cable end sleeve
Product property	UL certified
	Made from soft tin-plated electrolytic copper
	Correspond to the requirements of DIN 46228-1 and UL 486F in terms of size
	Plastic collar made of polypropylene
	Halogen-free
	Long/short-term temperature: +105°C/+120°C

Dimensions

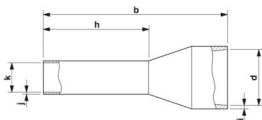Dimensional drawing	
Sleeve length	22 mm
Length contact range	12 mm
Ferrule diameter	4.6 mm
Sleeve wall thickness	0.2 mm
Insulating collar thickness	0.3 mm
Inner dimensions of the insulating collar	7.5 mm

Material specifications

Color	red (RAL 3001)
Flammability rating according to UL 94	HB
Coating	galvanically tin-plated
Surface characteristics	Tin-plated
Components	free from silicone and halogen

Mechanical properties


Technical data	
Sleeve length	22 mm

Standards and regulations

Design according to standard	DIN 46228-4:2020-03
------------------------------	---------------------

Drawings

Dimensional drawing

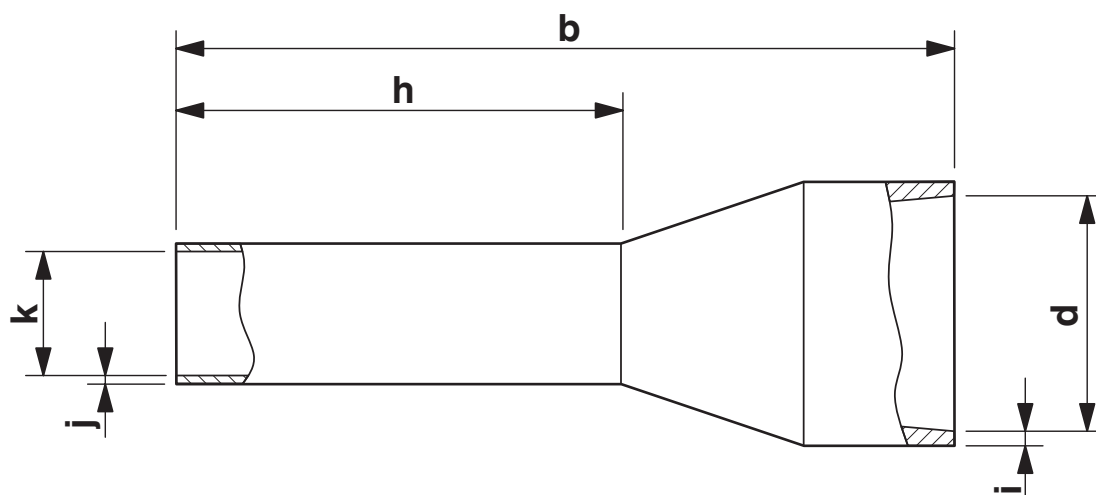

Sleeve length (b), length contact range (h), insulating collar inner dimension (d), sleeve diameter (k), insulating collar thickness (i), sleeve wall thickness (j)

AI 10-12 RD-2500 - Ferrule

2100041

<https://www.phoenixcontact.com/gb/products/2100041>



Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/gb/products/2100041>



cULus Listed

Approval ID: E488001

AI 10-12 RD-2500 - Ferrule



2100041

<https://www.phoenixcontact.com/gb/products/2100041>

Classifications

ECLASS

ECLASS-13.0	27400201
-------------	----------

ETIM

ETIM 9.0	EC000005
----------	----------

AI 10-12 RD-2500 - Ferrule

2100041

<https://www.phoenixcontact.com/gb/products/2100041>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk