


## LUMINESTRA 8 W/830

Linear LED systems for recessed or under-cabinet mounting / Extremely wide distribution

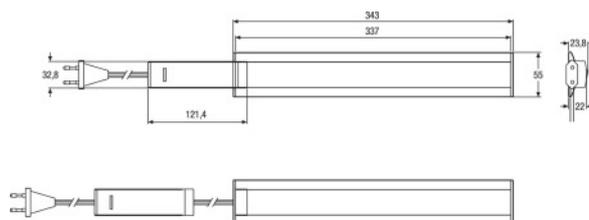

---

## Technical data

---

### Electrical data

Operating mode	ECG
Nominal wattage	8 W
Type of current	AC
Nominal voltage	220...240 V
Mains frequency	50...60 Hz

### Photometrical data

Color rendering index Ra	≥ 80
Color temperature	3000 K
Light color as per EN 12464-1	Warm white
Luminous efficacy	54 lm/W
Luminous flux	435 lm
Light color	830

### Light technical data

Beam angle (designation)	Wide
--------------------------	------

### Dimensions & weight

Product weight	356.00 g
Length	448.0 mm
Width	55.0 mm
Connection cable length	1.6 m

### Functional component FC1

FC1 Functional component	Housing
FC1 Material	Aluminum
Color	Silver



### Functional component FC2

FC2 Functional component	protection cap
Color	White

### Colors & materials

Product color	Silver
Surface feature of cover	Opal

**Additional product data**

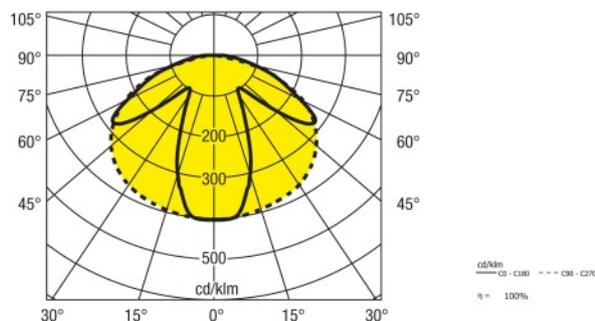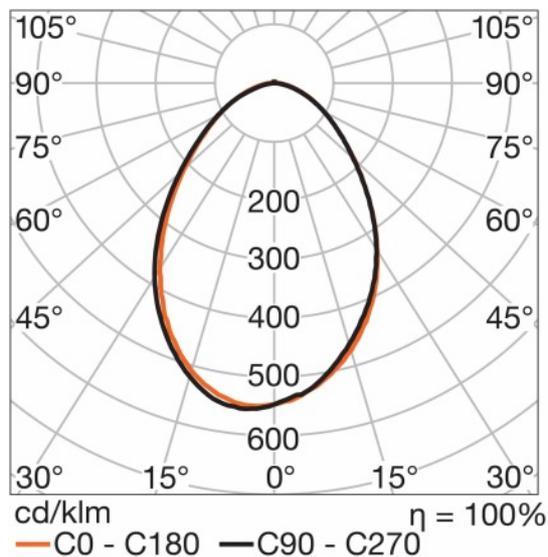

LDC typ polar

Spectral power distribution

<b>Lamp designation according to LBS</b>	OSLON LED
<b>Connection cable</b>	Pre-assembled
<b>Light source included</b>	Yes
<b>Cover</b>	Cover

**Capabilities**

<b>Type of installation</b>	Surface-mounted
<b>LED module replaceable</b>	Not replaceable

**Certificates & standards**

<b>Standards</b>	CE; ENEC 10 VDE
<b>Protection against ignition and fire</b>	F,MM
<b>Protection class</b>	II
<b>Type of protection</b>	IP20
<b>EEL of included LED module</b>	A++
<b>Certification</b>	CE, ENEC 10, VDE

**Country specific categorizations**

<b>Order number</b>	0FA2271AK830
---------------------	--------------

## Product datasheet

---

### Country specific information

---

Product code	METEL code	SEG number	STK number	UK Org
4008321524461	OSRLUMLED73092	7550191	4110500	-

---

---

### Logistical Data

---

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321524478	LUMINESTRA LED 8 W/830	Shipping carton box 4	128 mm x 70 mm x 631 mm	5.65 dm <sup>3</sup>	1857.40 g

---

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

### Disclaimer

---

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.