



SIVACON, base, with side cable entry, T: 1000 mm, W: 1000 mm, zinc-plated

Model	
product brand name	SIVACON
design of the product	With lateral cable entry
design of the surface	zinc plated
design of the product EMC version	No
material	steel
product component	
• ventilation	No

Mechanical Design	
width	1 000 mm
depth	1 000 mm
net weight	15 000 g


Approvals Certificates

General Product Approval	Test Certificates	other
	 EG-Konf.	
	Special Test Certificate	Confirmation
		Miscellaneous

other	Environment
Miscellaneous	
	Environmental Confirmations

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1000-2UB51-2>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1000-2UB51-2>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1000-2UB51-2
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

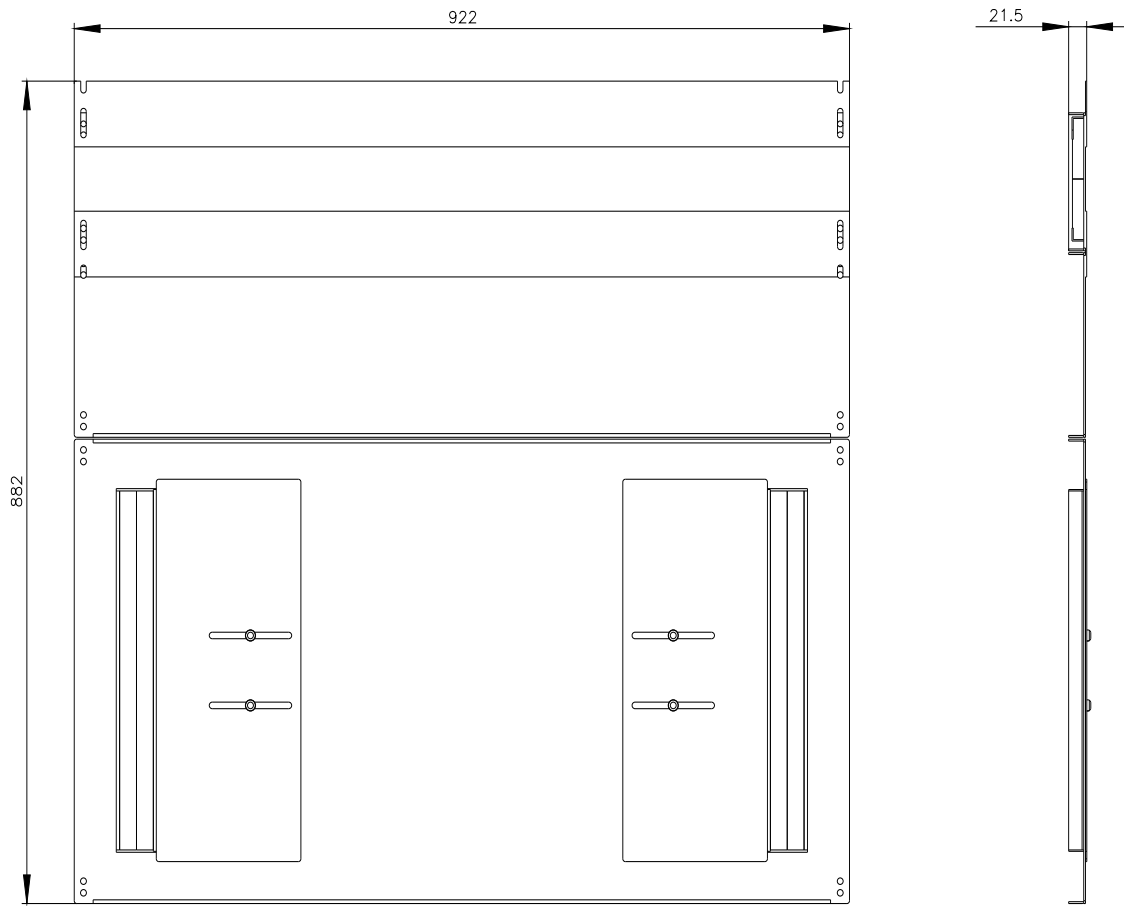

last modified:

6/3/2024 

